


16-Drum, 4-Hour Fire-Rated Outdoor Safety Locker - 913160

Product Images

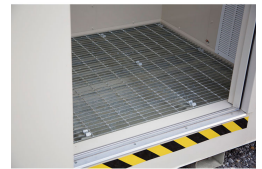

Short Description

- Higher fire rating — provides proximity advantage over non-combustible and 2-hour locker models
- 4-hour fire-rated construction
- 3-hour fire-rated door
- Meets EPA, NFPA 30 and NFPA 1 requirements; FM-approved
- Customizable with a variety of optional features and accessories

Description

Standard features include:

- 4-hour fire-rated construction — backed by a 15-year structural warranty
- 3-hour fire-rated door — third party tested and labeled
- Gravity air flow vents — UL Listed fire dampers with fusible links
- Secondary containment — leakproof all welded sump
- Removable, galvanized steel grate flooring
- 42-inch (1.07-m) wide door with UL listed, keyed lockset for security
- Door closer — ensures doors close automatically
- NFPA 704 diamond decal provides "Right to Know" information
- Multiple static grounding connections
- Anchoring plates for maximum hold down protection
- Chemical and UV resistant coating, inside and out
- Forklift channels for easy relocation
- Meets EPA, NFPA 30 and NFPA 1 requirements
- FM-approved — including third party tested, fire-rated wall and roof design

Customize the locker to meet specific applications with a variety of [optional features and accessories](#), including loading ramp, shelving, grounding kit, fire protection, heating/cooling, insulation, and lighting packages.

NOTE: Exterior dimensions include anchoring plates and door hardware.

Specifications

Model No	913160
UPC	697841158818
International Model No.	913160
Color	Bone
Material Specifications	Steel
FM Approval	Yes
UL Approval	Doors
Complies with NFPA Code 30	Yes
Complies with NFPA 1 Fire-Code	Yes
EPA Compliance	Yes
Dimensions, Exterior	99" H x 119" W x 114" D
	2515mm H x 3023mm W x 2896mm D
Dimensions, Interior	81" H x 98.5" W x 98.5" D
	2057mm H x 2502mm W x 2502mm D
55-Gallon Drum Capacity	16
Base Capacity, lbs	16000
Base Capacity, kg	7257.5
Number of Doors	1
Door Type	Fire-rated
Door Hinge	Left
Door Height inch	80
Door Width inch	42
Door Height mm	2032
Door Width mm	1067
Sump Capacity - Gallons	272
Sump Capacity - liters	1030

Sump Depth - inch	7.0
Sump Depth - mm	178
Storage Capacity cubic feet (Int Volume)	455
Storage Capacity cubic meters (Int Volume)	12.9
Net Weight, lbs	7826.0
Net Weight, kg	3549.9