


# SAUTER AD 9121

**KERN**

Rope and thread tension clamp up to 5 kN, Aluminium

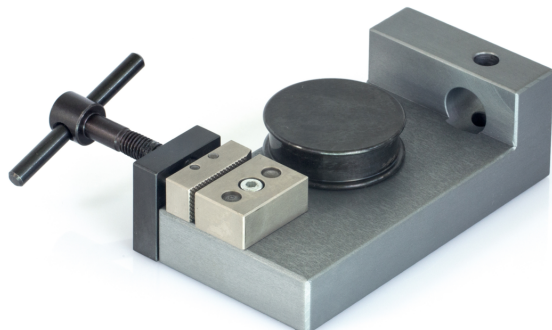

## Pictograms

STANDARD



## Category

Brand	Sauter
Product category	Clamp
Product group	Rope and thread tension clamp

## Construction

Dimensions completely mounted (W×D×H)	120×114×40 mm
Material	aluminium
Mounting - force dissipation	Threaded hole M6 External thread M12
Maximum clamp width	10 mm
Clamping width	5 mm
Tensile/compressive force [Max]	5 kN

## Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

## Packing & Shipping

Delivery time	14 d
Dimensions packaging (W×D×H)	120×114×40 mm
Shipping method	Parcel service
Net weight approx.	0,80 kg
Gross weight approx.	0,80 kg
Shipping weight	0,8 kg

## Product information

GTIN/EAN number	4045761178557
Trade number	90278990
REACH classification	no prohibited substances