


KERN BID3T-3D

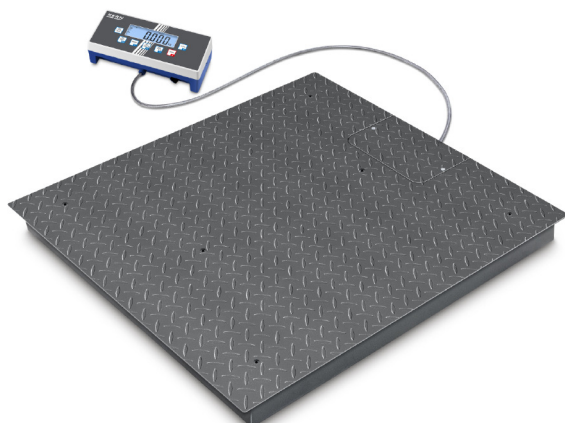

Floor scale with EC type approval [M] and the best price-performance ratio - now also as a high-resolution dual-range balance



Power supply

Battery:	no battery
Charging time:	3 h
Input voltage:	100V-240V AC 50/60Hz 0,400 Amax
Mains adapter:	Mains adapter external
Operating time (Backlight off):	43 h
Operating time (Backlight on):	26 h
Rechargeable battery:	Rchrg. battery optional - intern

Services (optional)

Adjustment at the location of installation: 961-252

DAkkS Certificate: 963-132

Category

Brand:	KERN
Category:	Balances
Product Group:	Floor scale

Packaging & shipping

Delivery:	48 h
Dimensions packaging (WxDxH):	1270 x 1560 x 240 mm
Gross weight:	167 kg
Net weight:	150 kg
Shipping method:	Freight forwarder

Construction

Cable length:	5 m
Cable length of display device:	5 m
Dimensions of display device (WxDxH):	268 x 115 x 80 mm
Dimensions of weighing plate (WxDxH):	1200 x 1500 x 108 mm
Level indicator:	yes
Revolving screw feet:	yes
Wall mount:	yes
Weighing surface (WxD):	1200 x 1500 mm

Measuring system

Adjustment options:	External calibration
Eccentric loading at 1/3 [Max]:	2,500 kg 5 kg
Linearisation (points):	3
Linearity:	1,500 kg 3 kg
Load cell connection:	4-wire
Number of weighing ranges:	2
Readability [d]:	200 g 500 g
Recommended adjusting weight:	3000 kg (M1)
Repeatability:	500 g 1000 g
Resolution:	7,500 6.000
Stabilisation time under laboratory conditions:	2 s
Tare range:	3 t
Warm up time:	30 min 30 min
Weighing capacity [Max]:	1,500 t 3 t
Weighing system:	Strain gauge
Weighing units:	g kg PCS lb tJ HJ oz

Display

Display digit height (large):	2,500 cm
Display digit height (small):	2,500 cm

Functions

Counting function:	yes
Percentage determination:	yes
PRE-TARE function:	yes
Vibration-free weighing (Animal weighing program):	yes
Weighing with tolerance range:	yes

Environmental conditions

Maximum humidity:	80 %
Minimum humidity:	0 %

KERN BID3T-3D



Floor scale with EC type approval [M] and the best price-performance ratio - now also as a high-resolution dual-range balance

Piktogramme

STANDARD



FACTORY

