


KERN BID 600K-1DS

High-resolution dual-range floor scale with the best price-to-performance ratio

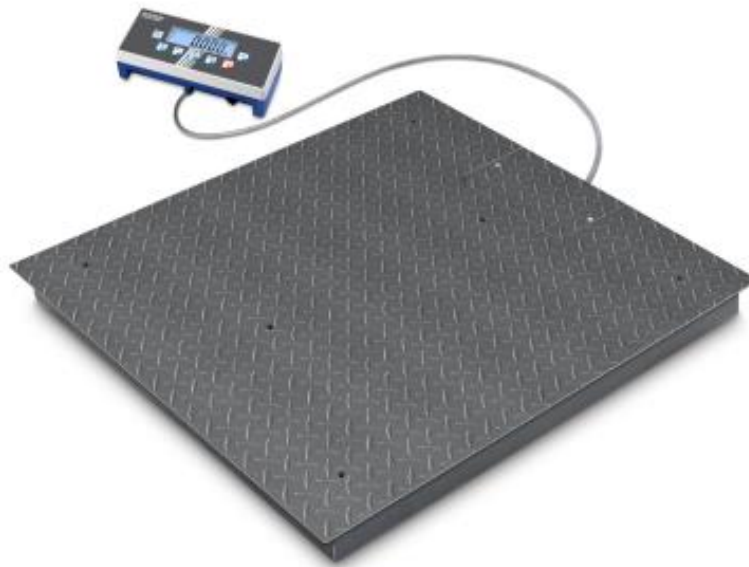

Article codes, product groups & Status information

Model article-code	BID 600K-1DS
Model-Serie	BID
Assortment	KERN
Segment	Industriewaagen
ProductGroup	Bodenwaagen
PM Status	Aktiv
Product usage type	Hauptartikel
EAN code (Model)	4045761275645

Technical data - Primary

Weighing capacity	300 kg; 600 kg
Readability	50 g; 100 g
Net weight	67 kg
Weighing area (Marketing)	1000×1000 mm

Technical data - Construction

Dimensions display casing	268×115×80 mm
Material weighing plate	Stahl, pulverbeschichtet
Level indicator	Yes
Revolving screw feet	Yes
Weighing surface (d)	1000×1000 mm
Dimensions of weighing plate (W×D)	1000×1000 mm
Indicator cable length	5 m

Wall mount	Yes
Dimensions weighing platform	1000×1000×108 mm
IP protection indicator	IP65
IP protection load cell	IP67

Technical data - Display

Display height	25 mm
Backlight	Ja

Technical data - Power supply

Battery	Keine Batterie
Charging time	3 h
Input Voltage	100V-240V AC 50/60Hz 0.4 Amax
Operating time (Backlight off)	43 h
Rechargeable battery	Akku optional - intern

Technical data - Measuring system

Calibration method	Justierung mit externem Gewicht
Linearity	± 0.3 kg; 0.6 kg
Readability ²	50 g; 100 g
Recommended adjusting weight	600 kg (M1)
Repeatability	0.1 kg; 0.2 kg
Resolution	6.000, 6.000
Stabilisation time under laboratory conditions	2 s
Tare range	600 kg
Warm up time	30 min; 30 min

KERN BID 600K-1DS

High-resolution dual-range floor scale with the best price-to-performance ratio



Weighing system	Dehnungsmessstreifen
Weighing units	G;HJ;kg;lb;oz;PCS;tJ
Linearity (in dots)	3
load cell connection	4-Leiter

Technical data - Environmental conditions

Maximum humidity	80 %
Maximum operating temperature	40 °C
Minimum ambient temperature	-10 °C
Minimum humidity	0 %

Technical data - Packing & Shipping

Dimensions packaging (WxDxH)	1080x1080x215 mm
Gross weight	95 kg
NetWeight2	70 kg
Shipping method	Spedition
Packaging component - by weight - paper	604 g
Packaging component - by weight - cardboard	0 g
Packaging component - by weight - plastics	9 g
Packaging component - by weight - styrofoam	0 g
Packaging component - by weight - glass	0 g
Packaging component - by weight - wood	23180 g

Packaging component - by weight - foam	0 g
Packaging component - by weight - metal	0 g
Delivery time	2 d

Technical data - Verification

Verification approval conforming to 2014/31/EU	Yes
--	-----

Price & Commercials

List price	1350.00 €
Warranty	36 mon

Optional Services

DAkKS Calibration	963-130
-------------------	---------

Functions

Standard



Option



Factory

