


SAUTER TI-HEA

KERN

Test stand for hardness testing Shore A and D

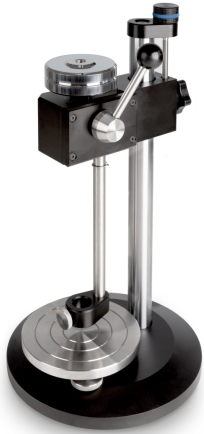

Product information

GTIN/EAN number	4045761366176
Trade number	90248000
REACH classification	no prohibited substances

Pictograms

STANDARD



Category

Brand	Sauter
Product category	Hardness testing
Product group	Manual Shore test stand
Product family	TI-HE

Measuring System

Hardness scales	Shore A
Test force Hardness measurement	10 N

Construction

Dimensions completely mounted (W×D×H)	200×200×390 mm
Base plate diameter (Ø)	115 mm
Material	steel, lacquered
Material housing	steel, lacquered
Test object height [Max]	50 mm
Traverse distance with lever movement / release [Max]	20 mm

Environmental conditions

Storage temperature [Max]	40 °C
---------------------------	-------

Packing & Shipping

Delivery time	1 d
Dimensions packaging (W×D×H)	250×250×400 mm
Shipping method	Parcel service
Net weight approx.	6 kg
Gross weight approx.	7 kg
Shipping weight	6,3 kg