


# KERN YKA-48

Power adapter (CH, EURO, UK)

# KERN

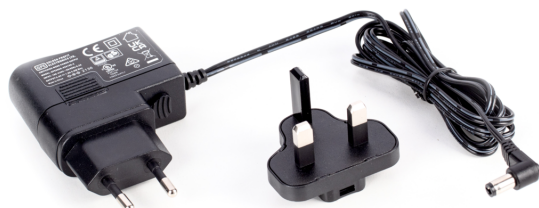

Shipping weight

0,11 kg

## Product information

|                      |                          |
|----------------------|--------------------------|
| GTIN/EAN number      | 4045761357181            |
| Trade number         | 85044095                 |
| REACH classification | no prohibited substances |

## Pictograms

## STANDARD



## Category

|                  |               |
|------------------|---------------|
| Brand            | KERN          |
| Product category | Balance       |
| Product group    | Power adapter |

## Construction

|                   |             |
|-------------------|-------------|
| Dimension (W×D×H) | 80×57×20 mm |
| Material          | plastic     |
| Cable length      | 1,5 m       |

## Functions

|                                 |   |
|---------------------------------|---|
| IP protection - complete device | - |
|---------------------------------|---|

## Power Supply

|                                                                           |                                                                              |
|---------------------------------------------------------------------------|------------------------------------------------------------------------------|
| Power supply type                                                         | Power adapter                                                                |
| Plug-in power supply / adapter for countries - included with the delivery | EURO<br>UK<br>CH                                                             |
| Input voltage power supply / power [Max]                                  | 100 V - 240 V, 50 / 60 Hz                                                    |
| Input voltage device / power [Max]                                        | 5 V 1000 mA                                                                  |
| Power socket for mains adapter                                            | Hollow plug, inside plus,<br>Ø outside 5,5 mm, Ø inside 2,1 mm, long 10,8 mm |

## Approval

|         |   |
|---------|---|
| CE mark | ✓ |
|---------|---|

## Packing & Shipping

|                              |                |
|------------------------------|----------------|
| Delivery time                | 1 d            |
| Dimensions packaging (W×D×H) | 90×80×50 mm    |
| Shipping method              | Parcel service |
| Net weight approx.           | 0,10 kg        |
| Gross weight approx.         | 0,15 kg        |