



DAG Guard

Class II, Div. 1 & 2 Groups E,F,G^①
Class III

Listed - File E12976

Certified - File LR11713

FEATURES-SPECIFICATIONS

DV DUST-IGNITION PROOF

Applications


For hazardous locations where suspended metal, carbon (coal, etc.) and grain dusts create explosive or ignitable mixtures with the air

Features

Cast of corrosion resistant aluminum alloy with electrostatically applied epoxy/polyester finish

Ceiling mounted units supplied with 4 hubs.

Dimensions

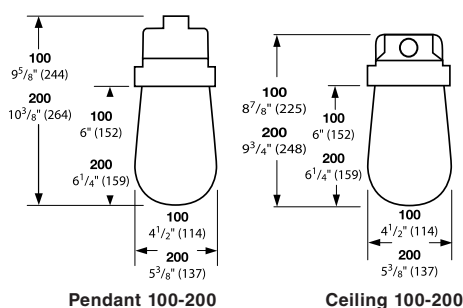

DV 100/200				
MODEL SIZE	LAMP SIZE	HUB	CATALOG NUMBER	
			PENDANT	CEILING
TYPE 100	100 Watt A-21	1/2"	DVA-110	DVX-110
	150 Watt A-23	3/4"	DVA-210	DVX-210
TYPE 200	150 Watt PS-25	1/2"	DVA-120	DVX-120
	200 Watt PS-25	3/4"	DVA-220	DVX-220

ACCESSORIES/REPLACEMENT PARTS			
FIXTURE TYPE	CATALOG NUMBER		
	GLASS GLOBE	WIRE GUARD	REPLACEMENT SOCKET
100	DCGE-10	DAG-100	VRME
200	DCGE-20	DAG-200	VRME

^① Temperature code T3B, use supply wire suitable for 150° C.

XHL SERIES HAND LAMPS

XHL Series Hand Lamps are a handy accessory to the ACCEPTOR® Series. Used as a supplemental illumination source for areas where flammable materials are present such as processed finished goods, storage vats or handling areas.

Features XHL Incandescent

- Phenolic handle for long service in rugged conditions
- Aluminum guard
- Heat and impact resistant globe
- Supplied with an A-21 100 Watt (100A/RS) Rough Service lamp
- Supplied with 2 grommets for use with either 14/3 or 16/3 user furnished SO cable

CATALOG NUMBER	DESCRIPTION
XHL-100	Handlamp
XHL-GL	Replacement Globe
XHLG	Replacement Guard
XHLS	Replacement Socket

XHL Incandescent

Class I, Div. 1 & 2, Groups C, D
Class I, Zones 1 & 2, Groups IIB, IIA

Listed File No. E97760

Certified File No. LR10019

Features XHLF Fluorescent (120 VAC)

- No exposed metal parts
- Furnished with 26 watt 1800 Lumen fluorescent lamp and light shield
- Supplied with grommet for use with 16/3 user furnished SO cable

CATALOG NUMBER	DESCRIPTION
XHLF26	Fluorescent hand lamp
XHLF26-50KP	Fluorescent hand lamp with 50' of 16/3 SOW cord and 15A Acceptor plug

XHLF Fluorescent

Class I, Div. 1 & 2, Groups C,D
Class I, Zones 1 & 2, Groups IIB, IIA
Class II, Div. 1 & 2, Groups F,G

Listed File No. E97760



XHL



XHLF



KILLARK®