


**Aluminum Conduit Bodies**  
**Applications**

- For use on threaded rigid/IMC conduit
- Use conduit bodies for making turns in conduit systems, connecting conduit sections, as pull outlets, and to provide openings for maintenance and making taps and splices to conductors

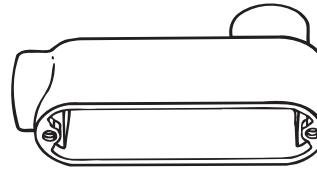

**Aluminum Conduit Bodies**  
**Product Features**

- Flat back design for easy mounting close to walls
- Cast of high strength, corrosion and weather resistant aluminum alloy with painted finish
- May be used on aluminum or steel conduit
- Lightweight, makes installation simple

**Compliances**


- – Standard 514B
- – C22.2 #18

**TYPE LB**

**ORDERING INFORMATION - DIMENSIONS**

| TYPE LB        |            |                |                |              |
|----------------|------------|----------------|----------------|--------------|
| CATALOG NUMBER | TRADE SIZE | UNIT CTN. QTY. | SHIP CTN. QTY. | UPC BAR CODE |
| EALB-1         | 1/2"       | 10             | 100            | —            |
| EALB-2         | 3/4"       | 10             | 50             | —            |
| EALB-3         | 1"         | 6              | 24             | —            |
| EALB-4         | 1-1/4"     | 2              | 8              | —            |
| EALB-5         | 1-1/2"     | 2              | 8              | —            |
| EALB-6         | 2"         | 1              | 5              | —            |
| EALB-7         | 2-1/2"     | —              | 1              | —            |
| EALB-8         | 3"         | —              | 1              | —            |
| EALB-9         | 3-1/2"     | —              | 1              | —            |
| EALB-10        | 4"         | —              | 1              | —            |

**TYPE LB**

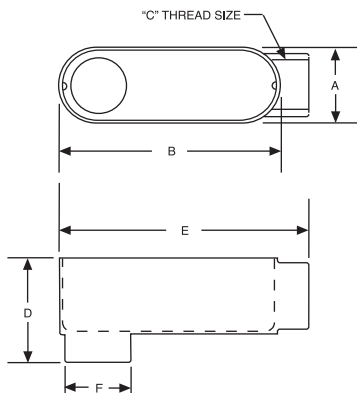

| DIMENSIONS   |         |         |        |          |          |          |
|--------------|---------|---------|--------|----------|----------|----------|
| CONDUIT SIZE | A       | B       | C      | D        | E        | F        |
| 1/2"         | 1-5/16" | 3-7/8"  | 1/2"   | 2-1/8"   | 4-3/8"   | 1-1/16"  |
| 3/4"         | 1-1/2"  | 4-5/8"  | 3/4"   | 2-7/16"  | 5-1/8"   | 1-11/32" |
| 1"           | 1-3/4"  | 5-3/8"  | 1"     | 2-13/16" | 5-15/16" | 1-21/32" |
| 1-1/4"       | 2-1/2"  | 6-5/8"  | 1-1/4" | 3-3/4"   | 6-7/8"   | 2-1/4"   |
| 1-1/2"       | 2-1/2"  | 6-5/8"  | 1-1/4" | 3-3/4"   | 6-7/8"   | 2-1/4"   |
| 2"           | 3-1/8"  | 8-1/2"  | 2"     | 4-1/8"   | 9-7/32"  | 2-15/16" |
| 2-1/2"       | 4-9/16" | 12-1/4" | 2-1/2" | 5-13/16" | 13-1/8"  | 3-7/16"  |
| 3"           | 4-9/16" | 12-1/4" | 3"     | 5-13/16" | 13-1/8"  | 4-7/64"  |
| 3-1/2"       | 5-7/16" | 14-7/8" | 3-1/2" | 7-1/4"   | 15-3/8"  | 5-9/64"  |
| 4"           | 5-7/16" | 14-7/8" | 4"     | 7-1/4"   | 15-3/8"  | 5-9/64"  |