



E SERIES

KILLARK

ALUMINUM - COVER AND GASKET INCLUDED

UL - Standard 514B
 NSF - C22.2 #18

FEATURES-SPECIFICATIONS

Applications

- For use on threaded rigid/IMC conduit
- Use conduit outlet bodies for connecting conduit sections, for making bends in conduit runs, as pull outlets, or to provide openings for making splices and taps in conductors



Features

- Assembled with cover and gasket to speed installation - installer has all components needed
- Flat back design for easy mounting close to walls
- Cast of high strength, corrosion and weather resistant aluminum alloy with painted finish
- May be used on aluminum or steel conduit
- Lightweight, makes installation simple
- Unique E-PAK™ packaging serves as a shipping and display carton





Type LB

TYPE LB								
CATALOG NUMBER	CONDUIT SIZE	DIMENSIONS						E PAK CTN
		A	B	C	D	E	F	
EALB-1CGN	1/2"	1-5/16"	3-7/8"	1/2"	2-7/8"	4-3/32"	1-1/16"	10
EALB-2CGN	3/4"	1-1/2"	4-5/8"	3/4"	2-7/16"	5-1/8"	1-11/32"	10
EALB-3CGN	1"	1-3/4"	5-3/8"	1"	2-13/16"	6-15/16"	1-21/32"	5
EALB-4CGN	1-1/4"	2-1/2"	6-5/8"	1-1/4"	3-3/4"	6-7/8"	2-1/4"	2
EALB-5CGN	1-1/2"	2-1/2"	6-5/8"	1-1/2"	3-3/4"	6-7/8"	2-1/4"	2
EALB-6CGN	2"	3-1/8"	8-1/2"	2"	4-1/8"	9-7/32"	2-15/16"	1
EALB-7CGN	2-1/2"	4-9/16"	12-1/4"	2-1/2"	5-13/16"	13-1/8"	3-7/16"	1
EALB-8CGN	3"	4-9/16"	12-1/4"	3"	5-13/16"	13-1/8"	4-7/64"	1
EALB-9CGN	3-1/2"	5-7/16"	14-7/8"	3-1/2"	7-1/4"	15-3/8"	5-9/64"	1
EALB-10CGN	4"	5-7/16"	14-7/8"	4"	7-1/4"	15-3/8"	5-9/64"	1

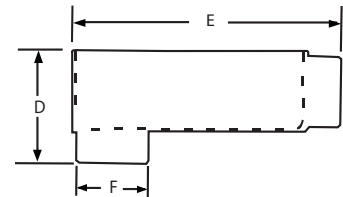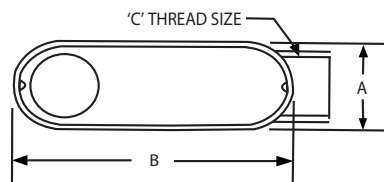

Type C

TYPE C								
CATALOG NUMBER	CONDUIT SIZE	DIMENSIONS						E PAK CTN
		A	B	C	D	E	F	
EAC-1CGN	1/2"	1-5/16"	3-7/8"	1/2"	1-7/16"	4-29/32"	1-1/16"	10
EAC-2CGN	3/4"	1-1/2"	4-5/8"	3/4"	1-11/16"	5-1/2"	1-11/32"	10
EAC-3CGN	1"	1-3/4"	5-3/8"	1"	1-15/16"	6-7/16"	1-21/32"	5
EAC-4CGN	1-1/4"	2-1/2"	6-5/8"	1-1/4"	2-7/8"	8-7/16"	2-1/4"	2
EAC-5CGN	1-1/2"	2-1/2"	6-5/8"	1-1/2"	2-7/8"	8-7/16"	2-1/4"	2
EAC-6CGN	2"	3-1/8"	8-1/2"	2"	3-7/16"	10-3/4"	2-15/16"	1
EAC-7CG	2-1/2"	4-9/16"	12-1/4"	2-1/2"	4"	14"	3-7/16"	1
EAC-8CG	3"	4-9/16"	12-1/4"	3"	4-3/4"	13-1/2"	4-7/64"	1
EAC-9CG	3-1/2"	5-7/16"	14-7/8"	3-1/2"	5-1/2"	15-29/32"	5-9/64"	1
EAC-10CG	4"	5-7/16"	14-7/8"	4"	5-1/2"	15-29/32"	5-9/64"	1

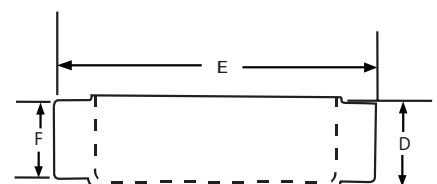
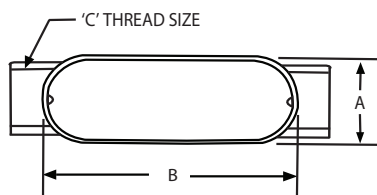


ALUMINUM - COVER AND GASKET INCLUDED




Type LL

TYPE LL								
CATALOG NUMBER	CONDUIT SIZE	DIMENSIONS						E PAK CTN
		A	B	C	D	E	F	
EALL-1CGN	1/2"	1-5/16"	3-7/8"	1/2"	2-3/64"	4-3/8"	1-7/16"	10
EALL-2CGN	3/4"	1-1/2"	4-5/8"	3/4"	2-5/16"	5-1/8"	1-11/16"	10
EALL-3CGN	1"	1-3/4"	5-3/8"	1"	2-21/32"	5-15/16"	1-15/16"	5
EALL-4CGN	1-1/4"	2-1/2"	6-5/8"	1-1/4"	3-15/32"	6-7/8"	2-7/8"	2
EALL-5CGN	1-1/2"	2-1/2"	6-5/8"	1-1/2"	3-15/32"	6-7/8"	2-7/8"	2
EALL-6CGN	2"	3-1/8"	8-1/2"	2"	3-7/8"	9-7/32"	3-7/16"	1
EALL-7CG	2-1/2"	4-9/16"	12-1/4"	2-1/2"	6"	13-1/8"	4"	1
EALL-8CG	3"	4-9/16"	12-1/4"	3"	6"	13-1/8"	4-3/4"	1
EALL-9CG	3-1/2"	5-7/16"	14-7/8"	3-1/2"	6-1/4"	15-3/8"	5-1/2"	1
EALL-10CG	4"	5-7/16"	14-7/8"	4"	6-1/4"	15-3/8"	5-1/2"	1

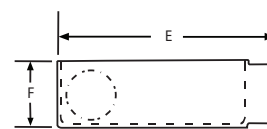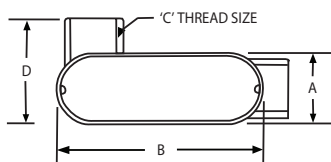

Type LR

TYPE LR								
CATALOG NUMBER	CONDUIT SIZE	DIMENSIONS						E PAK CTN
		A	B	C	D	E	F	
EALR-1CGN	1/2"	1-5/16"	3-7/8"	1/2"	2-3/64"	4-3/8"	1-7/16"	10
EALR-2CGN	3/4"	1-1/2"	4-5/8"	3/4"	2-5/16"	5-1/8"	1-11/16"	10
EALR-3CGN	1"	1-3/4"	5-3/8"	1"	2-21/32"	5-15/16"	1-15/16"	5
EALR-4CGN	1-1/4"	2-1/2"	6-5/8"	1-1/4"	3-15/32"	6-7/8"	2-7/8"	2
EALR-5CGN	1-1/2"	2-1/2"	6-5/8"	1-1/2"	3-15/32"	6-7/8"	2-7/8"	2
EALR-6CGN	2"	3-1/8"	8-1/2"	2"	3-7/8"	9-7/32"	3-7/16"	1
EALR-7CG	2-1/2"	4-9/16"	12-1/4"	2-1/2"	6"	13-1/8"	4"	1
EALR-8CG	3"	4-9/16"	12-1/4"	3"	6"	13-1/8"	4-3/4"	1
EALR-9CG	3-1/2"	5-7/16"	14-7/8"	3-1/2"	6-1/4"	15-3/8"	5-1/2"	1
EALR-10CG	4"	5-7/16"	14-7/8"	4"	6-1/4"	15-3/8"	5-1/2"	1

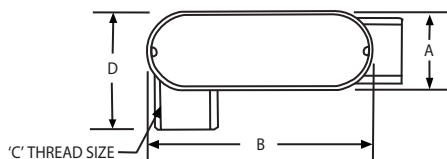

Type T

TYPE T								
CATALOG NUMBER	CONDUIT SIZE	DIMENSIONS						E PAK CTN
		A	B	C	D	E	F	
EAT-1CGN	1/2"	1-5/16"	3-7/8"	1/2"	1-7/16"	4-29/32"	2-1/8"	10
EAT-2CGN	3/4"	1-1/2"	4-5/8"	3/4"	1-11/16"	5-1/2"	2-11/32"	10
EAT-3CGN	1"	1-3/4"	5-3/8"	1"	1-15/16"	6-7/16"	2-21/32"	5
EAT-4CGN	1-1/4"	2-1/2"	6-5/8"	1-1/4"	2-7/8"	8-7/16"	3-19/32"	2
EAT-5CGN	1-1/2"	2-1/2"	6-5/8"	1-1/2"	2-7/8"	8-7/16"	3-19/32"	2
EAT-6CGN	2"	3-1/8"	8-1/2"	2"	3-7/16"	10-3/4"	4-1/32"	1
EAT-7CG	2-1/2"	4-9/16"	12-1/4"	2-1/2"	4"	14"	6-1/4"	1
EAT-8CG	3"	4-9/16"	12-1/4"	3"	4-3/4"	13-1/2"	6-1/4"	1
EAT-9CG	3-1/2"	5-7/16"	14-7/8"	3-1/2"	5-1/2"	15-29/32"	7"	1
EALB-10CG	4"	5-7/16"	14-7/8"	4"	5-1/2"	15-29/32"	7"	1

