

LIGHTING

EM/EQ/ESX/EEQ SERIES



DIMENSIONS



Pendant



Ceiling




Wall




Stanchion

FEATURES-SPECIFICATIONS


SERIES	EM/ EMB /ESX DIMENSIONS														
	PENDANT				CEILING				WALL				STANCHION		
	A	B	C	D	A	B	C	D	A	B	C	D	A	B	C
EMI15	14-5/16"	13-11/16"	7-7/16"	10-5/16"	14-5/16"	13-11/16"	7-7/16"	10-5/16"	15-13/16"	14-7/16"	14-1/2"	10-5/16"	14"	13-1/4"	13"
EMI20	(363)	(346)	(188)	(261)	(363)	(347)	(188)	(261)	(385)	(366)	(369)	(26)	(256)	(337)	(330)
EQF to 42W	16-13/16"	16-3/16"	7-7/16"	12-5/8"	16-13/16"	16-3/16"	7-7/16"	12-5/8"	18-5/16"	16-15/16"	14-1/2"	12-5/8"	16-1/4"	15-3/4"	15-1/4"
EEQ	(427)	(411)	(188)	(321)	(427)	(411)	(188)	(321)	(465)	(430)	(368)	(321)	(413)	(400)	(387)
EMI30															
EMH															
EMS	15-15/16"	15-1/16"	8-13/16"	11-15/16"	15-15/16"	15-1/16"	8-13/16"	11-15/16"	16-13/16"	15-13/16"	15"	11-15/16"	15-1/8"	14"	13-1/2"
ESX	(404)	(382)	(224)	(303)	(404)	(382)	(224)	(303)	(426)	(404)	(379)	(303)	(384)	(356)	(343)
EQF 52, 64, 84															

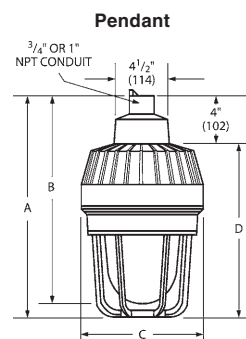


Pendant

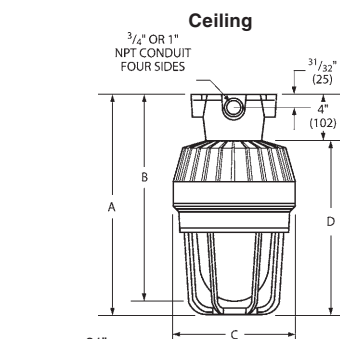


Ceiling

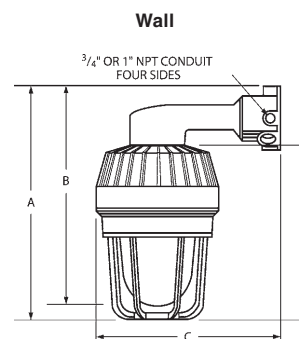



Wall

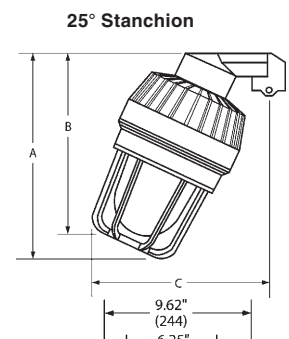




25° Stanchion

 

Standard Dome

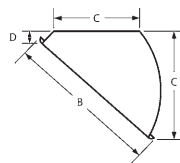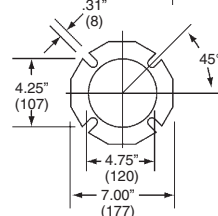

Angle

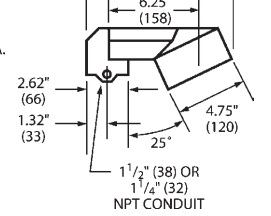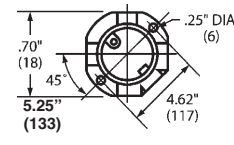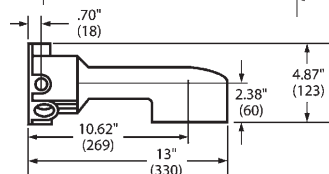

REFLECTOR DIMENSIONS							
SERIES	STANDARD DOME			ANGLE			
	A	B	C	A	B	C	D
EMI15/EMI20	7-3/8"	14"	3-3/4"	7"	11-1/2"	7-3/4"	1"
EQF to 42W	(187)	(356)	(95)	(178)	(292)	(197)	(25)
EMI30/EMS	8-3/4"	16-1/8"	3-15/16"	8-3/4"	14-3/16"	7-3/4"	1"
EMH	(222)	(409)	(100)	(222)	(360)	(197)	(25)
EQF 52, 64, 84							



COMPACT FLUORESCENT EMERGENCY LIGHTING



Class I, Div. 1 & 2, Groups C,D
Class I, Zones 1 & 2, Groups IIB, IIA
Class II, Div. 1 & 2, Groups E,F,G
Class III
NEMA 3

UL Complies: UL 844; UL 1570, UL924 (File E162407)

UL Wet Location Listed (Indoor & Outdoor)
 Rated for 40°C ambient. Minimum start 0° C

Temperature codes:

Class I C, D **T6**;

Class II E, F, G **T4**;

Suitable for Class III

Certified File LR11713



FEATURES-SPECIFICATIONS

HOSTILELITE® E

EMERGENCY

Applications

HOSTILELITE® EEQ Emergency Lighting fixtures provide continuous illumination under normal power and switch to emergency battery backup during power outages. Emergency Units ONLY are available that operate only when normal power fails.

Units contain battery unit that provides the OSHA required 90 minutes of illumination (same lamp) for egress.

Units are designed for general and task lighting indoors or outdoors where flammable gases or vapors or combustible dusts exist and create a hazardous location, as defined by the NEC.

See Page L211 for available Push-To-Test hazardous location control stations.


Features

- Quad-Pin long-life triple-tube compact fluorescent lamps included
- Choice of Pendant, Ceiling, Wall or Stanchion mount
- Factory Sealed - No external seal required
- Corrosion resistant-Copper-free aluminum (less than 4/10 of 1%) die-cast construction w/Baked-on epoxy/polyester powder finish
- Exposed hardware is 316 grade stainless steel
- LED charging indicator light visible through lens

Accessories

Exit sign: Model **HEXA-100** (note omit 2nd "G" in catalog number for globe-only fixture).

Reflectors: Use standard dome **ERSD15** or angle model **ERA15**.

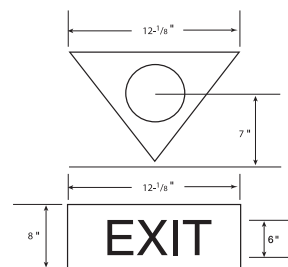

EEQ 26, 32 & 42 WATT EMERGENCY- ONLY MODE FIXTURES

QUAD-PIN FLUOR. LAMP INCLUDED	LINE VOLTAGE @ 50/60 HZ	CATALOG NUMBER ③④⑥			
		PENDANT 3/4" ①	CEILING 3/4" ①	BRACKET 3/4" ①	STANCHION 1-1/4" ②
26Watt	120 - 277VAC ⑤	EEQ0026E30A2G	EEQ0026E30X2G	EEQ0026E30B2G	EEQ0026E30D4G
32Watt	120 - 277VAC ⑤	EEQ0032E30A2G	EEQ0032E30X2G	EEQ0032E30B2G	EEQ0032E30D4G
42Watt	120 - 277VAC ⑤	EEQ0042E30A2G	EEQ0042E30X2G	EEQ0042E30B2G	EEQ0042E30D4G

EEQ 26, 32 & 42 WATT NORMAL & EMERGENCY MODE FIXTURES

QUAD-PIN FLUOR. LAMP INCLUDED	LINE VOLTAGE @ 50/60 HZ	CATALOG NUMBER ③④⑥			
		PENDANT 3/4" ①	CEILING 3/4" ①	BRACKET 3/4" ①	STANCHION 1-1/4" ②
26Watt	120 - 277VAC ⑤	EEQ2626E30A2G	EEQ2626E30X2G	EEQ2626E30B2G	EEQ2626E30D4G
32Watt	120 - 277VAC ⑤	EEQ3232E30A2G	EEQ3232E30X2G	EEQ3232E30B2G	EEQ3232E30D4G
42Watt	120 - 277VAC ⑤	EEQ4242E30A2G	EEQ4242E30X2G	EEQ4242E30B2G	EEQ4242E30D4G

① Pendant, Ceiling & Bracket models may be changed to 1" hubs by changing the 12th character from 2 to 3; e.g. EEQ2626E10A3GG.

② Stanchion fixtures are 1-1/2" with a 1-1/2 to 1-1/4" reducer.

③ Omit 2nd "G" for globe-only fixture for use with HEXA-100 Exit Accessory.

④ Standard color for fixtures is Killark beige. Add -R for RED adder.

⑤ All EEQ fixtures are factory set to 120V and can be changed to 277V in field by following included instructions. Replacement battery pack kit KFBP9.

⑥ EEQ fixtures use a tank extension ring and are 2-1/2" taller than EBF fixtures.

⑦ Photometric characteristics similar to EBF26, except adjusted for lumen output.

LUMEN OUTPUT ⑦

LAMP SOURCE	NORMAL POWER	EMERG. POWER
26Watt	1800	450
32Watt	2400	575
42Watt	3200	750

BALLAST DATA

LAMP WATTS	VOLTAGE	OPERATING AMPS	INPUT WATTS	BALLAST CIRCUIT	REGULATION
26Watt (1x26)	120 / 277 VAC	.24@120V / .11 @277V	29	HPF	Electronic
32Watt (1x32)	120 / 277 VAC	.31@120V / .13 @277V	36	HPF	Electronic
42Watt (1x42)	122 / 277 VAC	.38@120V / .17 @277V	46	HPF	Electronic