



GCBB-HANDLE-KIT - GCBB Series - Aluminum Handle For 1-Pole Circuit Breaker Load Centers

By Killark
Catalog # [GCBB-HANDLE-KIT](#)

GCBB Series - Aluminum Handle For 1-Pole Circuit Breaker Load Centers

Features


- Push pull handle mechanism operates circuit breakers.
- Handle mechanism supplied as standard with "Lockout" in OFF position.

Application

Indoor and outdoor hazardous areas where flammable gases or vapors, combustile dusts, or easily ignitable fibers or flyings may be present. Provides overcurrent and short circuit protection of branch lighting, heating, and appliance circuits.

Specifications

Hazardous Rating(s)	• Class I, Divisions 1 & 2, Groups B, C, D • Class I, Zones 1 & 2, Groups IIB+H2, IIA • Class II, Divisions 1 & 2, Groups E, F, G • Class III, Divisions 1 & 2
EU RoHS Indicator	Contact Manufacturer
Nema Rating	3R, 7(B, C, D), 9(E, F, G)
UL File Number	E83969

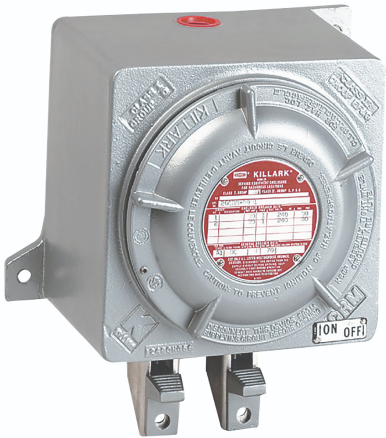

Buy America(n) Qualified	Contact Manufacturer
Current	
Frequency Rating	60 Hz
Dimensions	
Gross Weight with Packaging	0.3
General	
Type	Replacement Handle
Series	GCBB Series
Material	Aluminum, Copper Free (less than 4/10 of 1%)
UPC	783936039428
Operational	
Operating Temperature Celcius Max	40 Degree
Product Assets	
	Catalog [English]
	Catalog Page [English]