



GO28-2A7F22A - G Series, AL Short Maintained Contact 2-Pos Keyed Selector Switch Op, Keyed Alike w/ Key Removal Left, Off-On/Blank Nameplate, 2NC

By Killark
Catalog # [GO28-2A7F22A](#)

G Series - Aluminum Short Maintained Contact 2-Position Keyed Selector Switch Operator - Keyed Alike With Key Removal In Left Position - "Off -On"/Blank Nameplate - 2NC Contact Rating

Features

- Operators are all aluminum except for certain movable parts which are stainless steel.
- All other parts such as screws are either stainless steel or plated steel.
- Threaded bodies are all 3/4"-14 NPSM thread.
- Control stations can be grouped into a single assembly thus reducing installation time and cost.

Application

G Series custom control panel operators are designed for use in hazardous locations when installed in suitable enclosures such as B7E, EXB, XJB, DB, SWB, and GCS Series boxes and B7, Y7 starter enclosures.

Specifications


Hazardous Rating(s)	• Class I, Divisions 1 & 2, Groups C, D • Class II, Divisions 1 & 2, Groups E, F, G • Class III, Divisions 1 & 2
EU RoHS Indicator	Contact Manufacturer
UL File Number	E12379
CSA File Number	LR11714
Buy America(n) Qualified	Contact Manufacturer

Conductor

Number Of Poles	1
-----------------	---

Current

Contact Rating	• 60A INRUSH @ 120 VAC • 30A INRUSH @ 240 VAC • 15A INRUSH @ 480 VAC • 12A INRUSH @ 600 VAC • 0.55A INRUSH @ 125 VDC • 0.275A INRUSH @ 250 VDC
----------------	--

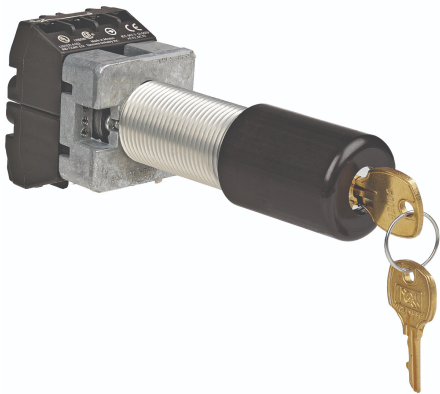

- 6A BREAKING @ 120 VAC
- 3A BREAKING @ 240 VAC
- 1.5A BREAKING @ 480 VAC
- 1.2A BREAKING @ 600 VAC
- 0.55A BREAKING @ 125 VDC
- 0.275A BREAKING @ 250 VDC
- 10A CARRYING @ 120 VAC
- 10A CARRYING @ 240 VAC
- 10A CARRYING @ 480 VAC
- 10A CARRYING @ 600 VAC
- 2.5A CARRYING @ 125 VDC
- 2.5A CARRYING @ 250 VDC.

Amperage Rating	10 A
Frequency Rating	50/60 Hz

Dimensions

Gross Weight with Packaging	0.6
Width	2.25 in
Height	1.25 in
Length	6.31 in
Dimensions	6.31 in x 2.25 in x 1.25 in

General

Type	Selector Switch
Series	GO Series
UPC	783936040998
Color	Black

Operational

Action	Rotary
Actuator	2 Position Selector Switch

Product Assets

[Catalog \[English\]](#)