



HKH Series Control Station, Maintained Contact Push Button E-Stop (Twist Release)- Din Rail Mount- M20 - Stainless Steel 1b

By Killark
Catalog # [HKH1BSDAM71E](#)

HKH Maintained Contact Push Button E-Stop (Twist Release)-
Din Rail Mount- M20 - Stainless Steel 1b

Features


- Size 1 Control Stations available as 1a, 1b, & 1c as standard catalog number offerings for 1, 2 & 3 device openings and will accept 2-M20 entries in either end.
- Ammeters available in 1b & 1c.
- Size 2 Enclosures available as 2a & 2c for 2, 4 & 6 device entries in cover with ability to accept 2-M25 entries in either end.
- Operating Temperature of -50°C to +60°C.
- Explosion Protected contact blocks 690 VAC N.O. & N.C. capable of 20 Amps for Switching Duty and HP Ratings up to 1HP.
- LED Pilot Light modules for 12-250V AC/ DC for UL applications. 12-254V AC/DC for IEC applications.
- Contacts & Pilot lights can be mounted inside enclosure on Din Rail or in cover to the actuator.
- Accessories available for Lockout/Tag Out functions made in 316 stainless steel.

Application

Hazardous and corrosive environments due to the presence of flammable gases or vapors, combustible dusts or ignitable fiber or flyings, Installations at petroleum refineries, chemical and petrochemical plants and other processing or storage facilities where similar hazards exist, Use in conjunction with motor starters or contactors for remote control of motors

Specifications

Hazardous Rating(s)	• Class I, Division 2, Groups A, B, C, D • Class II, Division 1, Groups E, F, G (Canada Only) • Class II, Division 2, Groups E, F, G • Class III, Divisions 1 & 2 • Zones 1 & 2
---------------------	---

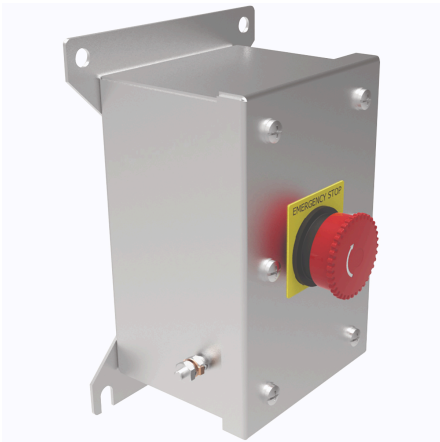

IECEX File Number	15.0054X
EU RoHS Indicator	Contact Manufacturer
Nema Rating	3, 4, 4X, 12, 13
UL File Number	E53360
Buy America(n) Qualified	Contact Manufacturer
ATEX File Number	1405X
Current	
Amperage Rating	20 A
Frequency Rating	50/60 Hz
Dimensions	
Depth	4.25 in
Hub Size	M20
Weight	1.66 lb.
General	
Series	HKH Series
Material	Stainless Steel, Type 316
UPC	783936133317
Color	Red
Mounting Type	Wall
Operational	
Operating Temperature Range	-50°C to 60°C
Celcius	
Action	Maintained
Actuator	Mushroom Pushbutton
Horsepower - Maximum	1
Product Assets	
Catalog [English]	
Installation Manual [English]	
Installation Manual [English]	