

**E INCANDESCENT**

EPG-2-200



EXG-2-200



EBG-2-200



HG-200

Class I, Div. 1 & 2, Groups A,B,C,D
Class I, Zones 1 & 2, Groups IIC,IIB,IIA
Class II, Div. 1 & 2, Groups E,F,G

Applications

For hazardous locations including where **Group A or Group B** gases are present, indoors or outdoors.

General, local or supplementary lighting in areas where Group A or Group B gases are manufactured, used or handled.

Features

- Cast of corrosion resistant aluminum alloy with electrostatically applied epoxy/polyester finish
- For 200 watt or 300 watt PS-30 medium base lamps. Fixture for lamp base-up mounting only
- Omit "G" in catalog number to omit guard

Groups **A,B** Rated

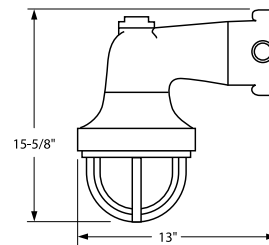
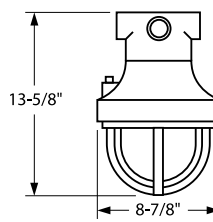
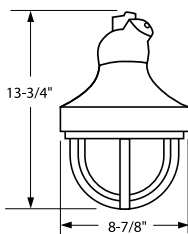
E INCANDESCENT FIXTURE	
CATALOG NUMBER	DESCRIPTION
EPG-2-200	Pendant 3/4" hub
EXG-2-200	Ceiling 3/4" hub
EBG-2-200	Bracket 3/4" hub

Note: For 200 watt or 300 watt PS-30 lamps.
Fixture for lamp base-up mounting only.

E ACCESSORIES	
CATALOG NUMBER	DESCRIPTION
HG-200	Guard
EGSA-200	Globe w/ support assembly
HRME*	Replacement socket
ERSD30	Dome reflector
ERA30	Angle reflector

* Also fits discontinued H series medium base fixtures

E APPLICATION DATA							
LAMP WATTS	RATED AMBIENT °C	CLASS I, DIV. 1 & 2		CLASS II, DIV. 1 & 2		CLASS III SUITABILITY	SUPPLY WIRE °C
		T-CODE	GROUPS	T-CODE	GROUPS		
200	40	T4	A, B, C, D	T3C	E, F, G	YES	90
300	40	T3C	A, B, C, D	T3A	E, F	NO	150

**H INCANDESCENT****500W MOGUL BASE**

SERIES DISCONTINUED

AVAILABLE REPLACEMENT PARTS	
CATALOG NUMBER	DESCRIPTION
HP-2	3/4" Pendant Mount
HX-2	3/4" Ceiling Mount
HB-2	3/4" Wall Mount
HGSA-500F	Globe with Support Assembly
EZG1G	Guard
HRMO	Replacement Mogul Socket
HRD-400	Deep Reflector 21-1/8" dia.

Class I, Div. 1 & 2, Groups C,D
Class I, Zones 1 & 2, Groups IIB,IIA
Class II, Div. 1 & 2, Groups E,F,G

UL Listed - File E12976

SP Certified - File LR11713



HP-2



HX-2



HB-2



HGSA-500F



EZG1G



HRMO



HRD-400



KILLARK®



EZG1



VMAG40S

GUARDS				
CATALOG NUMBER	SERIES	LAMP TYPE	WATTAGE	DESCRIPTION
EZG1	EZS	HPS	50-150	Painted cast aluminum
	EZH	MH	70-250	
	EZP	MHP	150, 175, 250	
VMAG40S	EZH	MH	400	Cadmium plated steel
	EZP	MHP	320-400	



VMAGBC

Bottom Closure for
 VMAG25S or VMAG40SⓈ

Ⓢ For VMAG40S with bottom
 closure order part number
 VMAG40SBC.



VMPSD-40



EZTB



VMPA-40



HRD-400 (pictured)
HRD-400ALZ



EZCB



EZMO

REFLECTORS	
CATALOG NUMBER	DESCRIPTION
VMPSD40	Standard dome. fiberglass reinforced polyester
VMPA40	30°Angle fiberglass reinforced polyester
HRD400	Deep dome. Aluminum with white finishⓈ
HRD400ALZ	Deep dome with specular anodized finishⓈ

Ⓢ For clearance, wall mount models require standoff of 1/2" if not bottom feed;
 1-1/2" if bottom feed.

REPLACEMENT CONNECTION BLOCKS AND LAMP SOCKET	
CATALOG NUMBER	DESCRIPTION
EZTB	Female (goes in splice box)
EZCB	Male (goes in top of fixture body)
EZMO	Replacement lamp socket with gasket

