



## OUTLET BODIES



JLC-20



JALX-20



JLX-21



JALX-22



JCB



JAH-2

Class I, Div. 1 & 2, Groups C, D  
Class II, Div. 1 & 2, Groups E, F, G  
Class III

UL LISTED - File E10514

SP Certified - File LR11716  
See files for details or call Killark.

## FEATURES-SPECIFICATIONS

## Applications

To provide access to conductors for pulling, splicing, and maintenance. May be used as a fixture hanger.

## Features

- Option of blank or hub covers
- Cast mounting lugs
- Large wiring area
- Furnished with internal ground screw
- Hub covers include set screws for locking to lighting fixture stems
- JL – Cast external hubs with integral bushings
- JAL – Four drilled and tapped conduit openings in an “x” configuration (three, close-up plugs included to allow five variations from one body)
- Option of blank or hub covers

## Material/Finish

- Copper-free aluminum (less than 4/10 of 1%)
- Natural Finish

## JL OUTLET BODIES WITH COVER

| CATALOG NUMBER   |                | BOX TYPE | CONDUIT SIZE     |       | BOX ONLY VOL. CU. IN. |
|------------------|----------------|----------|------------------|-------|-----------------------|
| WITH BLANK COVER | WITH HUB COVER |          | BOX <sup>①</sup> | COVER |                       |
| JLC-10           | JLC-11         | C        | 1/2"             | 1/2"  | 12.5                  |
| —                | JLC-12         | C        | 1/2"             | 3/4"  | 12.5                  |
| JLC-20           | JLC-21         | C        | 3/4"             | 1/2"  | 12.5                  |
| —                | JLC-22         | C        | 3/4"             | 3/4"  | 12.5                  |
| JLX-10           | JLX-11         | X        | 1/2"             | 1/2"  | 12.5                  |
| —                | JLX-12         | X        | 1/2"             | 3/4"  | 12.5                  |
| JLX-20           | JLX-21         | X        | 3/4"             | 1/2"  | 12.5                  |
| —                | JLX-22         | X        | 3/4"             | 3/4"  | 12.5                  |

① To order box only omit last digit of catalog number.

## JAL OUTLET BODIES WITH COVER

| CATALOG NUMBER   |                | TYPE | CONDUIT SIZE        |       | BOX ONLY VOL. CU. IN. |
|------------------|----------------|------|---------------------|-------|-----------------------|
| WITH BLANK COVER | WITH HUB COVER |      | BOX <sup>①</sup>    | COVER |                       |
| JALX-10          | JALX-11        | X    | 1/2"                | 1/2"  | 26.5                  |
| —                | JALX-12        | X    | 1/2"                | 3/4"  | 26.5                  |
| JALX-20          | JALX-21        | X    | 3/4"                | 1/2"  | 26.5                  |
| —                | JALX-22        | X    | 3/4"                | 3/4"  | 26.5                  |
| JALX-30          | JALX-31        | X    | 1"                  | 1/2"  | 26.5                  |
| —                | JALX-32        | X    | 1"                  | 3/4"  | 26.5                  |
| JALX-40          | —              | X    | 1-1/4" <sup>②</sup> | 1/2"  | 39                    |

① To order box only omit last digit of catalog number.

② 1-1/4" for Class I, Group D.

## REPLACEMENT HUB COVER


| CATALOG NUMBER | SERIES | HUB SIZE | DEPTH   | VOLUME CU. IN. |
|----------------|--------|----------|---------|----------------|
| JH-1           | JL     | 1/2"     | 1-3/32" | 1.5            |
| JH-2           | JL     | 3/4"     | 1-3/32" | 1.5            |
| JAH-1          | JAL    | 1/2"     | 1-1/8"  | 6.5            |
| JAH-2          | JAL    | 3/4"     | 1-1/8"  | 6.5            |

## REPLACEMENT BLANK COVER


| CATALOG NUMBER | SERIES | DEPTH  | VOLUME CU. IN. |
|----------------|--------|--------|----------------|
| JCB            | JL     | 5/8"   | 1.0            |
| JABC           | JAL    | 1-1/8" | 7.5            |

## DIMENSIONS


| SERIES             | A        | B        | C      | D       | E      | F      | G        |
|--------------------|----------|----------|--------|---------|--------|--------|----------|
| JL 1/2", 3/4"      | 1-15/16" | 11/16"   | 3-1/4" | 4-7/32" | 2-3/8" | 5-1/8" | 3-1/4"   |
| JAL 1/2", 3/4", 1" | 2-3/8"   | 1-5/32"  | 4-3/4" | 5-1/4"  | 4-1/8" | 5-7/8" | 4-3/4"   |
| JAL 1-1/4"         | 3-3/16"  | 1-17/32" | 4-5/8" | 5-1/4"  | 4-1/8" | 5-7/8" | 4-13/16" |

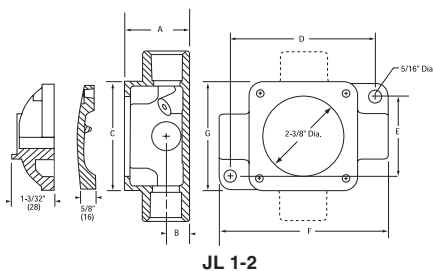

JL 1-2

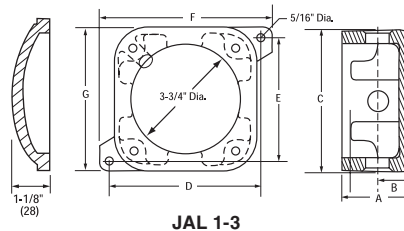

JAL 1-3

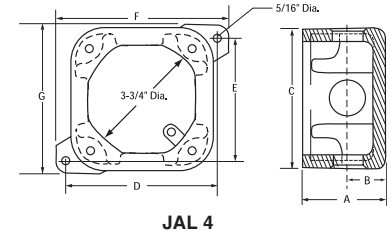

JAL 4