



Typical installation using conduit hardware.

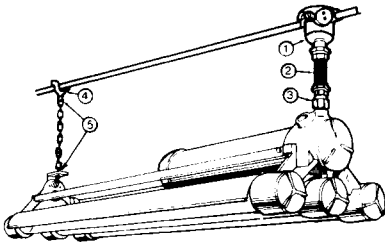

Dummy (non-powered) end lowers for relamping clearance, which is required when fixtures are mounted in close proximity. Flexible mounting provides free swing and impact protection.

1. Splice Box/Fixture Hanger (HXB)
2. Flexible Pendant Hanger (EKJ)
3. Union (GUM)
4. Rigid Support Saddle Bracket (KFHS)
5. Support Hook (KEFHM)


Note: Leave extra links to support fixture in relamping position. Chain furnished by others.

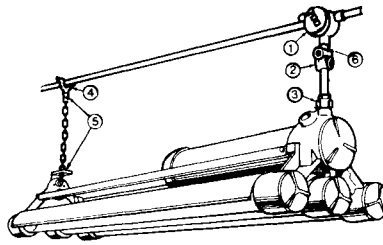

Dummy (non-powered) end lowers for relamping clearance, which is required when fixtures are mounted in close proximity.

1. Splice Box/Fixture Hanger (XFH)
2. Swivel Hanger (KESD)
3. Union (GUM)
4. Rigid Support Saddle Bracket (KFHS)
5. Support Hook (KEFHM)
6. 3/4" Rigid Threaded Nipple

Note: Leave extra links to support fixture in relamping position. Chain furnished by others.

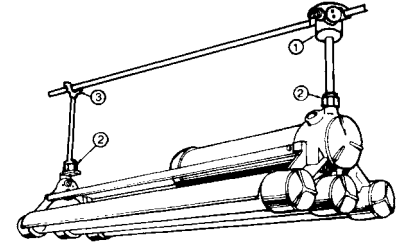


Rigid mounted—for installations where relamping can be accomplished without lowering dummy end.

1. Splice Box/Fixture Hanger (HXB)
2. Union (GUM)
3. Rigid Support Saddle Bracket (KFHS)

For wall mounting, use securely fastened 3/4" pipe 6" or less in length. Floor flange (furnished by others) recommended for dummy end as well as chain or cable providing vertical strain relief from above fixture. Chain furnished by others.

MOUNTING HARDWARE			
CATALOG NUMBER	HUB SIZE	LENGTH	DESCRIPTION
HXB-12	1/2"	—	HXB SERIES Splice Box/ 3/4" Fixture Hanger
HXB-22	3/4"	—	
EKJ-24	3/4"	4	EKJ SERIES Flexible Pendant Hanger
EKJ-26	3/4"	6	
EKJ-28	3/4"	8	
EKJ-210	3/4"	10	
EKJ-212	3/4"	12	
EKJ-215	3/4"	15	
EKJ-218	3/4"	18	
GUM-2	3/4"	—	GU SERIES Male Union

MOUNTING HARDWARE		
CATALOG NUMBER	HUB SIZE	DESCRIPTION
XFH-22	3/4"	XFH SERIES Splice box/fixture hanger
KESD-75	3/4"	KESD SERIES Swivel Hanger 15° swivel drop from center and full 360° free swing
KFHS-5075	3/4"	KFHS SERIES Rigid support saddle bracket for fluorescent fixtures (dummy end) Will support 350 lbs. and straddle Max. 1-1/4" conduit
KEFHM-75	3/4"	KEFHM SERIES Safety support hook with 3/4" male end For dummy end of fixture Will support 200 lbs. screw closed 3/8" jaw opening
HFX-SC	—	HFX SERIES Safety chain (36" length plated steel), standard on 4-tube fixture

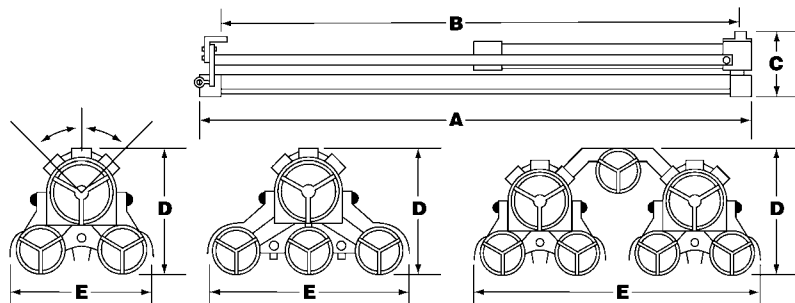

HFX DIMENSIONS								
HFX MODEL	CONDUIT SIZE	DIMENSIONS					NET WEIGHT	
		A	B	C	D	E		
Nominal 2'	2 Tubes 3/4-14 NPT	28-15/16" (735)	24-3/8" (619)	9-3/32" (231)	9-3/32" (231)	11" (279)	36.0 Lbs.	
Nominal 4'	2 Tubes 3/4-14 NPT	52-13/16" (1367)	48-3/8" (1229)	9-3/32" (231)	9-3/32" (231)	11" (279)	47.7 Lbs.	
Nominal 4'	3 Tubes 3/4-14 NPT	52-13/16" (1367)	48-3/8" (1229)	9-3/32" (231)	9-3/32" (231)	15-5/8" (397)	63.0 Lbs.	
Nominal 4'	4 Tubes 3/4-14 NPT	52-13/16" (1367)	48-3/8" (1229)	9-3/32" (231)	10-1/8" (257)	23" (584)	99.9 Lbs.	

