



KFS-6G
Steel Slipfitter
(includes bolts)



K4040G
Steel Wall/Pole Bracket



KFCBG
Cross Arm Fitting

Class I Div. 2, Groups A,B,C,D*
AEx nR/Ex nR**
Class I Zone 2, IIC, IIB, IIA*

UL 1598 HID Marine for Wet Locations
 UL 844 Hazardous Locations

CSA C22.2 9.9-9.6 General Requirements
 CSA C22.2 137-M1981 Hazardous Locations
 CSA Enclosure type IP66/67

ABS Type Approval for Shipboard Use

* Consult temperature data table on next page to determine application suitability.

FEATURES-SPECIFICATIONS

MARICARD®

Applications

- Offshore production platforms
- Refineries
- Offshore drilling rigs and barges
- Ocean-going vessels
- Commercial fishing vessels
- Ports, wharfs and jetties
- Waste water and sewage treatment facilities
- Any type of washdown, corrosive, abrasive, or dirty environment

Features and Benefits

- Type 316 Stainless Steel Housing. 16-gauge housing ensures low corrosion and long life, reducing maintenance costs
- Rugged quick-release 316 SS Lens Latches. No hardware seizing on disassembly saves maintenance time and money. Only tool needed is a screwdriver
- 316 SS Safety Lens Door Chains. Enables hands-free safe re-lamping
- 316 SS Mounting Yoke Reliable and safe installation
- Highly efficient photometrics and excellent asymmetrical distribution. Photometrics above 85%. Minimizes the number of required fixtures to deliver desired light levels. Saves in energy costs
- Hot-dipped Galvanized Steel Mounting Accessories. Corrosion resistant in marine and corrosive environments, assuring reliable installation

- 316 SS 3/4" Conduit Hub. Maintains grounding continuity. Watertight seal. Corrosion resistant
- Silicone Gasketed Lens Door Frame. Provides watertight seal, protecting interior from moisture and corrosives

KFSS STAINLESS STEEL FLOOD LIGHTS

CATALOG NUMBER	LAMP TYPE AND CIRCUIT	VOLTAGE ^① Ⓥ	BEAM SPREAD H° X V°
KFS150SS	150 HPS	120/208/240/277 @60Hz	6 (118) x 6 (118)
KFS156SS	S-55	120/277/347 @60 Hz	
KFS250SS	250 HPS	120/208/240/277 @60Hz	6 (118) x 6 (118)
KFS256SS	S-50	120/277/347 @60 Hz	
KFS400SS	400 HPS	120/208/240/277 @60Hz	6 (118) x 6 (118)
KFS406SS	S-51	120/277/347 @60 Hz	
KFH250SS	250 MH ^②	120/208/240/277 @60Hz	6 (118) x 6 (118)
KFH256SS	M-58	120/277/347 @60 Hz	
KFP250SS	250 MHP ^③	120/208/240/277 @60Hz	6 (118) x 6 (118)
KFP256SS	M-138	120/277/347 @60 Hz	
KFH400SS	400 MH ^②	120/208/240/277 @60Hz	6 (118) x 6 (118)
KFH406SS	M-59	120/277/347 @60 Hz	
KFP400SS	400 MHP ^③	120/208/240/277 @60Hz	6 (118) x 6 (118)
KFP406SS	M-135	120/277/347 @60 Hz	

^① Voltage: 6th character in the catalog number denotes voltage. See "Catalog Number Logic" for details; e.g. **KFS155SS** = 480 Volt 60Hz.; **KFH408SS**=240V 50Hz.

^② Mercury Vapor Lamps of the same wattage may be used if desired.


^③ Use a Pulse Start Metal Halide Lamp rated for Horizontal Position.

Ⓥ Consult factory for available lamp and voltage combinations.

KFSS ACCESSORIES

CATALOG NUMBER	DESCRIPTION
KFS-6G	Steel slipfitter for 2" pipe (2-3/8" O.D.) tenon. Hot-dipped galvanized (bolts included)
K4040G	Steel wall/pole bracket. Hot-dipped galvanized (bolts included)
KFCBG	Cross arm fitting for horizontal trunnion. Hot-dipped galvanized (bolts included)

Catalog Number Logic

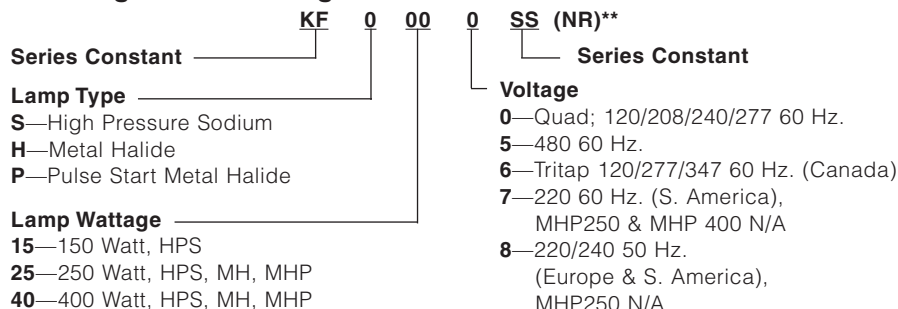

**Restricted Breathing option-see next page.



KILLARK®