



KP Series 60 Amp Plug - E Type - 2P 3W Circuit - Grommet Range 0.875-1.125 Inch - 115/230VAC 60Hz

By Killark
Catalog # [KP-603E45](#)

KP Series - Aluminum 60 Amp Plug - E Type - 2W 3P Circuit - Grommet Range 0.875-1.125 Inch - 115/230VAC 60Hz

Features

- Suitable where a connection is required for portable or movable equipment such as tools, motors, hand lights, etc.
- Solder Terminations for sure connection
- Copper free aluminum housing
- Delayed action contacts ensure safe interconnect
- Wide range of grommet openings
- Extra long grounding pin makes contact first and breaks contact last

Application


KP Series plugs are suitable: in hazardous locations due to the presence of flammable vapors or gases;where a heavy duty plug and receptacle is necessary;where a connection is required for portable or movable equipment such as tools, motors, hand lights

Specifications

EU RoHS Indicator	Contact Manufacturer
Hazardous Rating(s)	• Class I, Divisions 1 & 2, Groups C, D • Class I, Zones 1 & 2, Groups IIB,IIA
Nema Rating	3, 4, 4X, 7(B, C, D), 9(F, G)
Buy America(n) Qualified	Contact Manufacturer

Conductor

Number Of Wires	3
Wire Size	#8 AWG to #2 AWG
Number Of Poles	2

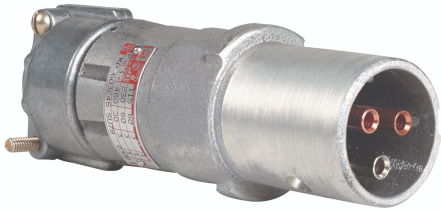

Current

Amperage Rating	60 A
-----------------	------

Dimensions

Length	11.13 in
Gross Weight with Packaging	2
Width	4.63 in
Height	3.5 in
Dimensions	11.13 in x 4.63 in x 3.5 in

General

Series	KP Series
Color	Gray
Receptacle Type	Delayed Action
Type	Pin & Sleeve
Material	Aluminum, Copper Free (less than 4/10 of 1%)
UPC	783936370118

Logistics

Carton Quantity	5
-----------------	---

Operational

Operating Cycles	10,000 operations
------------------	-------------------

Product Assets

- [Catalog \[English\]](#)
[Installation Manual \[English\]](#)