



KR Series - 60 Amp Receptacle With Enclosure - Includes 3Close-Up Plugs - 2P 3W Circuit - 115/230VAC At 60Hz - Hub Size 1 Inch

By Killark
Catalog # [KRJX-3603](#)

KR Series - Aluminum 60 Amp Receptacle With Enclosure - Includes 3Close-Up Plugs - 2W 3P Circuit - 115/230VAC At 60Hz - Hub Size 1 Inch

Features

- Suitable where a connection is required for portable or movable equipment such as tools, motors, hand lights, etc.
- Wire leads for termination
- Factory sealed
- Copper free aluminum housing
- Straight or angle type back boxes
- Delayed action contacts ensure safe interconnect
- Extra long grounding pin makes contact first and breaks contact last

Application


KR Series receptacles are suitable: in hazardous locations due to the presence of flammable vapors or gases;where a heavy duty plug and receptacle is necessary;where a connection is required for portable or movable equipment such as tools, motors, hand

Specifications

Hazardous Rating(s)	• Class I, Divisions 1 & 2, Groups C, D • Class I, Zones 1 & 2, Groups IIB,IIA
EU RoHS Indicator	Contact Manufacturer
Nema Rating	7 (C, D)
Buy America(n) Qualified	Contact Manufacturer

Conductor

Number Of Wires	3
Number Of Poles	2

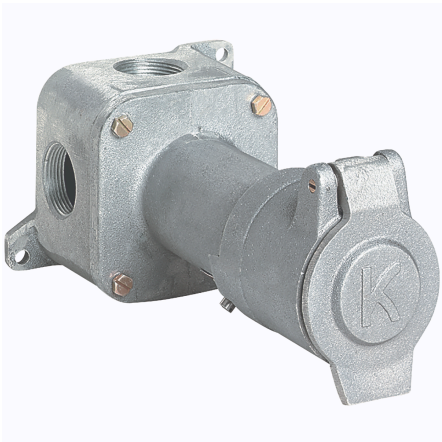

Configuration

Hub Pattern	Feed-Thru
-------------	-----------

Current

Amperage Rating	60 A
-----------------	------

Dimensions

Gross Weight with Packaging	6.6
Hub Size	1"
Width	7 in
Height	5.63 in
Length	15.75 in
Dimensions	15.75 in x 7 in x 5.63 in

General

Receptacle Type	Delayed Action
Type	Pin & Sleeve
Series	KR Series
Material	Aluminum, Copper Free (less than 4/10 of 1%)
UPC	783936391564
Color	Gray

Logistics

Factory Sealed	Factory Sealed
----------------	----------------

Product Assets

[Catalog \[English\]](#)