



LZ SERIES – ORDERING INFORMATION & TECHNICAL DATA

ORDERING INFORMATION AND AMBIENT SUITABILITY										C1D2 ^⑤		C2D1 ^⑤ LZ2NL GRPS. FG LZ2SL GRPS. FFG		C1Z2 ^⑤ AEx nA Ex nA	
CATALOG NUMBER ^{①②}				WATTAGE	LENGTH/ PCBS ^③	VOLTAGE	AMPS ^④	DELIVERED LUMENS	LUMENS PER WATT	40C	55C	40C	55C	40C	55C
FIBERGLASS	(WT.)	STAINLESS	(WT.)												
LZ2NL1830	12	LZ2SL1830	13	18	2' / 2	120-277VAC	0.15 - 0.06	2557	150	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL2830	12	LZ2SL2830	13	28	2' / 2	120-277VAC	0.23 - 0.10	3775	144	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL4530	12	LZ2SL4530	13	45	2' / 2	120-277VAC	0.38 - 0.16	5562	137	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL6030	14	LZ2SL6030	15	60	2' / 3	120-277VAC	0.50 - 0.22	7618	132	T4A	-	≤ 135°C	-	T4	-
LZ2NL3430	23	LZ2SL3430	24	34	4' / 4	120-277VAC	0.28 - 0.12	5075	149	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL5530	23	LZ2SL5530	24	55	4' / 4	120-277VAC	0.46 - 0.20	7577	144	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL8030	23	LZ2SL8030	24	80	4' / 4	120-277VAC	0.67 - 0.29	11140	137	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL12030	25	LZ2SL12030	26	120	4' / 6	120-277VAC	1.00 - 0.43	16010	132	T4A	-	≤ 135°C	-	T4	-

① See logic for additional voltages and options

② Shipping weights approximate


③ Length is nominal, see dimensional detail. PCB noted quantity used per fixture wattage

④ Amperage measured at 120VAC; 277VAC calculated


⑤ Use 60°C Minimum Supply Wire at 40°C Ambient except 120W; 75°C Wire at 55°C Ambient and all 120W

LED LUMEN LIFE	L70 CALCULATED	L70 TM-21**
40°C Ambient	212,000 Hours to 70% Initial	60,600 Hours Official Reported
55°C Ambient	99,600 Hours to 70% Initial	60,400 Hours Official Reported

Dimensions LZ2NL Series

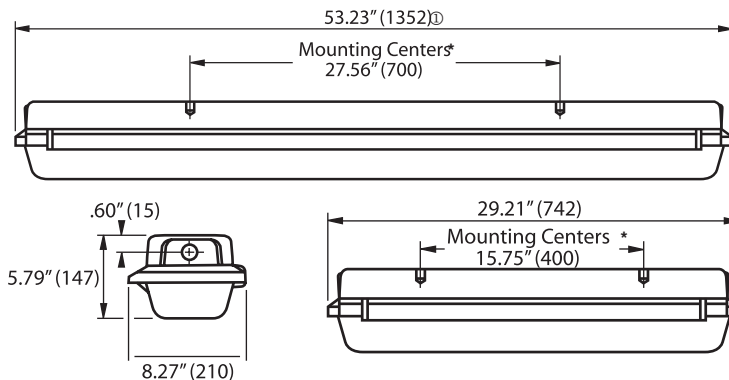

Dimensions LZ2SL Series

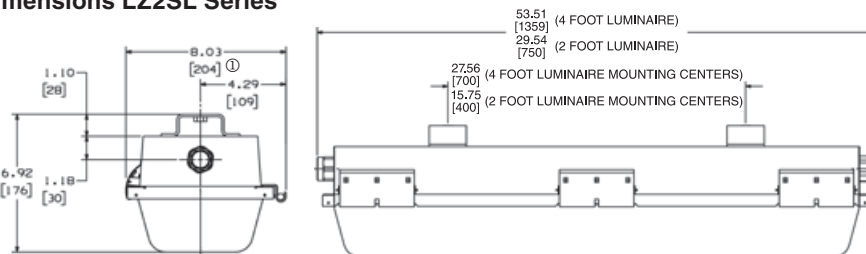

REPLACEMENT PARTS:

LZ2N4LENS	4' Lens only LZ2NL/LZ2SL
LZ2N2LENS	2' Lens only LZ2NL/LZ2SL
LZ2N4BAR	4' Locking Bar only LZ2NL
LZ2N2BAR	2' Locking Bar only LZ2NL
LZ2S-LATCH	Latch and Spring LZ2SL

*Mounting Centers are 1/4-20" tapped for user all thread rod or below accessories.

① Dimensions in () are millimeters.

② Product accessories have hardware for attachment to fixture; hardware to attach to wall/ceiling F.B.O.


NOTE: Eyebolts are 316 Series, brackets are 300 Series Stainless Steel.

Mounting Accessories

Wall Bracket Set^②


Part Number LZWB

Stainless Steel (natural finish)

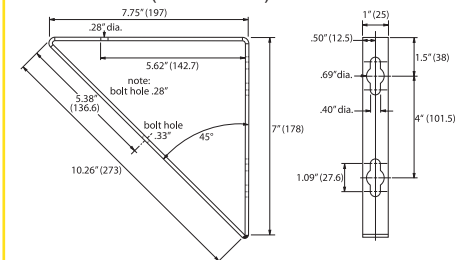Adjustable Wall Bracket Set^②


Part Number LZAB

Stainless Steel bracket with ceramic coated pivot bolt

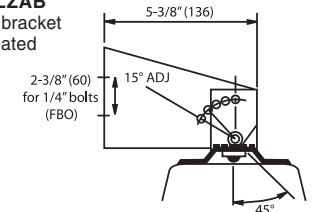Ceiling Bracket Set^②

Part Number LZCB


Stainless Steel (natural finish)

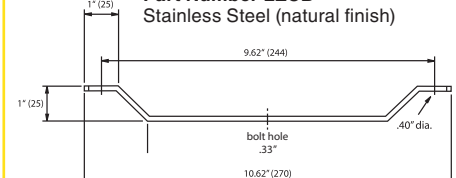

Eyebolt Set

Part Number LZEB

Stainless Steel bolt with lockwasher & nut (natural finish)

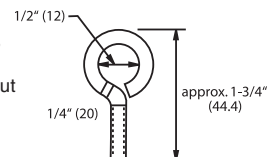

Suspension Chains (2 required)

Part Number HFX-SC

36" length plated steel chain with snap link ends For use with LZEB