





ACCESSORIES AND REPLACEMENT PARTS

ACCESSORIES AND REPLACEMENT PARTS: ① ②	
LAL-SB	Swivel Bracket Set w/ Adjustable Height; includes 5/16" bolts/nuts/lock-washers for attachment to LAL(C) "slots"; can also be attached to end cap mounting feet with FBO bolts.
LZCB	Ceiling Bracket Set with Stainless Steel Bolts to attach to LAL(C) "slots"
LZWB	Wall Bracket Set with Stainless Steel Bolts to attach to LAL(C) "slots"
LAL-BC	Steel/malleable Iron with Zinc electroplate for corrosion resistance; includes Stainless Steel Bolts to attach to LAL(C) "slots"
LAL-EB	Eyebolt Set with Stainless Steel Bolts to attach to LAL(C) "slots"
LAL-SSC	4' Stainless Safety Cable Loop/Loop Spring Safety Carabiner Hook
LALG	Stainless Guard for 1 LAL Lens, order two for 2 lens models
LALCG	LALC Stainless Guard
LAL-LENSCLR	Single Clear Lens with Gasket for LAL Series
LAL-LENSDIF	Single Diffuse Lens with Gasket for LAL Series
LALC-LENSCLR	Single Clear Lens with Gasket for LALC Series
LALC-LENSDIF	Single Diffuse Lens with Gasket for LALC Series
LAL-RIG-CB	Rig Mounting Style Ceiling Bracket
LAL-RIG-WB	Rig Mounting Style Wall Bracket

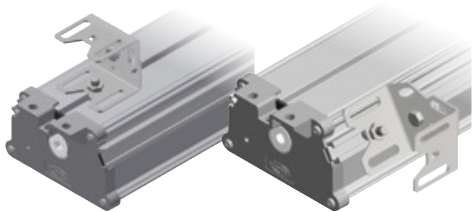


LAL-SB on Center Slot





LAL-SB on 45° Slot

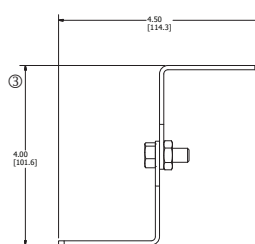



LAL-SB Dimensions – extended shown

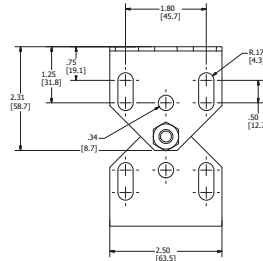

③ Un-extended height 3.25" (82.6)

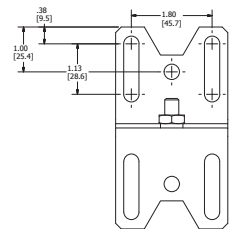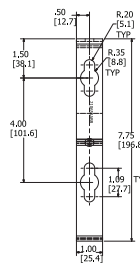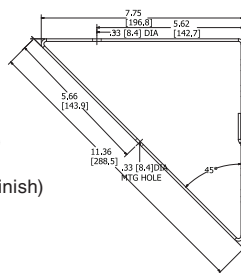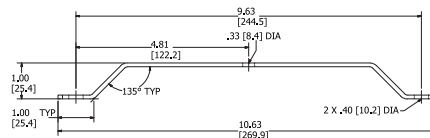
Wall Bracket Set②
Part Number LZWB
 Stainless Steel (natural finish)

Ceiling Bracket Set②
Part Number LZCB
 Stainless Steel (natural finish)

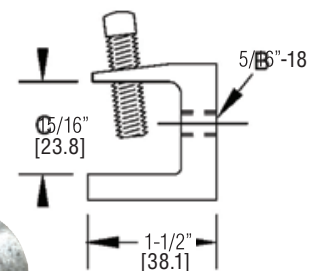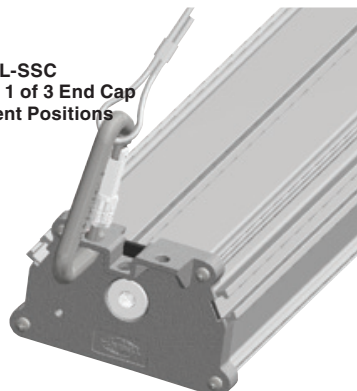
LAL-SSC Safety Cable

LAL-SSC
 Attached to 1 of 3 End Cap
 Attachment Positions


LAL-BC Beam Clamp

① Dimensions in () are millimeters.

② Product accessories have hardware for attachment to fixture; hardware to attach to wall/ceiling F.B.O.



LZ SERIES – ORDERING INFORMATION & TECHNICAL DATA

ORDERING INFORMATION AND AMBIENT SUITABILITY										C1D2 ^⑤		C2D1 ^⑤ LZ2NL GRPS. FG LZ2SL GRPS. FG		C1Z2 ^⑤ AEx nA Ex nA	
CATALOG NUMBER ^{①②}				WATTAGE	LENGTH/ PCBS ^③	VOLTAGE	AMPS ^④	DELIVERED LUMENS	LUMENS PER WATT	40C	55C	40C	55C	40C	55C
FIBERGLASS	(WT.)	STAINLESS	(WT.)												
LZ2NL1830	12	LZ2SL1830	13	18	2' / 2	120-277VAC	0.15 - 0.06	2557	150	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL2830	12	LZ2SL2830	13	28	2' / 2	120-277VAC	0.23 - 0.10	3775	144	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL4530	12	LZ2SL4530	13	45	2' / 2	120-277VAC	0.38 - 0.16	5562	137	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL6030	14	LZ2SL6030	15	60	2' / 3	120-277VAC	0.50 - 0.22	7618	132	T4A	-	≤ 135°C	-	T4	-
LZ2NL3430	23	LZ2SL3430	24	34	4' / 4	120-277VAC	0.28 - 0.12	5075	149	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL5530	23	LZ2SL5530	24	55	4' / 4	120-277VAC	0.46 - 0.20	7577	144	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL8030	23	LZ2SL8030	24	80	4' / 4	120-277VAC	0.67 - 0.29	11140	137	T5	T4A	≤ 135°C	≤ 135°C	T5	T4
LZ2NL12030	25	LZ2SL12030	26	120	4' / 6	120-277VAC	1.00 - 0.43	16010	132	T4A	-	≤ 135°C	-	T4	-

① See logic for additional voltages and options

② Shipping weights approximate

③ Length is nominal, see dimensional detail. PCB noted quantity used per fixture wattage


④ Amperage measured at 120VAC; 277VAC calculated

⑤ Use 60°C Minimum Supply Wire at 40°C Ambient except 120W; 75°C Wire at 55°C Ambient and all 120W


LED LUMEN LIFE	L70 CALCULATED	L70 TM-21**
40°C Ambient	212,000 Hours to 70% Initial	60,600 Hours Official Reported
55°C Ambient	99,600 Hours to 70% Initial	60,400 Hours Official Reported

** TM-21 based values require very long duration testing. IES TM-21 "official reported" is based on at least 10,000 hours of LED chip manufacturer's LM-80 Testing at printing.

Dimensions LZ2NL Series

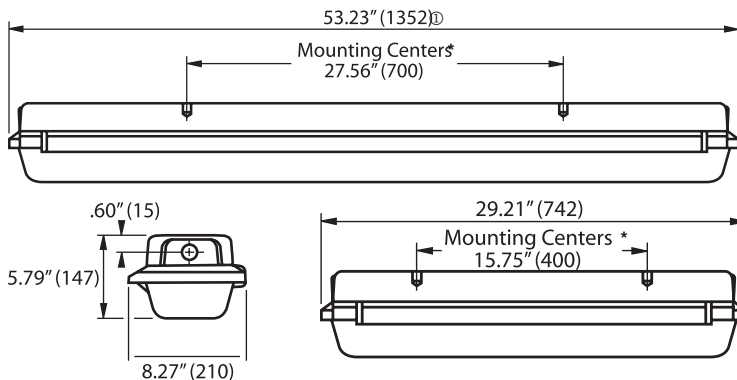

Dimensions LZ2SL Series

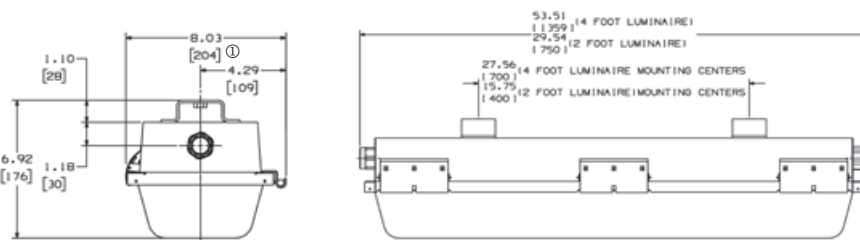

REPLACEMENT PARTS:

LZ2N4LENS	4' Lens only LZ2NL/LZ2SL
LZ2N2LENS	2' Lens only LZ2NL/LZ2SL
LZ2N4BAR	4' Locking Bar only LZ2NL
LZ2N2BAR	2' Locking Bar only LZ2NL
LZ2S-LATCH	Latch and Spring LZ2SL

*Mounting Centers are 1/4-20" tapped for user all thread rod or below accessories.

① Dimensions in () are millimeters.


② Product accessories have hardware for attachment to fixture; hardware to attach to wall/ceiling F.B.O.

NOTE: Eyebolts are 316 Series, brackets are 300 Series Stainless Steel.

Mounting Accessories
For All LZ2NL & LZ2SL SeriesWall Bracket Set^②


Part Number LZWB

Stainless Steel (natural finish)

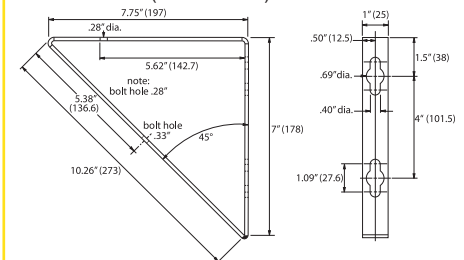Adjustable Wall Bracket Set^②


Part Number LZAB

Stainless Steel bracket with ceramic coated pivot bolt

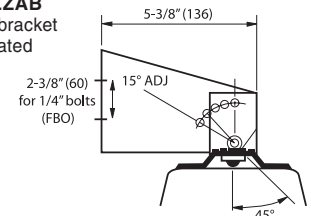Ceiling Bracket Set^②

Part Number LZCB


Stainless Steel (natural finish)

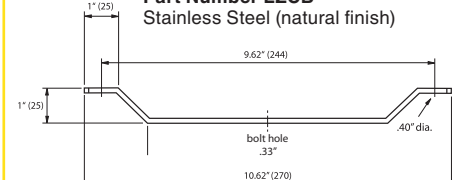

Eyebolt Set

Part Number LZEB

Stainless Steel bolt with lockwasher & nut (natural finish)

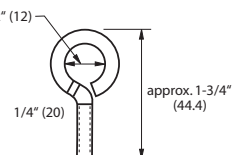

Suspension Chains (2 required)

Part Number HFX-SC




36" length plated steel chain with snap link ends For use with LZEB



LZ2N, LZ2S, LZ2NE, LZ2SE SERIES


DIMENSIONS, ACCESSORIES

Dimensions LZ2N, LZ2NE Series

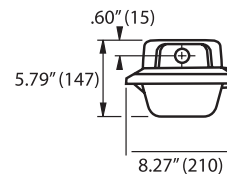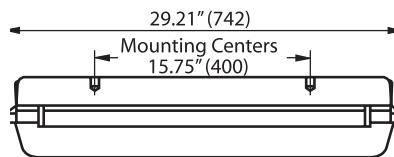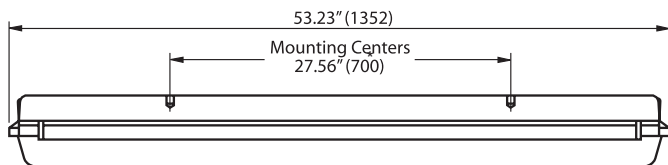


* Mounting Centers are 1/4-20" tapped for user all thread rod or below accessories.


Mounting Accessories for all LZ2N, LZ2S Series

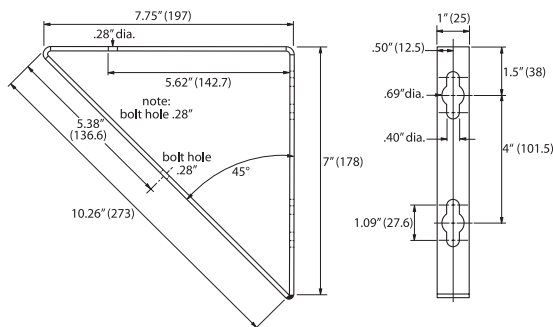


Wall Bracket Set^②
Part Number LZWB
Stainless Steel (natural finish)

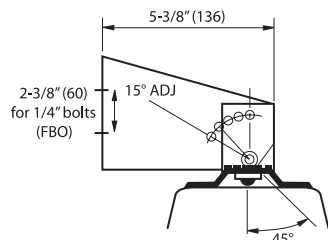

Adjustable Wall Bracket Set^②
Part Number LZAB
Stainless Steel bracket with ceramic coated pivot bolt

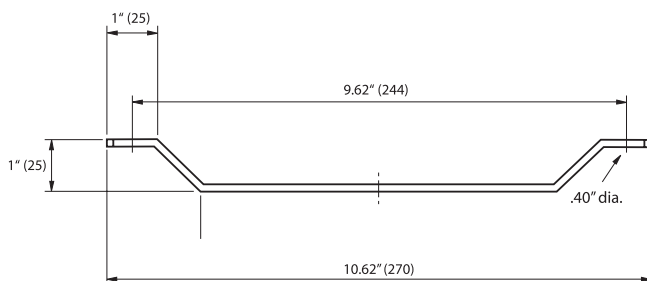

Ceiling Bracket Set^②
Part Number LZCB
Stainless Steel (natural finish)

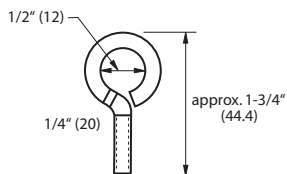

Eyebolt Set
Part Number LZEB
Stainless Steel bolt with lockwasher & nut (natural finish)

Suspension Chains (2 required)

Part Number HFX-SC

36" length plated steel chain with snap link ends. For use with LZEB

① Dimensions in () are millimeters.

② Product accessories have hardware for attachment to fixture; hardware to attach to wall/ceiling F.B.O.

NOTE: Eyebolts are 316 Series, brackets are 300 Series Stainless Steel.

REPLACEMENT PARTS:

LZ2N4LENS	4' Lens only LZ2N/LZ2S
LZ2N2LENS	2' Lens only LZ2N/LZ2S
LZ2N4BAR	4' Locking Bar only LZ2N
LZ2N2BAR	2' Locking Bar only LZ2N
LZ2S-LATCH	Latch and Spring