

FITTINGS

PCC/ECC/RACC SERIES



CONDUIT CLAMPS



PARALLEL TYPE



EDGE TYPE



RIGHT ANGLE TYPE

CSPI Listed - File E213669

FEATURES-SPECIFICATIONS

Applications

- Designed to secure rigid metal conduit, IMC or EMT across, parallel or perpendicular to channel, beam and angle supports.


Features

- Three styles meet every installation need
- Heavy duty U-bolts, hex bolts and hex nuts
- Capable of supporting heavy loads

Material/Finish

- Malleable iron (hot dipped galvanized) with steel U-bolts and nuts (mechanically galvanized).

Dimensions

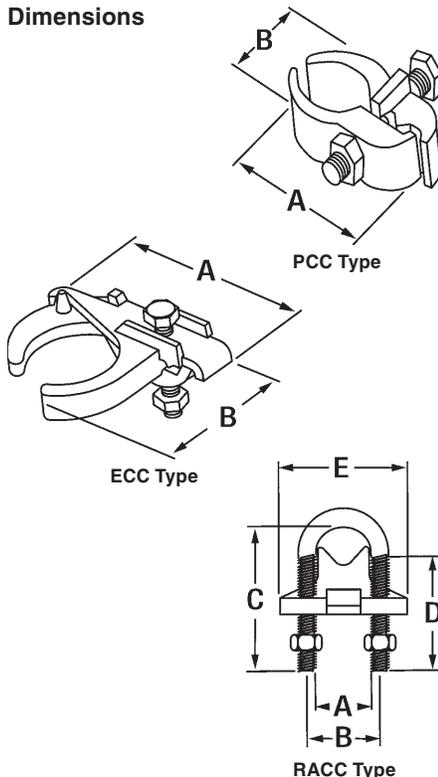

| PCC PARALLEL TYPE CLAMPS | | | |
|--------------------------|--------------|-------------------|-------------------|
| CATALOG NUMBER | CONDUIT SIZE | A | B |
| PCC050 | 1/2" | 2-7/8" (73) | 1-7/16" (36) |
| PCC075 | 3/4" | 3-1/16" (78) | 1-11/16" (43) |
| PCC100 | 1" | 3-1/4" (83) | 2" (51) |
| PCC125 | 1-1/4" | 3-5/8" (92) | 2-1/8" (53) |
| PCC150 | 1-1/2" | 3-7/8" (98) | 2-3/16" (56) |
| PCC200 | 2" | 4-5/8" (117) | 2-7/8" (73) |
| PCC250 | 2-1/2" | 5-1/4" (133) | 3-1/4" (83) |
| PCC300 | 3" | 5-1/8" (149) | 3-1/8" (98) |
| PCC350 | 3-1/2" | 6-5/16" (160) | 4-5/16" (110) |
| PCC400 | 4" | 6-13/16" (173) | 4-13/16" (122) |

| ECC EDGE TYPE CLAMPS | | | |
|----------------------|--------------|-------------------|------------------|
| CATALOG NUMBER | CONDUIT SIZE | A | B |
| ECC050 | 1/2" | 2-13/16" (71) | 2-1/8" (54) |
| ECC075 | 3/4" | 2-15/16" (75) | 2-3/8" (60) |
| ECC100 | 1" | 3-1/16" (78) | 2-5/8" (67) |
| ECC125 | 1-1/4" | 3-1/16" (78) | 3-1/16" (78) |
| ECC150 | 1-1/2" | 3-15/16" (100) | 3-1/4" (83) |
| ECC200 | 2" | 4-1/2" (114) | 4-1/16" (103) |
| ECC250 | 2-1/2" | 5-1/8" (130) | 4-5/8" (117) |
| ECC300 | 3" | 5-3/4" (146) | 5-1/4" (133) |

| RACC RIGHT ANGLE TYPE CLAMPS | | | | | | |
|------------------------------|--------------|-------------------|------------------|-------------------|------------------|------------------|
| CATALOG NUMBER | CONDUIT SIZE | A | B | C | D | E |
| RACC050 | 1/2" | 1" (25) | 1-1/4" (32) | 2-1/2" (64) | 1-13/16" (46) | 2-1/16" (52) |
| RACC075 | 3/4" | 1-1/8" (29) | 1-3/8" (35) | 2-13/16" (72) | 1-13/16" (46) | 2-1/4" (57) |
| RACC100 | 1" | 1-3/8" (35) | 1-5/8" (41) | 3-1/16" (78) | 1-13/16" (46) | 2-9/16" (65) |
| RACC125 | 1-1/4" | 1-3/4" (44) | 2" (51) | 3-3/16" (81) | 1-13/16" (46) | 2-7/8" (73) |
| RACC150 | 1-1/2" | 2" (51) | 2-3/8" (60) | 3-1/2" (89) | 1-13/16" (46) | 3-1/4" (83) |
| RACC200 | 2" | 2-1/2" (64) | 2-1/2" (64) | 4-1/2" (114) | 2-5/8" (67) | 4-1/16" (103) |
| RACC250 | 2-1/2" | 2-1/2" (64) | 3" (76) | 3-1/4" (83) | 4-7/8" (124) | 2-5/8" (67) |
| RACC300 | 3" | 3-5/8" (92) | 3-7/8" (98) | 5-3/8" (137) | 2-5/8" (67) | 5-1/8" (130) |
| RACC350 | 3-1/2" | 4-1/16" (103) | 4-9/16" (116) | 5-7/8" (149) | 2-5/8" (67) | 5-5/8" (143) |
| RACC400 | 4" | 4-11/16" (119) | 5-1/16" (129) | 6-11/16" (170) | 2-5/8" (67) | 6-1/8" (156) |