



TWOC Type



TWOLB Type



LISTED - FILE E3397



CERTIFIED - FILE LR11852

See files for details or call Killark.

FEATURES-SPECIFICATIONS

Applications

- For use with E.M.T conduit thin wall
- To make bends in the conduit system
- Connect conduit sections
- Provide access to the conduit system
- As a pulling outlet
- Provide openings for taps or splices

Features

- Easy installation (screwdriver is only tool required)
- Complete selection of sizes and hub configurations

Material/Finish

Copper-free Aluminum



(less than 4/10 of 1%)

- Electrostatically applied powder coating
- Aluminum and steel/iron type 5 covers and gaskets can be used with TW series bodies. See page F23



TWO C TYPE CONDUIT BODY									
CATALOG NUMBER	HUB SIZE	DIMENSIONS							VOLUME CU. IN.
		A	B	C	D	E	F	G	
TWOC-1	1/2"	5-3/16" (132)	15/16" (24)	1-5/16" (33)	1-1/8" (29)	3-1/2" (89)	—	5/8" (16)	4.0
TWOC-2	3/4"	5-3/4" (146)	1-1/2" (38)	2-5/16" (59)	1-3/16" (30)	4-1/8" (105)	—	3/4" (19)	7.0
TWOC-3	1"	7-1/16" (179)	1-3/4" (44)	1-3/4" (44)	1-1/2" (38)	4-7/8" (124)	—	7/8" (22)	12.0

TWO LB TYPE CONDUIT BODY									
CATALOG NUMBER	HUB SIZE	DIMENSIONS							VOLUME CU. IN.
		A	B	C	D	E	F	G	
TWOLB-1	1/2"	4-1/2" (114)	1-5/16" (33)	2-9/32" (58)	1-1/8" (29)	3-1/2" (89)	3-5/32" (80)	5/8" (16)	4.0
TWOLB-2	3/4"	5-3/16" (132)	1-1/2" (38)	2-9/16" (41)	1-5/16" (33)	4-1/8" (105)	3-3/4" (95)	3/4" (19)	7.0
TWOLB-3	1"	6-1/4" (159)	1-3/4" (44)	3-3/32" (79)	1-9/16" (40)	4-7/8" (124)	4-1/2" (114)	15/16" (24)	12.0
TWOLB-4	1-1/4"	8-1/16" (205)	2-1/2" (64)	3-3/4" (95)	2-1/4" (51)	6-1/2" (165)	6-1/16" (154)	1-3/16" (30)	32.0
TWOLB-5	1-1/2"	8-1/16" (205)	2-1/2" (64)	4" (102)	2-1/4" (51)	6-1/2" (165)	6-1/16" (154)	1-3/8" (32)	36.0
TWOLB-6	2"	10" (283)	3-1/8" (79)	4-11/16" (119)	2-7/8" (73)	8-9/16" (217)	8-1/8" (206)	1-5/8" (38)	70.0
TWOLB-7	2-1/2"	13" (330)	4-7/16" (113)	6-1/4" (159)	4-1/16" (103)	11-1/4" (286)	10-1/2" (267)	1-13/16" (54)	142.0
TWOLB-8	3"	13" (330)	4-7/16" (113)	6-1/4" (159)	4-1/16" (103)	11-1/4" (286)	10-1/2" (267)	2-3/16" (54)	173.0
TWOLB-9	3-1/2"	15-3/4" (400)	5-1/2" (140)	7-15/32" (190)	5-3/16" (132)	13-3/4" (349)	13-1/4" (337)	2-1/2" (67)	292.0
TWOLB-0	4"	15-3/4" (400)	5-1/2" (140)	7-15/32" (190)	5-3/16" (132)	13-3/4" (349)	13-1/4" (337)	2-3/4" (67)	324.0

Dimensions

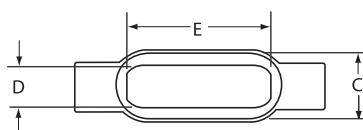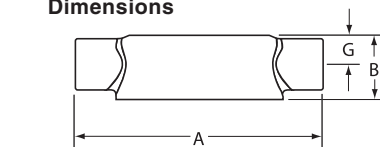

C Type

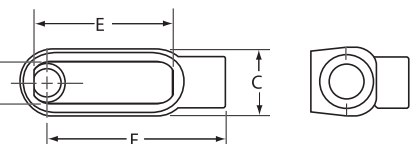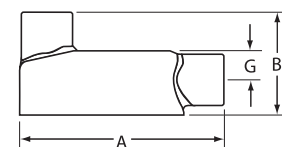

LB Type



KILLARK®