



UGRS / UGRGF RECEPTACLES



Breach Cap Model

Flip Cap

Class I, Div. 2, Groups B, C, D
Class I, Zone 2, Groups IIB+H₂, IIA
Class II, Div. 1 & 2, Groups F, G
Class III
NEMA 3, 4X

Certified File No. LR14667③



UGRGF

Class I, Div. 1 & 2, Groups C, D
Class I, Zones 1 & 2, Groups IIB, IIA
Class II, Div. 1 & 2, Groups F, G
Class III
NEMA 3, 7 (C, D) 9 (F, G)


Certified LR11714
 See files for details or call Killark.

FEATURES-SPECIFICATIONS

Dimensions

ACCEPTOR® SQUARE RECEPTACLE

UGRS Receptacles utilize VERSAMATE® 30A mounting boxes and are designed to provide **“ROTATABLE” design enables cover hinge location to be in most convenient position for application.** May also be utilized with sheet metal enclosures which contain no arcing devices.

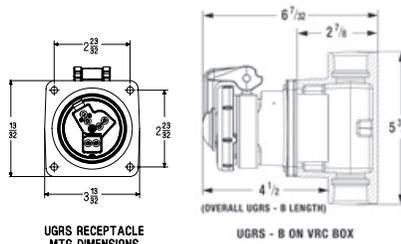

Breach Cap model shown.
 Flip Cap model dimensions are similar

GFI PROTECTED RECEPTACLE

Utilizes FXS GFI and ACCEPTOR® receptacle to interrupt a circuit, when a ground fault is detected on equipment which may be handled by personnel in hazardous locations.

Features


- Factory Sealed
- Test and Reset push buttons are provided on cover assembly, with optional pilot light available④ Unit should be tested monthly
- Includes new GFCI to meet latest UL943 GFCI standards revisions
- Exterior gasket provides NEMA 3 weatherproof protection
- Ground boss for grounding in the splice box
- Color coded wiring and stainless steel cover bolts
- Receptacle used is UGR0-20231. See page PR17

NEMA CONFIGURATION	125V SQUARE RECEPTACLE CAP STYLE	CATALOG NUMBER
20 Amp 125 Volt 2 POLE 3 WIRE 5-20R with T-slots	Breach-Lock with Notch* Flip Lid Type**	UGRS-20231BQW④ UGRS-20231FQW
	Killark 125V Plugs*** 20 Amp 15 Amp	UGP-20231QW UGP-15231QW
250V SQUARE RECEPTACLE CAP STYLE		
20 Amp 250 Volt 2 POLE 3 WIRE 6-20R with T-slots	Breach-Lock with Notch* Flip Lid Type**	UGRS-20232BQW UGRS-20232FQW
	Killark 250V Plugs*** 20 Amp 15 Amp	UGP-20232QW UGP-15232QW

* Breach cap models N4X with lid closed and turned, N3 When Plug inserted Hinge Up

** Flip Lid models N3 with hinge in UP position with or without plug

*** See PR15 for Plug NEMA Diagram and Dimensions

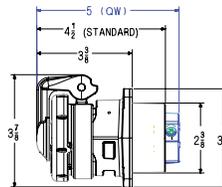

NEMA RATING & CONFIGURATION	ENCLOSURE STYLE	HUB SIZE	CATALOG NUMBER
20A, 125V, 2P, 3W	Dead End	1/2"	UGRGF107
	Dead End	3/4"	UGRGF108
	Dead End	1"	UGRGF109
	Feed Thru	1/2"	UGRGF110
	Feed Thru	3/4"	UGRGF111
	Feed Thru	1"	UGRGF112

UGRS RECEPTACLE & BACKBOXES①				
	E TYPE DEAD END ②	C TYPE FEED THRU ②	D TYPE ANGLED FEED THRU ④	RECEPTACLE ONLY
20A 125V	UGRS-20231BE2QW	UGRS-20231BC2QW	UGRS-20231BD2QW	UGRS-20231BQW
20A 250V	UGRS-20232BE3QW	UGRS-20232BC3QW	UGRS-20232BD3QW	UGRS-20232BQW

Electrical Rating

GFI units are rated at 20A, 120 VAC, 60Hz. Class A.

4-6 milliamp trip setting
 Trip Time-UL Curve

④ For Red LED pilot light indicator of live circuit, add "-PL" to catalog number. Example – UGRGF107-PL.

① Receptacles listed are with Breach cap; for Flip Cover change B to F.
 ② Boxes listed are for 3/4"; for 1/2" change last digit to 1, for 1" change last digit to 3.
 ③ cCSA_{us} Certified for United States, Canada, and other jurisdictions accepting the mark.
 ④ 125V 15A only (no T-slot) receptacles are available. See 5-15R Canadian configuration page PR17.
 Order numbers UGRS-15231BQW or UGRS-15231FQW.
 *** For Old Style plug remove QW from Catalog Number