



FH

 


Hook

V Hanger Boxes



VGA



VGC



VGH



VGX

Covers



Flexible Hanger Covers

Hub Covers  
(for Rigid Mounting)


## FEATURES-SPECIFICATIONS

## FH HOOK

## Features

- Economical hanger for pendant fixtures
- Fixtures may absorb minor bumps and vibration through free swinging action
- Hub provided with a set screw to prevent accidental loosening of fixture stem
- A 1/2 inch hole in body is for flexible cable. Cord may be assembled with plug for quick removal of fixtures
- Cast of aluminum alloy (copper-free—less than 4/10 of 1%)
- FH supports up to 125 pounds

| FH HOOK, LOOP  |             |                   |
|----------------|-------------|-------------------|
| CATALOG NUMBER | DESCRIPTION | FIXTURE STEM SIZE |
| FH-2           | Hook        | 3/4"              |

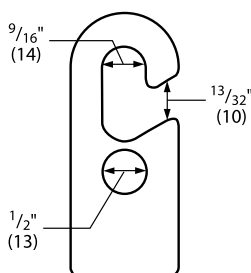

## V SERIES

## Features


- Flexible fixture hanger for threaded fixture stem
- Enclosed and gasketed, suitable for wet locations
- Permits angular displacement of fixture without twisting wires
- Cushioned—absorbs shock and vibration. Internal strap assures ground continuity
- Combines splice box and hanger in one unit. Splice box available in four configurations
- Cast of corrosion resistant aluminum alloy (copper-free—less than 4/10 of 1%)
- Supports up to 125 pounds

UL Listed - File E27731 or E3397

| FLEXIBLE HANGERS, V SERIES ENCLOSED AND GASKETED |                 |          |                   |
|--------------------------------------------------|-----------------|----------|-------------------|
| CATALOG NUMBER                                   |                 | HUB SIZE | FIXTURE STEM SIZE |
| HANGER W/SPLICE BOX                              | SPLICE BOX ONLY |          |                   |
| VPFHA-12                                         | VGA-1           | 1/2"     | 3/4"              |
| VPFHA-22                                         | VGA-2           | 3/4"     | 3/4"              |
| VPFHC-12                                         | VGC-1           | 1/2"     | 3/4"              |
| VPFHC-22                                         | VGC-2           | 3/4"     | 3/4"              |
| VPFHH-12                                         | VGH-1           | 1/2"     | 3/4"              |
| VPFHH-22                                         | VGH-2           | 3/4"     | 3/4"              |
| VPFHX-12                                         | VGX-1           | 1/2"     | 3/4"              |
| VPFHX-22                                         | VGX-2           | 3/4"     | 3/4"              |

| FIXTURE HANGERS ONLY |                                              |                   |
|----------------------|----------------------------------------------|-------------------|
| CATALOG NUMBER       | DESCRIPTION                                  | FIXTURE STEM SIZE |
| VPFH-2               | Flexible hanger cover, maximum load 125 Lbs. | 3/4"              |
| VG-2                 | Hub cover for rigid mounting                 | 3/4"              |

See page L11 for other box configurations.

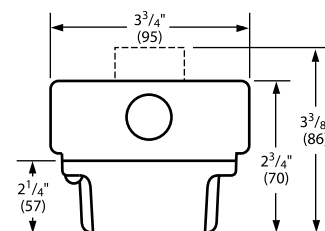

Flexible cover with box, dotted line is VGA pendant.

UL Listed - File E27731 or E3397  
See files for details or call Killark.



KILLARK®