



VSQ Series 30A 3P 4W Factory Sealed Hazardous Interlocked Receptacle

By Killark
Catalog # [VSQ3034FS](#)

30A 3W4P VSQ Factory Sealed Hazardous Interlocked Receptacle


Features

- Factory Sealed Construction
- Compact size and footprint
- Plug Interlock Mechanism for Dead-Front construction. Switch cannot be turned “ON” without fully inserted plug. Plug cannot be removed with switch in “ON” position
- Factory Wired Receptacle (Load Side)
- “Off” position is padlockable for maintenance safety
- Auxiliary Contact (late-make early-break) rated 10 Amp, 1/3 HP at 125/250 VAC.
- Adjustable mounting lugs
- Feed-through construction
- Horsepower-rated internal switch

Specifications

Hazardous Rating(s)	• Class I, Divisions 1 & 2, Groups B, C, D • Class I, Zones 1 & 2, Groups IIB+H2, IIA • Class II, Divisions 1 & 2, Groups F, G • Class III, Divisions 1 & 2
EU RoHS Indicator	Contact Manufacturer
Nema Rating	3, 4, 4X, 7(B, C, D), 9(F, G)
Buy America(n) Qualified	Contact Manufacturer

Conductor

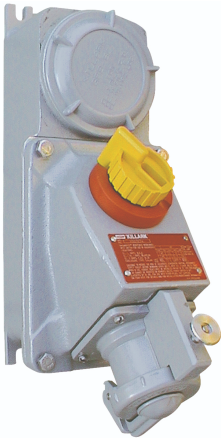

Number Of Wires	4
Number Of Poles	3

Configuration

Hub Pattern	Feed-Thru
-------------	-----------

Current

Amperage Rating	30 A
-----------------	------

Dimensions

Hub Size	1"
----------	----

General

Receptacle Type	Mechanically Interlocked
Type	Pin & Sleeve
Series	VSQ-FS
Material	Aluminum, Copper Free (less than 4/10 of 1%)
UPC	783936833361

Logistics

Factory Sealed	Factory Sealed
----------------	----------------

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)