



**Gilford™**

Bracket-mount scrub-up/plaster sink  
**K-12781**

**Features**

- Single center hole drilled back
- 30" x 22"

**Material**

- Vitreous china
- Premium material construction for durability and reliability

**Recommended Products/Accessories**

- K-1814-P Wall-Mount Sink Brackets
- K-8820 Sink Drain and Strainer
- K-23726 Drain treatment

**Optional Products/Accessories**

- K-9000 P-Trap
- K-9115 Sink Strainer



**Codes/Standards**

ASME A112.19.2/CSA B45.1


**KOHLER® One-Year Limited  
Warranty**


See website for detailed warranty information.

**Available Colors/Finishes**

*Color tiles intended for reference only.*

**Color Code Description**

	0	White
---	---	-------

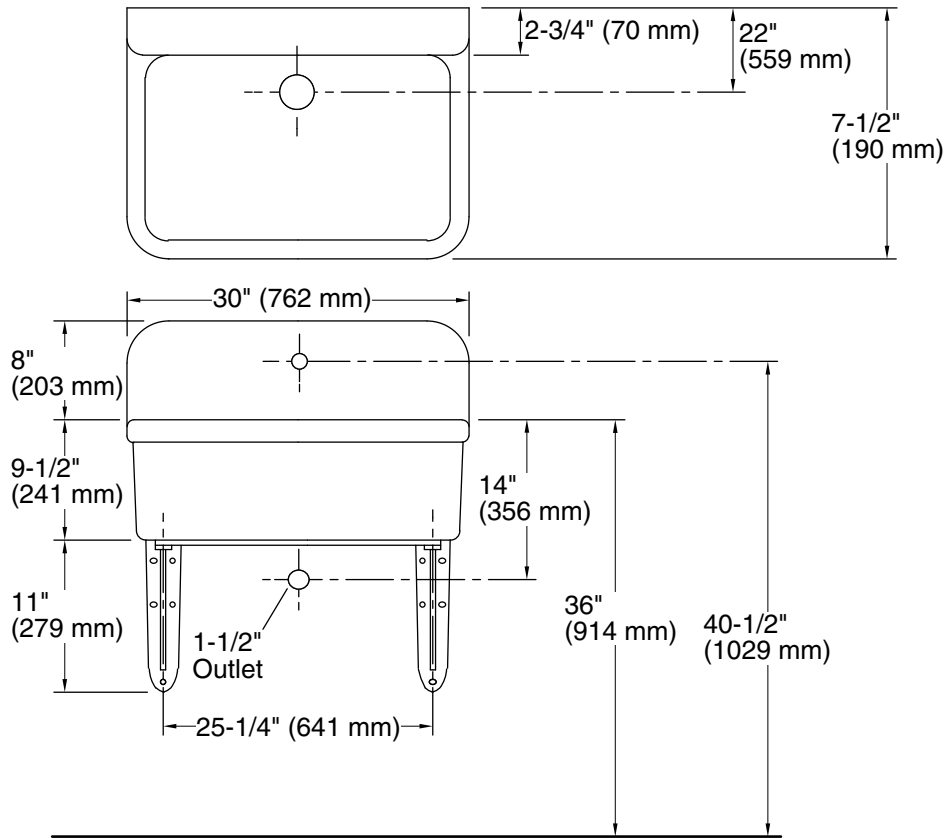

## Technical Information

All product dimensions are nominal.

Basin configuration:	Single Bowl
Bowl area (Only):	Length: 28" (711 mm) Width: 18" (457 mm) Water depth: 8-5/8" (219 mm)
With overflow:	No
Number of deck holes:	1
Faucet hole(s):	1-3/8" (35 mm)
Drain hole:	2-1/4" (57 mm)

## Notes

Install this product according to the installation instructions.

Product dimensions are nominal and may vary per ASME A112.19.2 tolerances.