

Features

- Universal input for 100–240 VAC, 50/60 Hz operation
- Powers up to eight Insight AC-powered touchless faucets
- Ultralow power consumption saves energy
- Energy Star Efficiency Level VI
- Regulated output of 5 VDC at 1.2 amps
- Short circuit and overcurrent output protection
- Intended for use in global outlets only. For North American outlets, please use K-13481-A

Installation

- Designed for portable or permanent hardwire installations
- Supplied with 30" (762 mm) power cord for easy 120-volt installation

Required Products/Accessories

K-13487 4' Cable Assembly

or

K-13602 6' Cable Assembly

Recommended Products/Accessories

K-13481 Multi-Outlet Power Supply




Codes/Standards

UL 60950
cUL Listed
UL Listed

KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

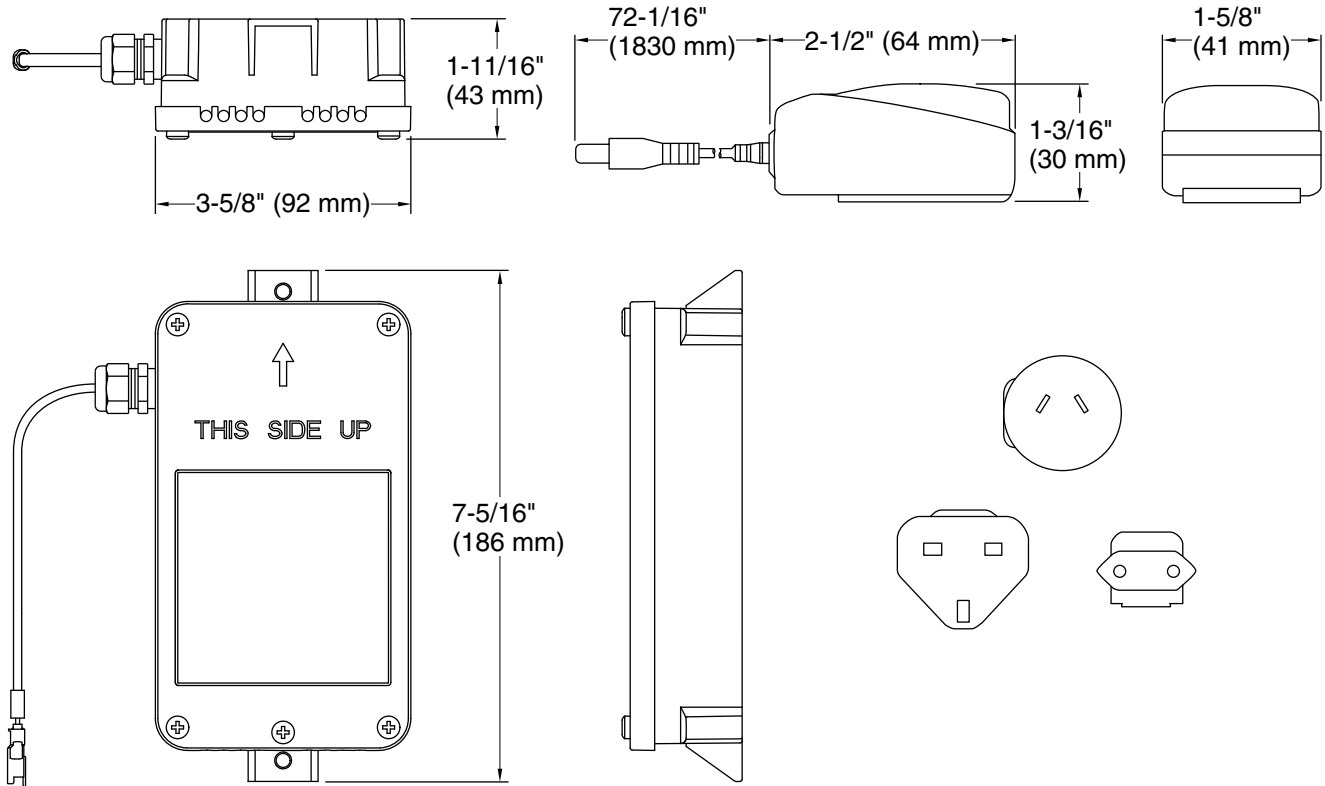

Required Electrical Service

One circuit required.

120/240 V, 0.3 A, 60 Hz

Technical Information

All product dimensions are nominal.

Material: Plastic

Notes

Install this product according to the installation instructions.