



Deerfield®
Top-/Under-Mount Kitchen Sink
K-5838

Features

- Double-equal bowls
- 9" (229 mm) depth provides generous workspace
- Smart Divide® feature offers a lower bowl divider that increases workspace versatility

Material

- KOHLER® enameled cast iron

Installation

- 33" minimum base cabinet width for top-mount installation, 36" minimum base cabinet width for undermount installation
- Top-mount or undermount

Recommended Products/Accessories

- K-8801 Sink drain and strainer with tailpiece
- K-8799 Sink drain and strainer basket
- K-23726 Drain treatment
- K-23725 Cast iron cleaner

Optional Products/Accessories

- K-6039 Sink Rack
- K-11352 Disposal Flange with Stopper
- K-9000 P-Trap



Codes/Standards

ASME A112.19.1/CSA B45.2


**KOHLER® Enameled Cast Iron
Kitchen and Bathroom Sink Lifetime
Limited Warranty**

See website for detailed warranty information.

DISCONTINUED This product has been discontinued.



Deerfield®
Top-/Under-Mount Kitchen Sink
K-5838

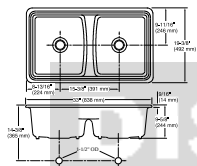

DISCONTINUED

This product has
been discontinued.

Technical Information

All product dimensions are nominal.

Basin configuration: Equal Bowls
Min. base cabinet width: 33" (838 mm)

Bowl area: Length: 14-5/8" (371 mm)
Width: 18-1/16" (459 mm)
Bowl depth: 9-5/8" (244 mm)
Water depth: 9" (229 mm)

Drain hole: 3-7/8" (98 mm)

Template: 1207481-7, required, included

Notes

Install this product according to the installation instructions.

NOTICE: Countertop manufacturer or cutter must use the cut-out template provided with the product, or a current one provided by Kohler Co. (call 1-800-4KOHLER). Kohler Co. is not responsible for cut-out errors when the incorrect cut-out template is used.

DISCONTINUED

This product has
been discontinued.

DISCONTINUED

This product has
been discontinued.