

Features

- Fixture-mount design
- Includes a 30-year hybrid energy cell

Material

- Brass

Technology

- Electronic infrared sensor with Tripoint® technology for accurate activation
- Slow-closing piston technology

Installation

- Intended for urinal installations with 3/4" (19 mm) spud coupling connection

Optional Products/Accessories

GP1118986 Flushometer Extension Kit



ADA

CSA B651

OBC


Codes/Standards

ASME A112.18.1/CSA B125.1
CSA B64
CSA B125.3
ASSE 1037/ASME A112.1037/CSA B125.37
ADA
ICC/ANSI A117.1
CSA B651
OBC

KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

*10-3/4" (273 mm) minimum with a
6" (152 mm) critical level above the fixture

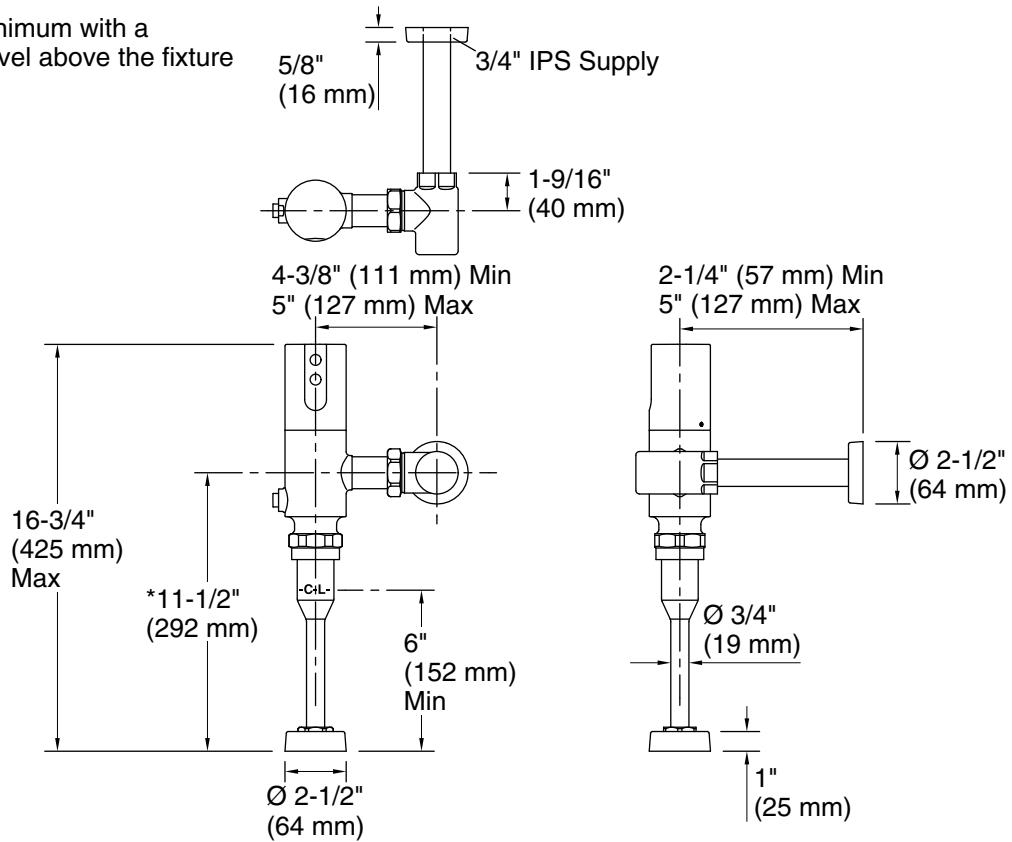

Technical Information

All product dimensions are nominal.

Power source: Hybrid Energy Cell, included

Spout:

Pressure/fixture Supply Requirements

Fixture pressure 80 psi (551.6 kPa)

max (static):

Min flowing 25 psi (172.4 kPa)

pressure:

Min flow rate: 10 gpm (37.9 lpm)

Notes

Install this product according to the installation instructions.

ADA, OBC, CSA B651 compliant when installed to the specific requirements of these regulations.