

Features

- Multifunction handshower offers two spray options
- Sweep® spray provides a wide massage stream of fine droplets with moderate pressure
- Cloud spray experience restores with a thick cloud of silky, super-fine water droplets
- MasterClean™ sprayface features an easy-to-clean surface that withstands mineral buildup and maximizes spray performance
- Optimized sprayface for maximum performance
- 1.75 gpm (6.6 lpm) maximum flow rate at 45 psi (3.1 bar)
- Requires shower hose (sold separately)
- This product can help a building earn Water Efficiency points in LEED® Green Building Rating System

Material


- Premium material construction for durability and reliability
- KOHLER finishes resist corrosion and tarnishing

Installation

- G 1/2 inlet connection
- Requires wand handshower holder or ceiling-mount dual shower arm (sold separately)
- Not recommended for use with a standard handshower holder

Optional Products/Accessories

K-7394 6" ceiling-mount single-function rainhead arm & flange

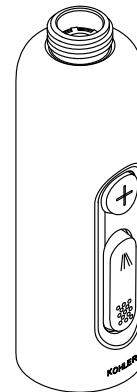


Codes/Standards

ASME A112.18.1/CSA B125.1
DOE - Energy Policy Act 1992
EPA WaterSense®
California Energy Commission (CEC)

KOHLER® Faucet Lifetime Limited Warranty

See website for detailed warranty information.

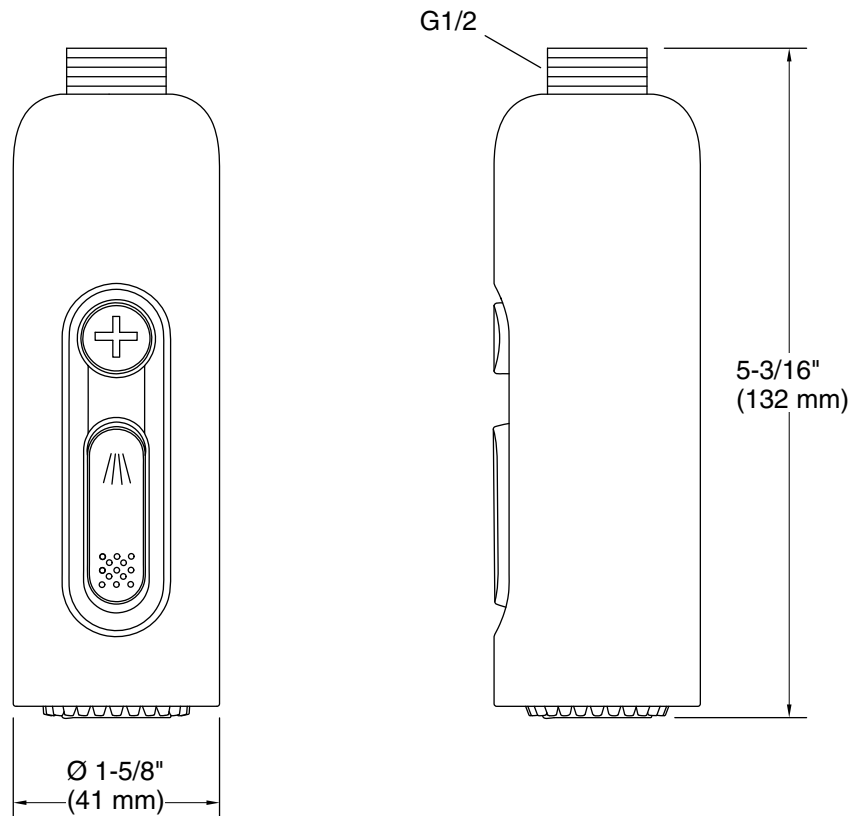

Technical Information

All product dimensions are nominal.

Spout:

Handshower rated max flow: 1.75 gal/min (6.6 l/min)