

### Features

- 0.5 gpm (1.9 lpm) maximum flow rate
- Factory-set 30-second maximum continual run cycle
- Vandal-resistant aerator
- 24" (610 mm) flexible supply hose for easy installation
- 5-5/16" (135 mm) spout reach
- Less drain
- Includes 3.6 volt Hybrid Energy Cell
- Less temperature mixer
- Insight™ adaptive infrared technology
- Waterproof shroud protects electronic components
- Water-saving vandal-resistant 0.5 gpm aerator

### Material

- Brass

### Technology

- Electronic Insight™ sensor technology for accurate and consistent activation

### Installation


- Single-hole mounting
- Above-counter valve for easy installation and maintenance

### Recommended Products/Accessories

K-23726 Drain treatment

### Optional Products/Accessories

K-99799 Thermostatic Tempering Valve  
 1351966 Concealed Spray 0.35 gpm (1.3 l/min)  
 K-7129 Drain  
 K-7129-A Bathroom sink grid drain with overflow  
 1101643 Large Concealed Spray 0.5 gpm (1.9 l/min)  
 1139288 Large Concealed Spray Aerated 1.0 gpm (3.8 l/min)  
 1139289 Large Concealed Laminar 1.0 gpm (3.8 l/min)  
 1139290 Large Concealed Aerated 1.5 gpm (5.7 l/min)  
 1100596 Large Concealed Laminar 1.5 gpm (5.7 l/min)  
 K-13478-B 4" escutcheon plate for Insight™ and Kinesis® faucet  
 K-13479-A 8" escutcheon plate for Insight™ and Kinesis® faucet  
 K-13479-B 8" escutcheon plate for Insight™ and Kinesis® faucet  
 K-13478-A 4" escutcheon plate for Insight™ and Kinesis® faucet

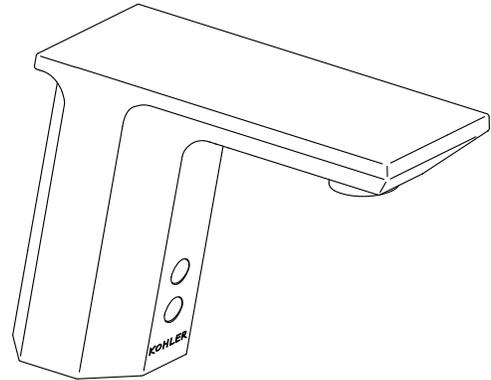

ADA

CSA B651

OBC

### Codes/Standards

ASME A112.18.1/CSA B125.1  
 NSF/ANSI/CAN 372  
 DOE - Energy Policy Act 1992  
 ADA  
 ICC/ANSI A117.1  
 CSA B651  
 OBC


### KOHLER® One-Year Limited Warranty

See website for detailed warranty information.

### Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
	CP	Polished Chrome
	VS	Vibrant® Stainless

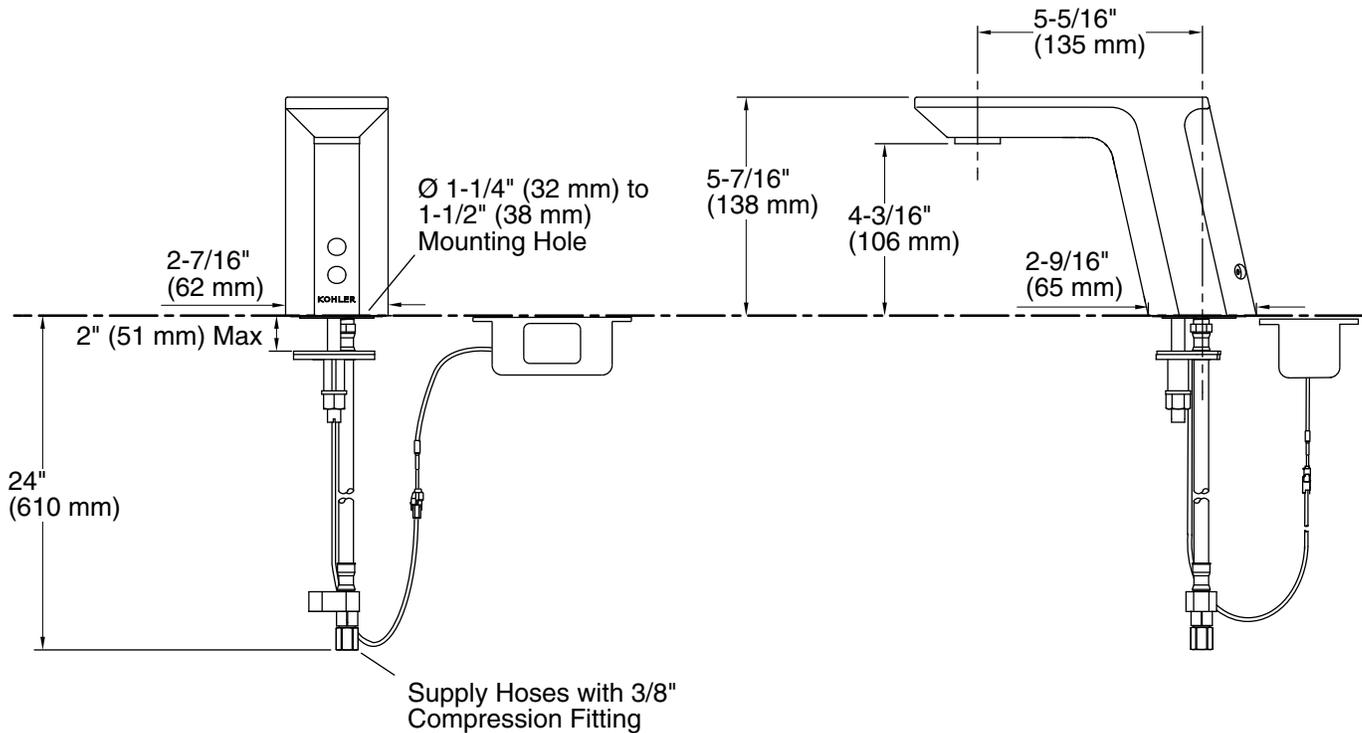

### Technical Information

All product dimensions are nominal.

Faucet flow rate: 0.5 gal/min (1.9 l/min)

### Spout:

Spout reach: 5-1/4" (133 mm)

### Notes

Install this product according to the installation guide.

A 1-1/4" (32 mm) minimum to 1-1/2" (38 mm) maximum diameter mounting hole is required.

The minimum distance between the back of the faucet spout and the wall must be 1-3/4" (44 mm). This will allow proper clearance for setscrew access.

The maximum distance between the bathroom sink basin edge to the base of the faucet spout must be 1-3/4" (44 mm).

The maximum height of the lip basin should be 3/4" (19 mm).

Product includes rosebud spray aerator. Other aerator styles are available.

ADA, OBC, CSA B651 compliant when installed to the specific requirements of these regulations.