


PRODUCT INFORMATION PACKET



Model No: 191543.00

Catalog No: 191543.00

Pedestal Fan Motor, 0.25 HP, 1 Ph, 60 Hz, 115/230 V, 1800 RPM, 48YZ Frame, TEAO

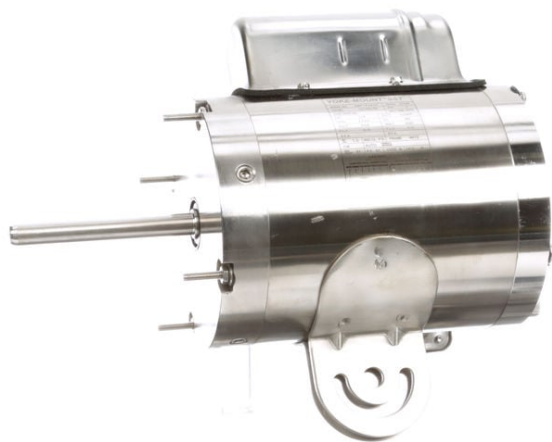

Regal and Leeson are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

©2023 Regal Rexnord Corporation, All Rights Reserved. MC017097E





Nameplate Specifications

Phase	1	Output HP	0.25 Hp
Output KW	0.19 kW	Voltage	115/230 V
Speed	1735 rpm	Service Factor	1.00
Frame	48YZ	Enclosure	Totally Enclosed Air Over
Thermal Protection	Automatic	Efficiency	59.5 %
Ambient Temperature	40 °C	Frequency	60 Hz
Current	2.6/1.3 A	Power Factor	99
Duty	Continuous	Insulation Class	F
Design Code	NO DESIGN CODE	KVA Code	B
Drive End Bearing Size	6203	Opp Drive End Bearing Size	6203
UL	Recognized	CSA	Y
CE	N	IP Code	55
Number of Speeds	1		

Technical Specifications

Electrical Type	Permanent Split Capacitor	Starting Method	Across The Line
Poles	4	Rotation	Selective Clockwise
Resistance Main	22.59 Ohms	Mounting	ROUND - EXTENDED STUDS
Motor Orientation	Horizontal	Drive End Bearing	Ball
Opp Drive End Bearing	Ball	Frame Material	Stainless Steel
Shaft Type	Single Special Extension	Overall Length	11.58 in
Shaft Diameter	0.500 in	Shaft Extension	4.05 in
Assembly/Box Mounting	F1 ONLY		
Connection Drawing	N/A	Outline Drawing	OL19154300

