

Versi-Duct[®] Vertical Cable Management System

APPLICATION

The Versi-Duct Cable Management System uses slotted ducts to route cable. The system mounts onto an industry-standard equipment rack. Two vertical 40-inch ducts, or one 80-inch duct (comprised of two 40-inch ducts) span the full length of a standard seven-foot equipment rack. The vertical slotted ducts come with cable concealing covers. An assortment of compatible cable management accessories is available.



SPECIFICATION

The vertical cable management system shall be a slotted duct configuration for copper and fiber cable systems. The management system shall be cULus listed, PVC rated UL 94V-0, ABS rated UL 94HB, and compliant with ANSI/TIA-568 standards. It shall mount onto an industry-standard 19-inch equipment rack. The management system shall offer an assortment of accessories including cable retainers, slack loop organizers, cover hinges, and designer covers.

ACCESSORIES

Accessories sold separately:

- **Cable Retainer** - Mounts on the duct fingers, is adjustable to slide along the duct finger, and includes break-away detail to accommodate all duct sizes
- **Mounting Bracket Kit** - Used to attach a vertical duct to an adjacent equipment rack (each kit comes with #8 screws)
- **Slack Loop Storage Organizer** - Stores slack cable and maintains a minimum of 1.18-inch bend-radius. Designed to be mounted on the duct fingers and can be adjusted to a variety of slack loop sizes
- **Duct Cover Hinge** - Designed to easily open and close duct cover for increased protection and easy access

FEATURES

- Versatile solution for fiber and copper cable organization and management
- Front only and front/rear configurations
- Cable concealing covers
- Mount on standard equipment racks with top, bottom, and side cable entry
- Duct fingers align with standard rack spacing

DESIGN CONSIDERATIONS

- Use on side of rack to route, protect, and manage fiber or copper cable

STANDARDS & REGULATIONS

- ANSI/TIA-568
- cULus Listed

MECHANICAL SPECIFICATIONS

Dimensions:	See page two
Materials (channel):	ABS rated for UL94HB
Materials (cover):	PVC rated for UL 94V-0

COUNTRY OF ORIGIN


Taiwan:	4940L-VF _x , 4980L-VF _x , 49265-BKT
USA:	49265-xxx, 59265-5DC

WARRANTY INFORMATION

For Leviton product warranties, go to leviton.com/ns/warranty

4940L-VF_x, 4980L-VF_x, 49265-xxx, 59265-5DC

PRODUCT SPECIFICATIONS
4940L-VF_x, 4980L-VF_x, 49265-xxx, 59265-5DC

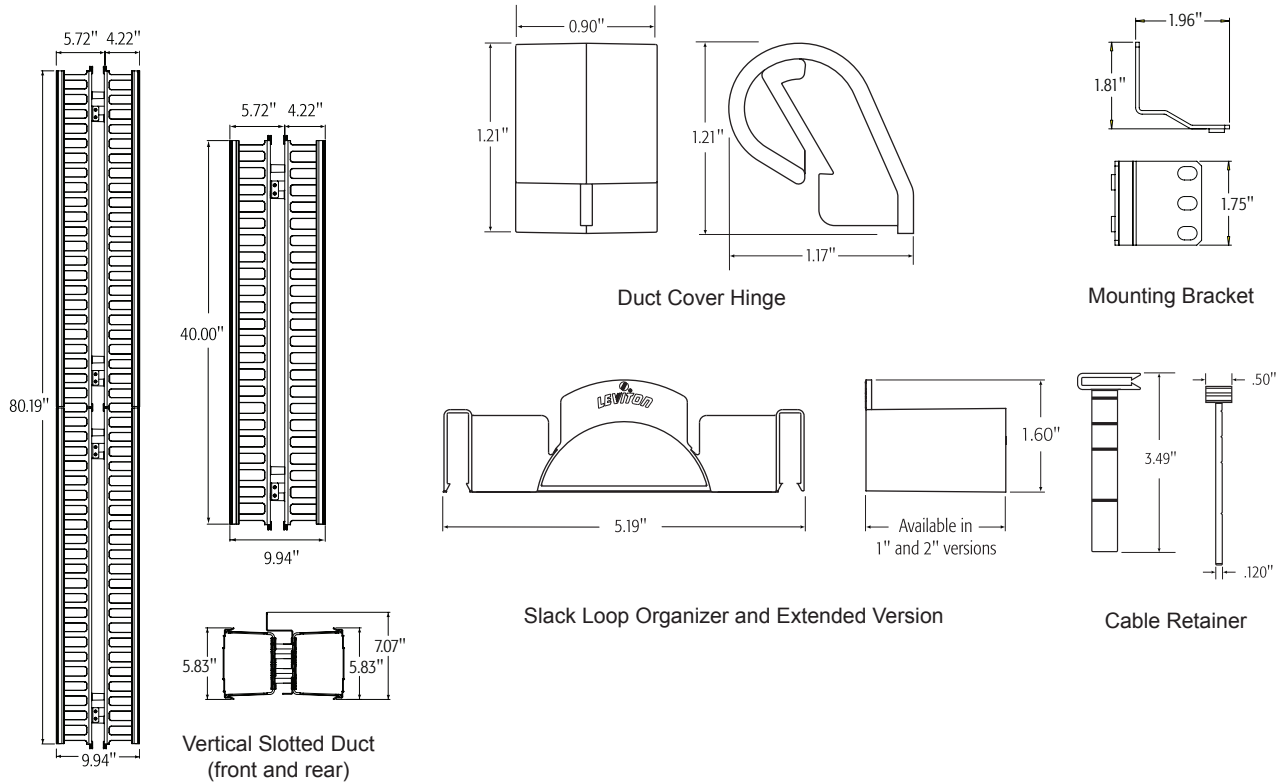

4940L-VF_x, 4980L-VF_x, 49265-xxx, 59265-5DC

PART NUMBERS

Description	Part No.
Versi-Duct® Vertical Slotted Duct - 4" x 5" rear and 4" x 5" front (front and rear) 40" H	4940L-VFR
Versi-Duct Vertical Slotted Duct - 4" x 5" (front only) 40" H	4940L-VFO
Versi-Duct Vertical Slotted Duct - 4" x 5" rear and 4" x 5" front (front and rear) 80" H	4980L-VFR
Versi-Duct Vertical Slotted Duct 4" x 5" (front only) 80" H	4980L-VFO
Versi-Duct Cable Retainer	49265-WR1
Versi-Duct Slack Loop Organizer	49265-SL1
Versi-Duct Slack Loop Organizer (extended)	49265-SL2
Versi-Duct Mounting Bracket	49265-BKT
Versi-Duct Duct Cover Hinge	49265-HNG
Vertical 40" Designer Cover, 5" channel, gray (set of 2)	59265-5DC
Vertical 40" Cover, 5" channel, snap-on, black (set of 4)	4940L-SRC

For further support information, visit leviton.com/ns/support