

## 5256-VB

15 Amp, 125 Volt, NEMA 5-15P, 2P, 3W, Plug, Straight Blade, Industrial Grade, Grounding, Python - Black



**UPC Code :** 078477055175

**Country Of Origin :** Mexico

**RoHS Compliant :** Yes



**Available Colors :**



When it comes to the demanding nature of today's commercial and industrial electrical environments, ruggedness and ease of installation are the features you look for first in any line of plugs and connectors. Leviton's Python straight-blade plugs and connectors hold up under the most exacting requirements, the toughest conditions, the roughest handling. Python's exceptional design features meet your needs for a quick, easy-to-wire plug and connector system, a must in today's faced-paced world where lost minutes on a job can translate into lost profits.

### Technical Information

#### Electrical Specifications

**Amperage :** 15 A

**Current Interrupting :** Certified for current interrupting at full rated current

**Dielectric Voltage :** Withstands 2000V per UL498

**Grounding :** Grounding

**Pole :** 2

**Temperature Rise :** Max 30C after 250 cycles OL at 200 percent rated current

**Voltage :** 125 VAC

**Wire :** 3

#### Environmental Specifications

**Environment :** Dry

**Flammability :** Rated V-2 per UL 94

**Operating Temperature :** -40°C to 60°C

#### Material Specifications

**Assembly Screws :** Steel, Zinc Plated

**Back Cover :** Thermoplastic

**Blades/Contacts :** Solid Brass

**Body Material :** Super Tough Nylon

**Clamp Insert :** Nylon

**Color :** Black

**Cord-Clamp :** Nylon

**Terminal Screws :** Brass

**Wire Module :** Nylon

#### Mechanical Specifications

**Cord Range :** .245 - .700

**Product ID :** Ratings and NEMA I.D. permanently marked on device

**Terminal Accom. :** 18-10 AWG

**Terminal ID :** Brass-Hot, Green-Ground, Silver-Neutral

**Torque Range :** 12-14 in-lbs

#### Product Features

**Brand :** Python

**Color :** Black

**Device Type :** Straight Blade Plug

**NEMA :** 5-15P

#### Standards and Certifications

**ANSI :** C-73



**CSA C22.2 No. 42 :** File LR-406

**NOM :** 057

**UL 498 :** File E13399

**Warranty :** 2-Year Limited

**Dimensional Diagram**

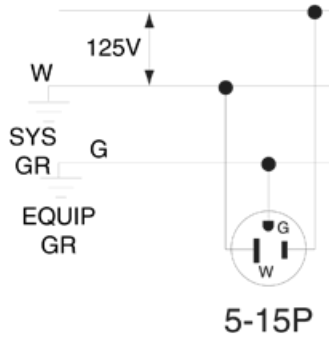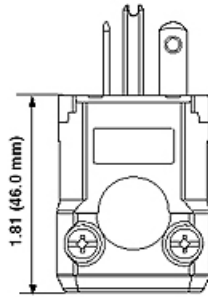

**SPECIFICATION SUBMITTAL**

|                      |                      |                      |                      |
|----------------------|----------------------|----------------------|----------------------|
| JOB NAME:            |                      | CATALOG NUMBERS:     |                      |
| <input type="text"/> |                      | <input type="text"/> | <input type="text"/> |
| JOB NUMBER:          | <input type="text"/> | <input type="text"/> | <input type="text"/> |

**Leviton Manufacturing Co., Inc.**

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):

+1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-

1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)

© 2021 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**

If you would like to know where your local Leviton office is located please go to:

[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

