




**Color :**  Fresh Pink Lemonade

**UPC Code :** 078477807347

**Country Of Origin :** China

**RoHS Compliant :** Yes

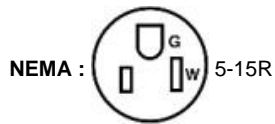

**Available Colors :**



# RUAA1-FP

Renu 3.6A USB Type-A/Type-A Wall Outlet Charger with 15A Tamper-Resistant Receptacle

Combination Duplex Receptacle/Outlet and USB Charger. 15 Amp, 125 Volt, Renu Tamper-Resistant Receptacle/Outlet, NEMA 5-15R. 3.6 Amps, 5VDC, 2.0 Type A USB Chargers. Grounding, Side Wired & Back Wired – Fresh Pink Lemonade

- SMART - Built-in smart chip recognizes the individual device's charging requirement to optimize the charge
- POWERFUL – Two high-powered charging ports with 3.6A of charging power
- CONVENIENT – No more searching for charging adapters! Upgrade your existing outlets so you can charge up to two USB powered electronics at once, leaving the outlets free for additional power needs
- EASY - Matte finish available in 20 popular colors that works with Leviton Renu wallplate REWP1/REWP2/REWP3/REWP4

### Technical Information

Product Features

**Amperage :** 15 A  
**Brand :** Renu  
**Color :** Fresh Pink Lemonade  
**Color Change Kit :** RKA01  
**Device Type :** USB Duplex Outlet  
**Grade :** Residential  
**Grounding :** Self-Grounding Clip and Green Ground Screw  
**Horsepower Rating :** 15A-1/2 HP  
**NEMA :** 5-15R  
**Ratings :** 15A-125V  
**Type :** Type A/A Duplex Receptacle  
**Voltage :** 125 VAC  
**Wallplate :** Not Included

Electrical Specifications

**Amperage :** 15 A  
**Flammability :** Rated V-0 per UL 94  
**Grounding :** Self-Grounding Clip and Green Ground Screw  
**Horsepower Rating :** 15A-1/2 HP  
**Operating Temperature :** -10°C to 40°C  
**Ratings :** 15A-125V

Environmental Specifications

**Body Material :** Thermoplastic  
**Cover Material :** Thermoplastic  
**Flammability :** Rated V-0 per UL 94  
**Operating Temperature :** -10°C to 40°C

**Strap Material :** Steel

Material Specifications

**Body Material :** Thermoplastic  
**Cover Material :** Thermoplastic  
**Product ID :** Stamped on Strap  
**Strap Material :** Steel  
**Terminal Accom. :** 14-12 AWG  
**Terminal ID :** Brass-Hot Black-Hot White-Neutral Green-Gnd  
**Termination :** Back & Side  
**Torque Range :** 14 – 18 in.-lbs

Mechanical Specifications

**Color :** Fresh Pink Lemonade  
**Color Change Kit :** RKA01  
**Device Type :** USB Duplex Outlet  
**Grade :** Residential  
**NEMA :** 5-15R  
**Product Family :** Renu  
**Product ID :** Stamped on Strap  
**Terminal Accom. :** 14-12 AWG  
**Terminal ID :** Brass-Hot Black-Hot White-Neutral Green-Gnd  
**Termination :** Back & Side  
**Torque Range :** 14 – 18 in.-lbs

Standards and Certifications

**FCC Part 15 :** Class B  
**Listed :** cCSAus  
**NOM :** 057  
**Warranty :** 5-Year Limited

### Features and Benefits



Wood Smoke

- Smart chip recognizes and optimizes the charging requirements of individual devices
- 3.6A charging capacity
- Two high-powered charging ports
- Two 15A or 20A Tamper-Resistant receptacles for improved safety
- USB ports are positioned vertically providing more space for maneuvering and reducing stress on USB cables
- Compatible with USB 2.0 devices
- Fits in a standard wallbox
- Back and side wired for easy installation
- Can replace existing outlets Can be multi-ganged with Renu devices
- Available in 20 popular colors to match any décor
- Once installed, face easily snaps OFF and ON. Change color by ordering the RKAA1 or RKAA2 color change kit
- Uses only Renu Wallplates (sold separately)

**SPECIFICATION SUBMITTAL**

JOB NAME: <input style="width: 95%; height: 20px;" type="text"/>	CATALOG NUMBERS: <input style="width: 95%; height: 20px;" type="text"/>	
JOB NUMBER: <input style="width: 95%; height: 20px;" type="text"/>	<input style="width: 95%; height: 20px;" type="text"/>	<input style="width: 95%; height: 20px;" type="text"/>

**Leviton Manufacturing Co., Inc.**  
 201 North Service Road, Melville, NY 11747  
 Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):  
 +1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**  
 165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·  
 FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**  
 Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-  
 1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)  
 © 2021 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**  
 If you would like to know where your local Leviton office is located please go to:  
[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

