


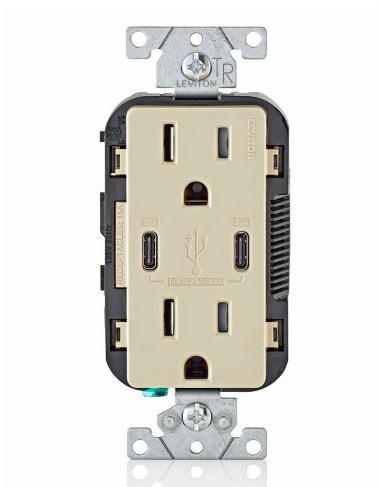


UPC Code : 078477979235

Country Of Origin : Please Contact Customer Service.

RoHS Compliant : Yes



Available Colors :

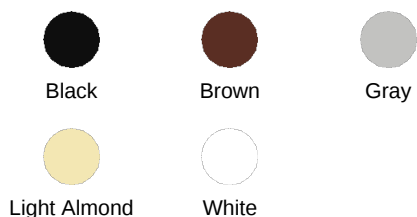

## T5635-I

30W (6A) USB Dual Type-C/C Power Delivery Wall Outlet Charger with 15A Tamper-Resistant Outlet

15 Amp, 125 Volt, Decora Tamper-Resistant Outlet. NEMA 5-15R, 30W (6 Amps), Dual Type-C/C Power Delivery USB Chargers, Grounding, Side Wired & Back Wired - Ivory

- POWERFUL – 30W charge on a single port. Up to 2x the charging power with PD-enabled devices
- INNOVATIVE – USB Type-C or USB-C provides faster charging and is emerging as the standard port on many phones, tablets and laptops
- ENHANCED SAFETY – Overcurrent protection helps protect electronic devices from over charging/heating and tamper-resistant outlets prevent unwanted objects from being inserted into the outlets
- FAST CHARGING – Smart chip ensures each device gets the power level it needs to charge fast and efficiently

### Technical Information

#### Product Features

**Amperage** : 15 A  
**Brand** : Decora  
**Color** : Ivory  
**Flammability** : Rated V-0 per UL 94  
**Grade** : Residential/Commercial Specification Grade  
**NEMA** : 5-15R  
**Operating Temperature** : -10°C to 40°C  
**Product Type** : Outlet/USB Combo  
**Type** : Type C/C with PD Duplex Receptacle  
**Voltage** : 125 VAC  
**Wallplate** : Not Included

#### Electrical Specifications

**Amperage** : 15 A  
**Body Material** : Thermoplastic  
**Color** : Ivory  
**Cover Material** : Thermoplastic  
**Grounding** : Grounding  
**Horsepower Rating** : 15A-1/2 HP  
**Ratings** : 15A-125V  
**Strap Material** : Steel  
**Voltage** : 125 VAC

#### Environmental Specifications

**Flammability** : Rated V-0 per UL 94  
**Operating Temperature** : -10°C to 40°C  
**Product ID** : Stamped on Strap

**Terminal Accom.** : 14-12 AWG

**Terminal ID** : Brass-Hot Black-Hot White-Neutral Green-Gnd

**Termination** : Back & Side

**Torque Range** : 14 – 18 in.-lbs

#### Material Specifications

**Body Material** : Thermoplastic  
**Color** : Ivory  
**Cover Material** : Thermoplastic  
**Grade** : Residential/Commercial Specification Grade  
**Strap Material** : Steel

#### Mechanical Specifications

**Listed** : cCSAus  
**NOM** : 057  
**Product ID** : Stamped on Strap  
**Terminal Accom.** : 14-12 AWG  
**Terminal ID** : Brass-Hot Black-Hot White-Neutral Green-Gnd  
**Termination** : Back & Side  
**Torque Range** : 14 – 18 in.-lbs  
**Warranty** : 2-Year Limited

#### Standards & Certifications

**FCC Part 15** : Class B  
**Listed** : cCSAus  
**NOM** : 057  
**UL 1310** : Yes  
**UL 498** : Yes  
**Warranty** : 2-Year Limited

### Features and Benefits

- The most advanced USB in-wall charger on the market with up to 2X the charging power with PD-enabled devices (No data transfer capability)
- Up to 30W charge when PD-enabled device connected to single port. Up to 15W charge per port (30W total) when both USB ports are connected to devices. Examples of maximum charging outputs are: Single port connected to PD-enabled device: 15VDC@2A (30W) or 9VDC@3A (27W) Single port connected to non-PD device: 5VDC@3A (15W) Both ports connected to devices (PD or non-PD): 5VDC@3A each (up to 30W total)
- Charges most Type-C devices as well as Type A devices (adapter required)
- Shallowest profile on the market for ease of installation
- Smart chip recognizes and optimizes the charging requirements of individual devices
- Built-in overcurrent protection helps protect the electronics from receiving too much power, which can damage the device
- Internal thermo regulator prevents the electronics from overheating
- USB Ports tested to meet the industry requirement to withstand over 10,000 insertions
- Compatible with USB 3.1, 3.0, 2.0, 1.1 devices
- Type-C USB Ports enable cables to be inserted in either direction
- Tamper-Resistant improves child safety – built-in shutter prevents access by most non-rated/foreign objects
- Charging time may be affected by the charge cord used. Leviton recommends using the cord provided with the device
- Compatible with Decora® wallplates and Decora Plus™ screwless wallplates
- Ideal for residential and commercial applications including kitchens, bedrooms, home offices, college dormitories, airport lounges, hospitals, salons and spas, hotels, meeting rooms, cafes, restaurants and more
- Compatible with Decora® wallplates and Decora Plus™ screwless wallplates. Wallplate sold separately
- No data transfer capability

#### Patents\*

|                  |           |
|------------------|-----------|
| CA2621644        | US7820909 |
| CA2624409        | US7868719 |
| CA2677283        | US8242362 |
| CN200880004760.2 | US8944859 |
| MX338817         | US9368982 |
| US7355117        | US9496726 |

\*This list is provided for patent marking purposes only. A good faith effort is made to maintain the accuracy and completeness of this list. No legal inference should be drawn from the omission of a patent from this list.

## SPECIFICATION SUBMITTAL

|                                   |                                          |                      |
|-----------------------------------|------------------------------------------|----------------------|
| JOB NAME:<br><input type="text"/> | CATALOG NUMBERS:<br><input type="text"/> |                      |
| JOB NUMBER: <input type="text"/>  | <input type="text"/>                     | <input type="text"/> |

**Leviton Manufacturing Co., Inc.**

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):  
+1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-  
1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

**Visit our Website at: [www.leviton.com](http://www.leviton.com)**

© 2021 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**

If you would like to know where your local Leviton office is located please go to:  
[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

