



Color:  Light Almond

UPC Code: 07847748925

Country Of Origin: Mexico

NEMA:
5-20R



TDR20-T

Brand Features

Plug Into Safety with Leviton's Line of Tamper-Resistant (TR) Receptacles. Leviton makes it easy for you to comply with the current NEC mandate for TR Receptacles in all new residential housing. This requirement resulted from a Consumer Product Safety Commission study, that reported alleged injuries in the home caused each year by children attempting to insert foreign objects into receptacles. TR receptacles have been mandated in pediatric care areas for over 20 years and have likely been successful in preventing electrical injuries. As a long-time manufacturer of tamper-resistant devices, we are pleased to be at the forefront of this safety measure with an expanded product line that encompasses a wide range of TR devices in Residential, Commercial, Industrial and Hospital Grades.

Item Description

Decora Plus Duplex Receptacle Outlet, Heavy-Duty Industrial Specification Grade, Tamper-Resistant, Smooth Face, 20 Amp, 125 Volt, Back or Side Wire, NEMA 5-20R, 2-Pole, 3-Wire, Self-Grounding - Light Almond

Technical Information

AC Horsepower Rating

Horsepower Rating: 1 HP

Electrical Specifications

Amperage: 20 A

Dielectric Voltage: Withstands 3000 V minimum

Grounding: Self-Grounding

Pole: 2

Temperature Rise: Max 30 °C temperature rise at full rated current

Voltage: 125 VAC

Wire: 3

Environmental Specifications

Flammability: Rated V-0 per UL 94

Operating Temperature: -40°C to 75°C

Material Specifications

Body Material: PBT Polyester Blend

Face Material: PBT Polyester Blend

Ground Clips: Brass

Ground Contacts: 0.030" Brass

Grounding Screw: #8 Hex Head, Triple-Drive Brass

Line Contacts: 0.030" Phosphor Bronze

Mounting Screws: Triple-Drive Plated Steel

Shutter Mechanism: Acetal

Strap Material: Steel (Galvanized G60)

Terminal Clamps: Brass

Terminal Screws: #8 Triple-Drive Brass

Mechanical Specifications

Product ID: Ratings are permanent part of devices

Terminal Accom.: #14 AWG - #10 AWG

Terminal ID: Brass - Hot, Silver - Neutral, Green - Ground

Termination: Back and Side Wire

Wire Type: Stranded or Solid

Product Features

Color: Light Almond

Color / Feature: Light Almond

Device Type: Duplex Receptacle Outlet

Feature:

Feature 2: Tamper-Resistant

Feature 4: Smooth Face

Grade: Heavy-Duty Industrial Specification Grade

NEMA: 5-20R

Standards & Certifications

ANSI: C-73

Applicable Standards: UL 498, Fed Spec W-C-596, CSA C22.2. No. 42

Certification/Listing: cULus, NOM-ANCE


NEMA: WD 1 & WD 6

RoHS: RoHS Compliant

Patents*

CA2483480	US6743029
CA2621644	US7355117
CA2624409	US7820909
CA2677283	US7868719
CN200880004760.2	US8242362
MX257790	US8684771
MX321216	

*This list is provided for patent marking purposes only. A good faith effort is made to maintain the accuracy and completeness of this list. No legal inference should be drawn from the omission of a patent from this list.

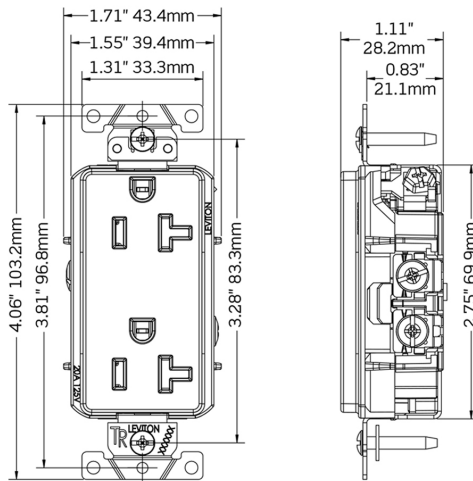

Drawing Applies to 15 & 20A Devices

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
JOB NUMBER:		

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Teléfono: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. Todos los derechos reservados. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts/

