

Little **GIANT**[®] Pump Company

1-42 SERIES



Features

- For submersed or in-line use
- Epoxy coated die-cast aluminum housing
- Oil-filled motor
- 7.4' maximum lift
- 70 watts
- 1/4" MNPT discharge
- Thermal overload protection


Construction

- Motor — 1/150 HP Oil Filled
- Maximum Flow Rate — 205 GPH @ 1'
- Maximum Head — 7.4'
- Intermittent Liquid Temp. up to — 120° F
- Intake — 1/2" MNPT & 1/4" FNPT
- Discharge — 1/4" MNPT
- Housing — Epoxy coated cast aluminum
- Cover — Epoxy coated cast aluminum
- Volute — Nylon
- Impeller — Nylon
- Shaft Seal — Nitrile

Dual purpose oil-filled pump that may be used totally submersed or in-line (fed with pipe or hose). For commercial, industrial and home applications including statuary fountains, water displays, air conditioners, machine tool coolants, and many other applications where liquid must be transferred or recirculated. This

Little Giant Pump Co.

1-42 SERIES

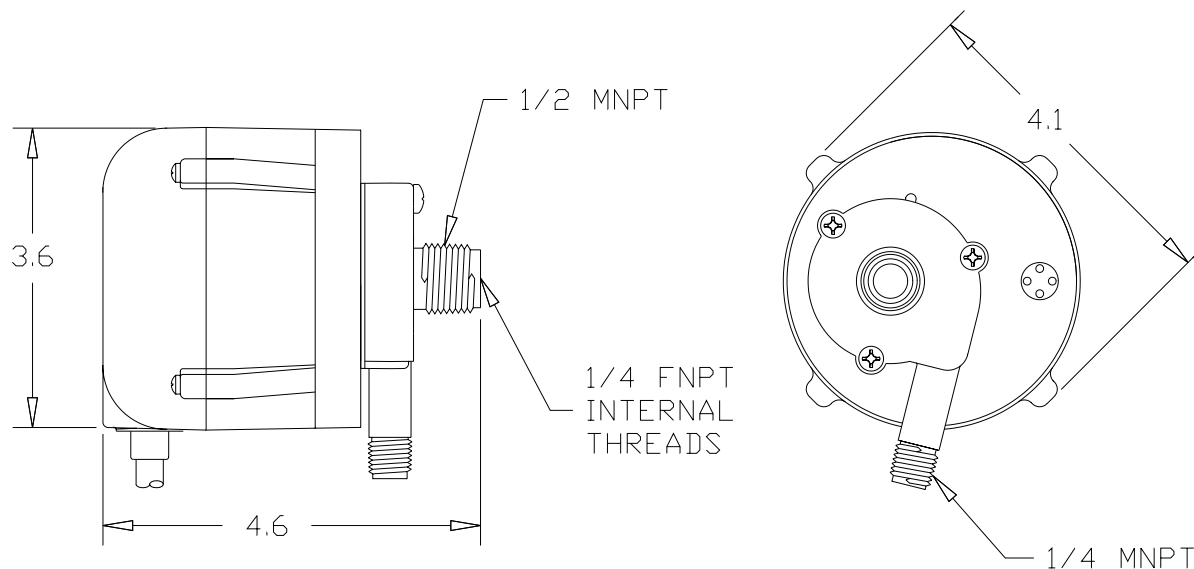


Specifications

Model No.	Item No.	Discharge	Intake	Listing(s)	HP	Volts	Hertz	Amps	Watts	Performance (GPH @ Head)			Shut Off		Pwr. Cord (ft)	Weight (Lbs.)
										1'	3'	5'	Feet	PSI		
1-42	501203	1/4" MNPT	1/2" FNPT & 1/4" FNPT	UL	1/150	115	60	1.1	70	205	168	120	7.4	3.2	6	3.50

Replacement Parts

Volute	101330
Impeller	101442
Gasket	131009

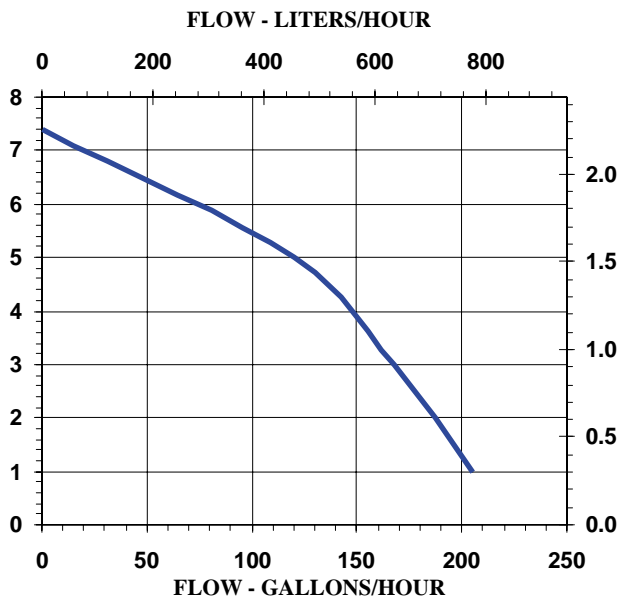

Replacement Parts

Volute	101330
Impeller	101442
Gasket	131009

For technical advice or service please take your pump into your local pump service center.
To order pump or parts or for pricing please go to the following links :

[Little Giant Pumps Home >>](#)

[Little Giant Pumps stock list >>](#)