


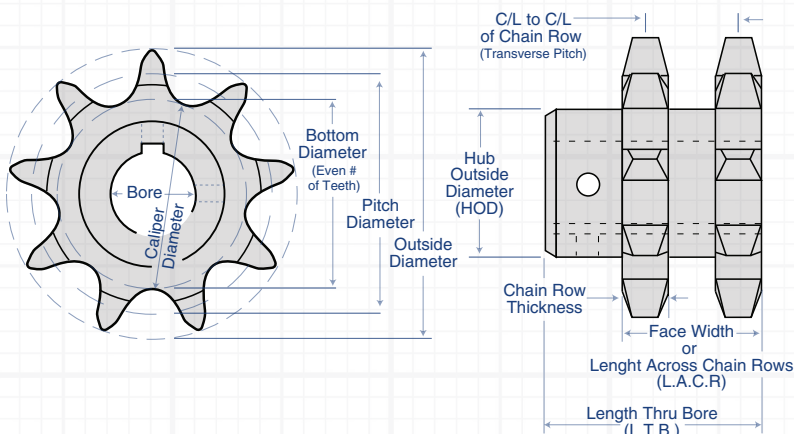

Sprocket Nomenclature

Sprocket Nomenclature



of Strands

Blank Single
D Double
E Triple
F Quadruple
DS Double Single

D 160 B 16 H 2 1/4

Bore Size

Special Instructions

H Hardened Teeth
SS Stainless Steel

of Teeth


Chain Pitch (measured in eighths)

25 = 2/8 = 1/4" 100 = 10/8 = 1 1/4"
35 = 3/8 = 3/8" 120 = 12/8 = 1 1/2"
40 = 4/8 = 1/2" 140 = 14/8 = 1 3/4"
41 = 4/8 = 1/2" 160 = 16/8 = 2"
50 = 5/8 = 5/8" 180 = 18/8 = 2 1/4"
60 = 6/8 = 3/4" 200 = 20/8 = 2 1/2"
80 = 8/8 = 1" 240 = 24/8 = 3"

Sprocket Type

A Plate Only
B Hub One Side
C Hub Both Sides
D Detachable Hubs
JA, SH,... QD
BTB Taper Bushed
H, P, Q,... MST®
BS Bored-To-Size

Types of Sprockets

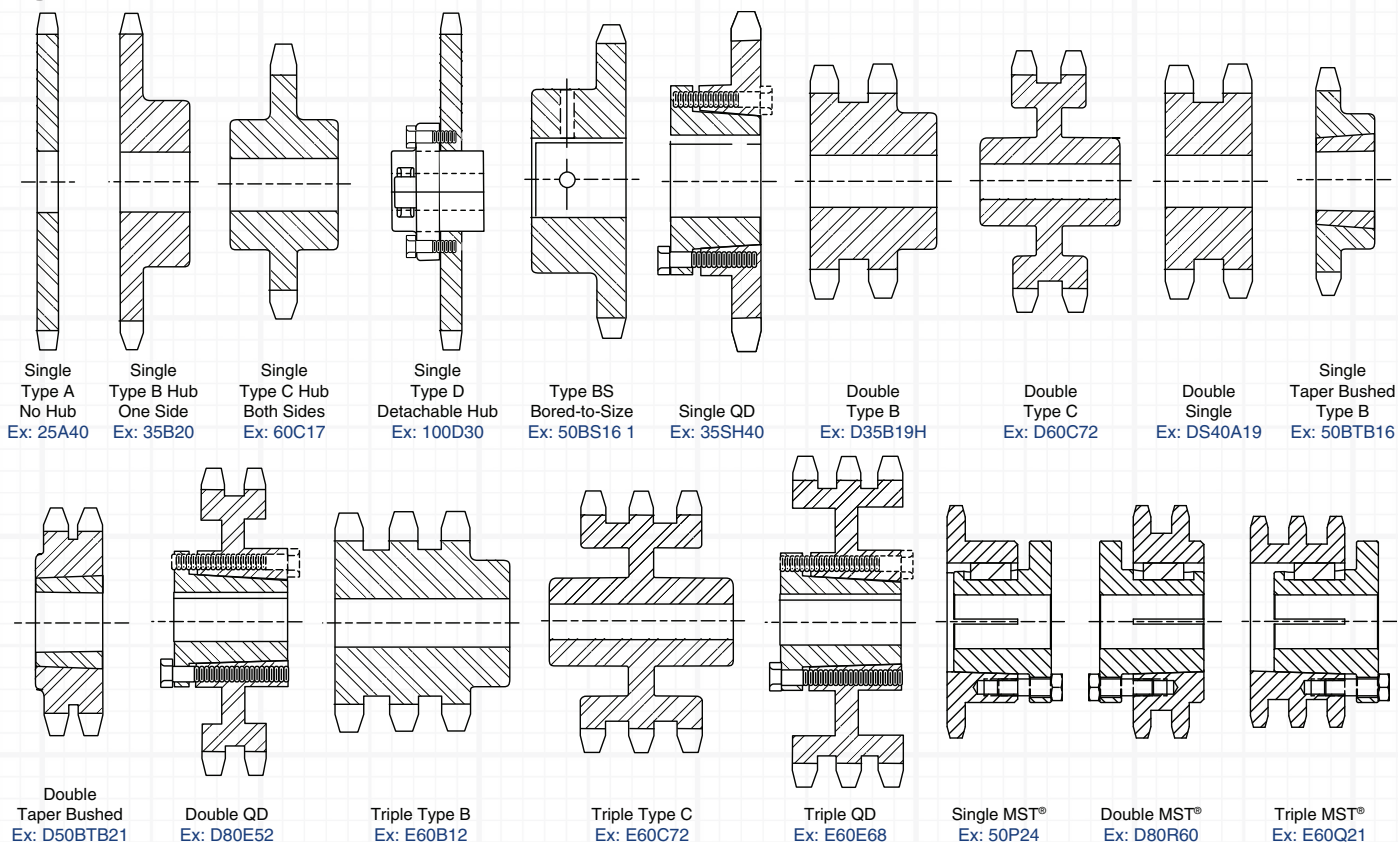

martinsprocket.com • 817.258.3000

Copyright © 2019 Martin Sprocket & Gear, Inc. • All Rights Reserved • CARD-SPK 2/18/2019