





FHP and VP Sheave Nomenclature

FHP and VP Sheave
Nomenclature

FHP Sheaves



Bored-to-Size and MST® Bushed

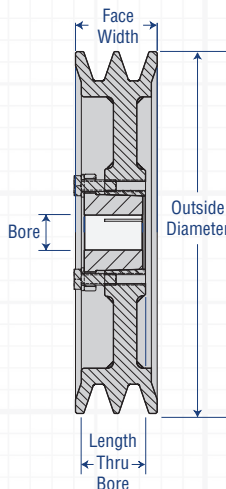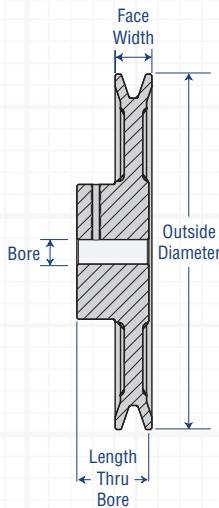

# of Grooves	2	AK	104	3/4	Bore or Bushing
If not listed, sheave is a single groove					Bore in Inches MST® "H" Bushing
Belt Selection					Approximate OD
AK 3L, 4L, A Section					1 decimal point: 10.4"
BK 4L, 5L, A, B Section					

Variable Pitch Sheaves

Bored-to-Size

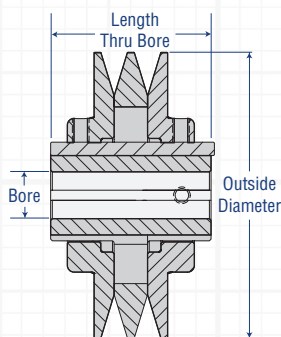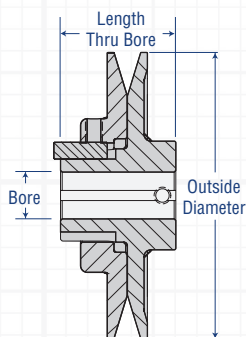

# of Grooves	1	VP	68	1 3/4	Bore
					Inches
Variable Pitch					Approximate OD
Belt Selection:					1 decimal point: 6.8"
3L, 4L, 5L, A, B, 5V Section					

- Full Line in Stock Now
- Wide Variety for HVAC and Lawn and Garden Equipment Applications

Call *Martin* for all your Made-to-Order Needs!

www.martinsprocket.com - 817 258 3000

Copyright© 2017 Martin Sprocket & Gear, Inc. • All Rights Reserved • CARD-FHP 1/25/2017