
 


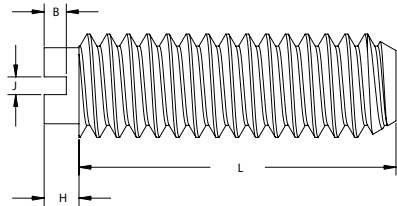

SET SCREWS

01S Series
Slotted Head Set Screw



- Specifications:
- Material: UL94 V-2 Nylon 6/6
 - Color: Natural

Item No.	Thread	L	ØA	H	J	B	Bulk Pack Qty
		in	in	in	in	in	
010256S006	#2-56	0.063	0.055	0.035	0.018	0.020	1000
010256S009	#2-56	0.094	0.055	0.035	0.018	0.020	1000
010256S012	#2-56	0.125	0.055	0.035	0.018	0.020	1000
010256S015	#2-56	0.156	0.055	0.035	0.018	0.020	1000
010256S018	#2-56	0.188	0.055	0.035	0.018	0.020	1000
010256S025	#2-56	0.250	0.055	0.035	0.018	0.020	1000
010256S028	#2-56	0.281	0.055	0.035	0.018	0.020	1000
010256S031	#2-56	0.313	0.055	0.035	0.018	0.020	1000
010256S037	#2-56	0.375	0.055	0.035	0.018	0.020	1000
010256S043	#2-56	0.438	0.055	0.035	0.018	0.020	1000
010256S050	#2-56	0.500	0.055	0.035	0.018	0.020	1000
010256S056	#2-56	0.563	0.055	0.035	0.018	0.020	1000
010256S062	#2-56	0.625	0.055	0.035	0.018	0.020	1000
010256S075	#2-56	0.750	0.055	0.035	0.018	0.020	1000
010256S087	#2-56	0.875	0.055	0.035	0.018	0.020	1000
010256S100	#2-56	1.000	0.055	0.035	0.018	0.020	1000
010256S112	#2-56	1.125	0.055	0.035	0.018	0.020	1000
010264S018	#2-64	0.188	0.055	0.035	0.018	0.020	1000
010264S037	#2-64	0.375	0.055	0.035	0.018	0.020	1000
010436S050	#4-36	0.500	0.075	0.045	0.020	0.025	1000
010440S009	#4-40	0.094	0.075	0.045	0.020	0.025	1000
010440S012	#4-40	0.125	0.075	0.045	0.020	0.025	1000
010440S014	#4-40	0.141	0.075	0.045	0.020	0.025	1000
010440S015	#4-40	0.156	0.075	0.045	0.020	0.025	1000
010440S018	#4-40	0.188	0.075	0.045	0.020	0.025	1000
010440S025	#4-40	0.250	0.075	0.045	0.020	0.025	1000
010440S028	#4-40	0.281	0.075	0.045	0.020	0.025	1000
010440S031	#4-40	0.313	0.075	0.045	0.020	0.025	1000
010440S037	#4-40	0.375	0.075	0.045	0.020	0.025	1000
010440S043	#4-40	0.438	0.075	0.045	0.020	0.025	1000
010440S050	#4-40	0.500	0.075	0.045	0.020	0.025	1000
010440S056	#4-40	0.563	0.075	0.045	0.020	0.025	1000
010440S062	#4-40	0.625	0.075	0.045	0.020	0.025	1000
010440S068	#4-40	0.688	0.075	0.045	0.020	0.025	1000
010440S075	#4-40	0.750	0.075	0.045	0.020	0.025	1000
010440S087	#4-40	0.875	0.075	0.045	0.020	0.025	1000
010440S100	#4-40	1.000	0.075	0.045	0.020	0.025	1000
010440S112	#4-40	1.125	0.075	0.045	0.020	0.025	1000
010440S118	#4-40	1.188	0.075	0.045	0.020	0.025	1000
010440S125	#4-40	1.250	0.075	0.045	0.020	0.025	1000
010440S137	#4-40	1.375	0.075	0.045	0.020	0.025	1000
010440S150	#4-40	1.500	0.075	0.045	0.020	0.025	1000
010440S162	#4-40	1.625	0.075	0.045	0.020	0.025	1000
010440S175	#4-40	1.750	0.075	0.045	0.020	0.025	1000
010448S025	#4-48	0.250	0.075	0.045	0.020	0.025	1000
010632S009	#6-32	0.094	0.100	0.055	0.025	0.030	1000
010632S012	#6-32	0.125	0.100	0.055	0.025	0.030	1000
010632S015	#6-32	0.156	0.100	0.055	0.025	0.030	1000
010632S018	#6-32	0.188	0.100	0.055	0.025	0.030	1000
010632S025	#6-32	0.250	0.100	0.055	0.025	0.030	1000
010632S031	#6-32	0.313	0.100	0.055	0.025	0.030	1000
010632S037	#6-32	0.375	0.100	0.055	0.025	0.030	1000
010632S043	#6-32	0.438	0.100	0.055	0.025	0.030	1000
010632S050	#6-32	0.500	0.100	0.055	0.025	0.030	1000
010632S056	#6-32	0.563	0.100	0.055	0.025	0.030	1000
010632S062	#6-32	0.625	0.100	0.055	0.025	0.030	1000
010632S068	#6-32	0.688	0.100	0.055	0.025	0.030	1000
010632S075	#6-32	0.750	0.100	0.055	0.025	0.030	1000
010632S087	#6-32	0.875	0.100	0.055	0.025	0.030	1000
010632S100	#6-32	1.000	0.100	0.055	0.025	0.030	1000
010632S112	#6-32	1.125	0.100	0.055	0.025	0.030	1000
010632S125	#6-32	1.250	0.100	0.055	0.025	0.030	1000
010632S150	#6-32	1.500	0.100	0.055	0.025	0.030	1000
010632S162	#6-32	1.625	0.100	0.055	0.025	0.030	1000
010632S175	#6-32	1.750	0.100	0.055	0.025	0.030	1000
010632S187	#6-32	1.875	0.100	0.055	0.025	0.030	1000
010632S200	#6-32	2.000	0.100	0.055	0.025	0.030	1000
010632S225	#6-32	2.250	0.100	0.055	0.025	0.030	1000
010640S025	#6-40	0.250	0.100	0.055	0.025	0.030	1000
010640S037	#6-40	0.375	0.100	0.055	0.025	0.030	1000

(Continued on next page >)