




01S Series (continued)
Slotted Head Set Screw

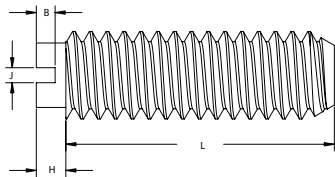

- Specifications:
- Material: UL94 V-2 Nylon 6/6
 - Color: Natural

Item No.	Thread	L in	ØA in	H in	J in	B in	Bulk Pack Qty
010640S075	#6-40	0.750	0.100	0.055	0.025	0.030	1000
010640S100	#6-40	1.000	0.100	0.055	0.025	0.030	1000
010832S012	#8-32	0.125	0.120	0.055	0.028	0.035	1000
010832S018	#8-32	0.188	0.120	0.055	0.028	0.035	1000
010832S025	#8-32	0.250	0.120	0.055	0.028	0.035	1000
010832S028	#8-32	0.281	0.120	0.055	0.028	0.035	1000
010832S031	#8-32	0.313	0.120	0.055	0.028	0.035	1000
010832S037	#8-32	0.375	0.120	0.055	0.028	0.035	1000
010832S043	#8-32	0.438	0.120	0.055	0.028	0.035	1000
010832S050	#8-32	0.500	0.120	0.055	0.028	0.035	1000
010832S062	#8-32	0.625	0.120	0.055	0.028	0.035	1000
010832S075	#8-32	0.750	0.120	0.055	0.028	0.035	1000
010832S087	#8-32	0.875	0.120	0.055	0.028	0.035	1000
010832S100	#8-32	1.000	0.120	0.055	0.028	0.035	1000
010832S112	#8-32	1.125	0.120	0.055	0.028	0.035	1000
010832S125	#8-32	1.250	0.120	0.055	0.028	0.035	1000
010832S137	#8-32	1.375	0.120	0.055	0.028	0.035	500
010832S150	#8-32	1.500	0.120	0.055	0.028	0.035	500
010832S175	#8-32	1.750	0.120	0.055	0.028	0.035	500
010832S187	#8-32	1.875	0.120	0.055	0.028	0.035	500
010832S200	#8-32	2.000	0.120	0.055	0.028	0.035	500
011024S012	#10-24	0.125	0.150	0.060	0.035	0.050	1000
011024S018	#10-24	0.188	0.150	0.060	0.035	0.050	1000
011024S025	#10-24	0.250	0.150	0.060	0.035	0.050	1000
011024S031	#10-24	0.313	0.150	0.060	0.035	0.050	1000
011024S037	#10-24	0.375	0.150	0.060	0.035	0.050	1000
011024S050	#10-24	0.500	0.150	0.060	0.035	0.050	1000
011024S062	#10-24	0.625	0.150	0.060	0.035	0.050	1000
011024S075	#10-24	0.750	0.150	0.060	0.035	0.050	1000
011024S100	#10-24	1.000	0.150	0.060	0.035	0.050	500
011024S125	#10-24	1.250	0.150	0.060	0.035	0.050	500
011024S150	#10-24	1.500	0.150	0.060	0.035	0.050	500
011032S012	#10-32	0.125	0.150	0.060	0.035	0.050	1000
011032S018	#10-32	0.188	0.150	0.060	0.035	0.050	1000
011032S025	#10-32	0.250	0.150	0.060	0.035	0.050	1000
011032S031	#10-32	0.313	0.150	0.060	0.035	0.050	1000
011032S037	#10-32	0.375	0.150	0.060	0.035	0.050	1000
011032S050	#10-32	0.500	0.150	0.060	0.035	0.050	1000
011032S062	#10-32	0.625	0.150	0.060	0.035	0.050	1000
011032S075	#10-32	0.750	0.150	0.060	0.035	0.050	500
011032S081	#10-32	0.813	0.150	0.060	0.035	0.050	500
011032S087	#10-32	0.875	0.150	0.060	0.035	0.050	500
011032S100	#10-32	1.000	0.150	0.060	0.035	0.050	1000
011032S106	#10-32	1.063	0.150	0.060	0.035	0.050	500
011032S125	#10-32	1.250	0.150	0.060	0.035	0.050	500
011032S150	#10-32	1.500	0.150	0.060	0.035	0.050	500
011032S175	#10-32	1.750	0.150	0.060	0.035	0.050	500
011032S200	#10-32	2.000	0.150	0.060	0.035	0.050	500
012520S025	1/4-20	0.250	0.175	0.080	0.040	0.060	1000
012520S031	1/4-20	0.313	0.175	0.080	0.040	0.060	1000
012520S037	1/4-20	0.375	0.175	0.080	0.040	0.060	1000
012520S050	1/4-20	0.500	0.175	0.080	0.040	0.060	1000
012520S062	1/4-20	0.625	0.175	0.080	0.040	0.060	500
012520S075	1/4-20	0.750	0.175	0.080	0.040	0.060	500
012520S087	1/4-20	0.875	0.175	0.080	0.040	0.060	500
012520S100	1/4-20	1.000	0.175	0.080	0.040	0.060	1000
012520S125	1/4-20	1.250	0.175	0.080	0.040	0.060	500
012520S150	1/4-20	1.500	0.175	0.080	0.040	0.060	500
012520S175	1/4-20	1.750	0.175	0.080	0.040	0.060	500
012520S200	1/4-20	2.000	0.175	0.080	0.040	0.060	500
012520S250	1/4-20	2.500	0.175	0.080	0.040	0.060	500
012528S018	1/4-28	0.188	0.175	0.080	0.040	0.060	1000
012528S025	1/4-28	0.250	0.175	0.080	0.040	0.060	1000
012528S031	1/4-28	0.313	0.175	0.080	0.040	0.060	500
012528S037	1/4-28	0.375	0.175	0.080	0.040	0.060	1000
012528S062	1/4-28	0.625	0.175	0.080	0.040	0.060	500
012528S075	1/4-28	0.750	0.175	0.080	0.040	0.060	500
012528S100	1/4-28	1.000	0.175	0.080	0.040	0.060	500
0137516S050	3/8-16	0.500	0.285	0.086	0.054	0.081	500
0137516S062	3/8-16	0.625	0.285	0.086	0.054	0.081	500
0137524S031	3/8-24	0.313	0.285	0.086	0.054	0.081	1000
0137524S041	3/8-24	0.422	0.285	0.086	0.054	0.081	500
0131224S081	5/16-24	0.813	0.246	0.078	0.051	0.078	500