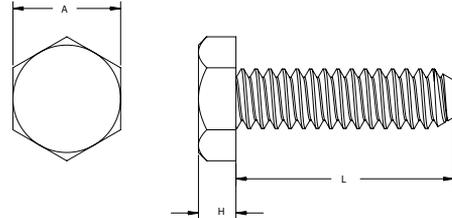



50J Series
Metric Hex Unslotted Screw


Specifications:

- Material: UL94 V-2 Nylon 6/6
- Color: Natural

Item No.	Thread	L		H		Bulk Pack Qty
		mm	mm	mm	mm	
50M020040J004	M2 x .4	4.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J005	M2 x .4	5.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J006	M2 x .4	6.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J008	M2 x .4	8.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J010	M2 x .4	10.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J012	M2 x .4	12.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J016	M2 x .4	16.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J020	M2 x .4	20.0	1.3 - 1.6	3.0 - 3.2	1000	
50M020040J025	M2 x .4	25.0	1.3 - 1.6	3.0 - 3.2	1000	
50M025045J004	M2.5 x .45	4.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J005	M2.5 x .45	5.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J006	M2.5 x .45	6.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J008	M2.5 x .45	8.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J010	M2.5 x .45	10.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J012	M2.5 x .45	12.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J016	M2.5 x .45	16.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J020	M2.5 x .45	20.0	1.8 - 2.1	3.8 - 4.0	1000	
50M025045J025	M2.5 x .45	25.0	1.8 - 2.1	3.8 - 4.0	1000	
50M030050J004	M3 x .5	4.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J005	M3 x .5	5.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J006	M3 x .5	6.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J008	M3 x .5	8.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J010	M3 x .5	10.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J012	M3 x .5	12.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J016	M3 x .5	16.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J020	M3 x .5	20.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J025	M3 x .5	25.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J030	M3 x .5	30.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J035	M3 x .5	35.0	2.0 - 2.3	4.8 - 5.0	1000	
50M030050J042	M3 x .5	42.0	2.0 - 2.3	4.8 - 5.0	1000	
50M035060J005	M3.5 x .6	5.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J006	M3.5 x .6	6.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J007	M3.5 x .6	7.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J008	M3.5 x .6	8.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J010	M3.5 x .6	10.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J012	M3.5 x .6	12.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J016	M3.5 x .6	16.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J020	M3.5 x .6	20.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J025	M3.5 x .6	25.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J035	M3.5 x .6	35.0	2.3 - 2.6	5.3 - 5.5	1000	
50M035060J042	M3.5 x .6	42.0	2.3 - 2.6	5.3 - 5.5	1000	
50M040070J006	M4 x .7	6.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J008	M4 x .7	8.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J010	M4 x .7	10.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J012	M4 x .7	12.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J016	M4 x .7	16.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J020	M4 x .7	20.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J025	M4 x .7	25.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J030	M4 x .7	30.0	2.6 - 3.0	6.8 - 7.0	1000	
50M040070J035	M4 x .7	35.0	2.6 - 3.0	6.8 - 7.0	500	
50M040070J040	M4 x .7	40.0	2.6 - 3.0	6.8 - 7.0	500	
50M050080J006	M5 x .8	6.0	3.3 - 3.8	7.8 - 8.0	1000	
50M050080J008	M5 x .8	8.0	3.3 - 3.8	7.8 - 8.0	1000	

Item No.	Thread	L		H		Bulk Pack Qty
		mm	mm	mm	mm	
50M050080J010	M5 x .8	10.0	3.3 - 3.8	7.8 - 8.0	1000	
50M050080J012	M5 x .8	12.0	3.3 - 3.8	7.8 - 8.0	1000	
50M050080J014	M5 x .8	14.0	3.3 - 3.8	7.8 - 8.0	1000	
50M050080J016	M5 x .8	16.0	3.3 - 3.8	7.8 - 8.0	1000	
50M050080J020	M5 x .8	20.0	3.3 - 3.8	7.8 - 8.0	1000	
50M050080J025	M5 x .8	25.0	3.3 - 3.8	7.8 - 8.0	500	
50M050080J030	M5 x .8	30.0	3.3 - 3.8	7.8 - 8.0	500	
50M050080J035	M5 x .8	35.0	3.3 - 3.8	7.8 - 8.0	500	
50M050080J040	M5 x .8	40.0	3.3 - 3.8	7.8 - 8.0	500	
50M050080J070	M5 x .8	70.0	3.3 - 3.8	7.8 - 8.0	500	
50M060100J005	M6 x 1.0	5.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J008	M6 x 1.0	8.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J010	M6 x 1.0	10.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J012	M6 x 1.0	12.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J016	M6 x 1.0	16.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J020	M6 x 1.0	20.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J025	M6 x 1.0	25.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J030	M6 x 1.0	30.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J035	M6 x 1.0	35.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J040	M6 x 1.0	40.0	4.1 - 4.7	9.8 - 10.0	1000	
50M060100J045	M6 x 1.0	45.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J050	M6 x 1.0	50.0	4.1 - 4.7	9.8 - 10.0	1000	
50M060100J060	M6 x 1.0	60.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J070	M6 x 1.0	70.0	4.1 - 4.7	9.8 - 10.0	500	
50M060100J075	M6 x 1.0	75.0	4.1 - 4.7	9.8 - 10.0	500	
50M080125J006	M6 x 1.0	6.0	4.1 - 4.7	9.8 - 10.0	500	
50M080125J010	M8 x 1.25	10.0	5.2 - 6.0	12.7 - 13.0	500	
50M080125J016	M8 x 1.25	16.0	5.2 - 6.0	12.7 - 13.0	500	
50M080125J020	M8 x 1.25	20.0	5.2 - 6.0	12.7 - 13.0	1000	
50M080125J025	M8 x 1.25	25.0	5.2 - 6.0	12.7 - 13.0	1000	
50M080125J030	M8 x 1.25	30.0	5.2 - 6.0	12.7 - 13.0	1000	
50M080125J035	M8 x 1.25	35.0	5.2 - 6.0	12.7 - 13.0	500	
50M080125J040	M8 x 1.25	40.0	5.2 - 6.0	12.7 - 13.0	500	
50M080125J050	M8 x 1.25	50.0	5.2 - 6.0	12.7 - 13.0	1000	
50M080125J070	M8 x 1.25	70.0	5.2 - 6.0	12.7 - 13.0	500	
50M080125J080	M8 x 1.25	80.0	5.2 - 6.0	12.7 - 13.0	250	
50M100150J016	M8 x 1.25	16.0	5.2 - 6.0	12.7 - 13.0	500	
50M100150J020	M10 x 1.5	20.0	6.5 - 7.5	15.7 - 16.0	500	
50M100150J025	M10 x 1.5	25.0	6.5 - 7.5	15.7 - 16.0	500	
50M100150J030	M10 x 1.5	30.0	6.5 - 7.5	15.7 - 16.0	500	
50M100150J035	M10 x 1.5	35.0	6.5 - 7.5	15.7 - 16.0	500	
50M100150J050	M10 x 1.5	50.0	6.5 - 7.5	15.7 - 16.0	250	
50M100150J060	M10 x 1.5	60.0	6.5 - 7.5	15.7 - 16.0	500	
50M120125J012	M10 x 1.5	12.0	6.5 - 7.5	15.7 - 16.0	250	
50M120175J020	M12 x 1.75	20.0	7.8 - 9.0	17.7 - 18.0	500	
50M120175J025	M12 x 1.75	25.0	7.8 - 9.0	17.7 - 18.0	250	
50M120175J030	M12 x 1.75	30.0	7.8 - 9.0	17.7 - 18.0	250	
50M120175J035	M12 x 1.75	35.0	7.8 - 9.0	17.7 - 18.0	250	
50M120175J040	M12 x 1.75	40.0	7.8 - 9.0	17.7 - 18.0	250	
50M120175J050	M12 x 1.75	50.0	7.8 - 9.0	17.7 - 18.0	250	
50M120175J060	M12 x 1.75	60.0	7.8 - 9.0	17.7 - 18.0	250	