



PLASTIC SCREWS

01WPC Series


 
Transparent Phillips Pan Head Screw

Specifications:

- Material: UL94 V-2 Polycarbonate
- Color: Transparent

Features:

- Exceptionally high impact strength
- Polycarbonate is unaffected by greases, oils & detergents

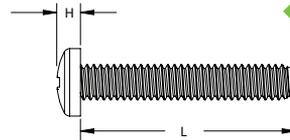

Item No.	Thread	Length		H	Ø A	Bulk Pack Qty
		in	mm			
010256W012PC	#2-56	0.125	0.155 - 0.167	0.053 - 0.062	1000	
010256W018PC	#2-56	0.188	0.155 - 0.167	0.053 - 0.062	1000	
010256W025PC	#2-56	0.250	0.155 - 0.167	0.053 - 0.062	1000	
010256W037PC	#2-56	0.375	0.155 - 0.167	0.053 - 0.062	1000	
010256W050PC	#2-56	0.500	0.155 - 0.167	0.053 - 0.062	1000	
010440W018PC	#4-40	0.188	0.205 - 0.219	0.070 - 0.080	1000	
010440W025PC	#4-40	0.250	0.205 - 0.219	0.070 - 0.080	1000	
010440W028PC	#4-40	0.281	0.205 - 0.219	0.070 - 0.080	1000	
010440W037PC	#4-40	0.375	0.205 - 0.219	0.070 - 0.080	1000	
010440W050PC	#4-40	0.500	0.205 - 0.219	0.070 - 0.080	1000	
010632W025PC	#6-32	0.250	0.256 - 0.270	0.087 - 0.097	1000	
010632W037PC	#6-32	0.375	0.256 - 0.270	0.087 - 0.097	1000	
010632W050PC	#6-32	0.500	0.256 - 0.270	0.087 - 0.097	1000	
010632W062PC	#6-32	0.625	0.256 - 0.270	0.087 - 0.097	1000	



Item No.	Thread	Length		H	Ø A	Bulk Pack Qty
		in	mm			
010632W075PC	#6-32	0.750	0.256 - 0.270	0.087 - 0.097	1000	
010832W012PC	#8-32	0.125	0.306 - 0.322	0.105 - 0.115	1000	
010832W025PC	#8-32	0.250	0.306 - 0.322	0.105 - 0.115	1000	
010832W037PC	#8-32	0.375	0.306 - 0.322	0.105 - 0.115	1000	
010832W050PC	#8-32	0.500	0.306 - 0.322	0.105 - 0.115	1000	
010832W062PC	#8-32	0.625	0.306 - 0.322	0.105 - 0.115	1000	
010832W075PC	#8-32	0.750	0.306 - 0.322	0.105 - 0.115	1000	
011032W025PC	#10-32	0.250	0.357 - 0.373	0.122 - 0.133	1000	
011032W037PC	#10-32	0.375	0.357 - 0.373	0.122 - 0.133	1000	
011032W050PC	#10-32	0.500	0.357 - 0.373	0.122 - 0.133	1000	
011032W062PC	#10-32	0.625	0.357 - 0.373	0.122 - 0.133	1000	
011032W075PC	#10-32	0.750	0.357 - 0.373	0.122 - 0.133	500	
011032W100PC	#10-32	1.000	0.357 - 0.373	0.122 - 0.133	500	

50P Series

Metric Phillips Pan Head Screw

Specifications:

 - Material: UL94 V-2 Nylon 6/6
- Color: Natural

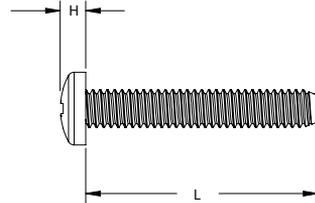

Item No.	Thread	L		H	Ø A	Bulk Pack Qty
		mm	mm			
50M020040P004	M2 x 0.4	4.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P005	M2 x 0.4	5.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P006	M2 x 0.4	6.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P008	M2 x 0.4	8.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P010	M2 x 0.4	10.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P012	M2 x 0.4	12.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P016	M2 x 0.4	16.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P020	M2 x 0.4	20.0	1.4 - 1.6	3.7 - 4.0	1000	
50M020040P025	M2 x 0.4	25.0	1.4 - 1.6	3.7 - 4.0	1000	
50M025045P004	M2.5 x 0.45	4.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P005	M2.5 x 0.45	5.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P006	M2.5 x 0.45	6.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P008	M2.5 x 0.45	8.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P010	M2.5 x 0.45	10.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P012	M2.5 x 0.45	12.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P016	M2.5 x 0.45	16.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P020	M2.5 x 0.45	20.0	1.9 - 2.1	4.7 - 5.0	1000	
50M025045P025	M2.5 x 0.45	25.0	1.9 - 2.1	4.7 - 5.0	1000	
50M030050P003	M3 x 0.5	3.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P004	M3 x 0.5	4.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P005	M3 x 0.5	5.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P006	M3 x 0.5	6.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P008	M3 x 0.5	8.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P010	M3 x 0.5	10.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P012	M3 x 0.5	12.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P016	M3 x 0.5	16.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P020	M3 x 0.5	20.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P025	M3 x 0.5	25.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P030	M3 x 0.5	30.0	2.2 - 2.4	5.3 - 5.6	1000	
50M030050P035	M3 x 0.5	35.0	2.2 - 2.4	5.3 - 5.6	500	
50M030050P042	M3 x 0.5	42.0	2.2 - 2.4	5.3 - 5.6	1000	
50M035060P005	M3.5 x 0.6	5.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P006	M3.5 x 0.6	6.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P007	M3.5 x 0.6	7.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P008	M3.5 x 0.6	8.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P010	M3.5 x 0.6	10.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P012	M3.5 x 0.6	12.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P016	M3.5 x 0.6	16.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P020	M3.5 x 0.6	20.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P025	M3.5 x 0.6	25.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P035	M3.5 x 0.6	35.0	2.3 - 2.6	6.6 - 7.0	1000	
50M035060P042	M3.5 x 0.6	42.0	2.3 - 2.6	6.6 - 7.0	1000	
50M040070P003	M4 x 0.7	3.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P006	M4 x 0.7	6.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P008	M4 x 0.7	8.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P010	M4 x 0.7	10.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P012	M4 x 0.7	12.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P016	M4 x 0.7	16.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P020	M4 x 0.7	20.0	2.8 - 3.1	7.6 - 8.0	1000	

Item No.	Thread	L		H	Ø A	Bulk Pack Qty
		mm	mm			
50M040070P025	M4 x 0.7	25.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P030	M4 x 0.7	30.0	2.8 - 3.1	7.6 - 8.0	1000	
50M040070P035	M4 x 0.7	35.0	2.8 - 3.1	7.6 - 8.0	500	
50M040070P040	M4 x 0.7	40.0	2.8 - 3.1	7.6 - 8.0	500	
50M050080P006	M5 x 0.8	6.0	3.4 - 3.7	9.1 - 9.5	1000	
50M050080P008	M5 x 0.8	8.0	3.4 - 3.7	9.1 - 9.5	1000	
50M050080P010	M5 x 0.8	10.0	3.4 - 3.7	9.1 - 9.5	1000	
50M050080P012	M5 x 0.8	12.0	3.4 - 3.7	9.1 - 9.5	1000	
50M050080P015	M5 x 0.8	15.0	3.4 - 3.7	9.1 - 9.5	1000	
50M050080P016	M5 x 0.8	16.0	3.4 - 3.7	9.1 - 9.5	1000	
50M050080P020	M5 x 0.8	20.0	3.4 - 3.7	9.1 - 9.5	1000	
50M050080P025	M5 x 0.8	25.0	3.4 - 3.7	9.1 - 9.5	500	
50M050080P030	M5 x 0.8	30.0	3.4 - 3.7	9.1 - 9.5	500	
50M050080P035	M5 x 0.8	35.0	3.4 - 3.7	9.1 - 9.5	500	
50M050080P040	M5 x 0.8	40.0	3.4 - 3.7	9.1 - 9.5	500	
50M060100P005	M6 x 1.0	5.0	4.3 - 4.6	11.5 - 12.0	1000	
50M060100P008	M6 x 1.0	8.0	4.3 - 4.6	11.5 - 12.0	1000	
50M060100P010	M6 x 1.0	10.0	4.3 - 4.6	11.5 - 12.0	1000	
50M060100P012	M6 x 1.0	12.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P016	M6 x 1.0	16.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P020	M6 x 1.0	20.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P022	M6 x 1.0	22.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P025	M6 x 1.0	25.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P030	M6 x 1.0	30.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P035	M6 x 1.0	35.0	4.3 - 4.6	11.5 - 12.0	1000	
50M060100P040	M6 x 1.0	40.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P045	M6 x 1.0	45.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P050	M6 x 1.0	50.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P060	M6 x 1.0	60.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P070	M6 x 1.0	70.0	4.3 - 4.6	11.5 - 12.0	500	
50M060100P075	M6 x 1.0	75.0	4.3 - 4.6	11.5 - 12.0	500	
50M080125P010	M8 x 1.25	10.0	5.6 - 6.0	15.5 - 16.0	500	
50M080125P016	M8 x 1.25	16.0	5.6 - 6.0	15.5 - 16.0	500	
50M080125P020	M8 x 1.25	20.0	5.6 - 6.0	15.5 - 16.0	500	
50M080125P025	M8 x 1.25	25.0	5.6 - 6.0	15.5 - 16.0	500	
50M080125P030	M8 x 1.25	30.0	5.6 - 6.0	15.5 - 16.0	500	
50M080125P035	M8 x 1.25	35.0	5.6 - 6.0	15.5 - 16.0	500	
50M080125P050	M8 x 1.25	50.0	5.6 - 6.0	15.5 - 16.0	500	
50M080125P070	M8 x 1.25	70.0	5.6 - 6.0	15.5 - 16.0	500	
50M100150P013	M10 x 1.5	13.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P016	M10 x 1.5	16.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P019	M10 x 1.5	19.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P020	M10 x 1.5	20.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P025	M10 x 1.5	25.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P030	M10 x 1.5	30.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P035	M10 x 1.5	35.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P050	M10 x 1.5	50.0	7.1 - 7.5	19.4 - 20.0	500	
50M100150P060	M10 x 1.5	60.0	7.1 - 7.5	19.4 - 20.0	500	