


Brass Pipe Fittings
Hex Head Plug (MPT)

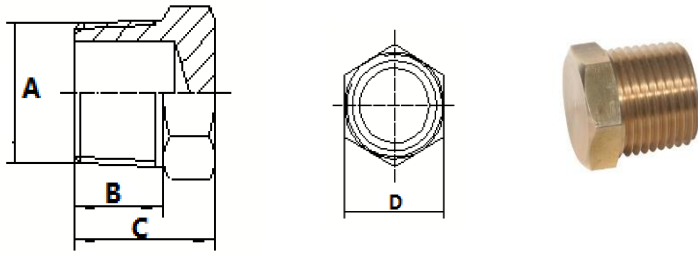

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: MPT

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
23152X2	1/8"	1/8"	0.37"	0.55"	7/16"
23152X4	1/4"	1/4"	0.47"	0.67"	9/16"
23152X6	3/8"	3/8"	0.53"	0.75"	11/16"
23152X8	1/2"	1/2"	0.67"	0.94"	7/8"
23152X12	3/4"	3/4"	0.67"	1.06"	1-1/16"
23152X16	1"	1"	0.83"	1.30"	1-3/8"

Drawing Date: 8/2019

Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov