


Brass Pipe Fittings
Bushing (MPT x FPT)

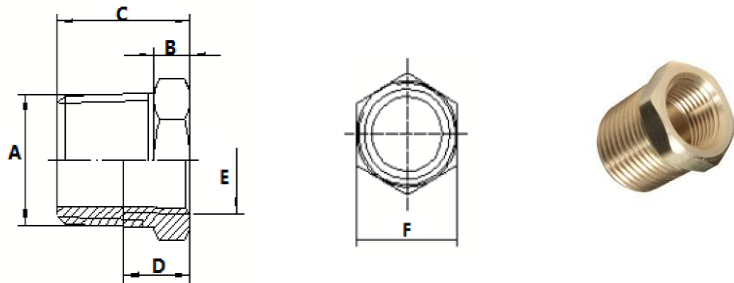

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: MPT x FPT

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)	E (In)	F (In)
23224X2	1/4 x 1/8	1/4"	0.20"	0.64"	0.35"	1/8"	9/16"
23226X4	3/8 x 1/4	3/8"	0.26"	0.75"	0.39"	1/4"	11/16"
23228X4	1/2 x 1/4	1/2"	0.24"	0.87"	0.43"	1/4"	7/8"
23228X6	1/2 x 3/8	1/2"	0.24"	0.87"	0.43"	3/8"	7/8"
232212X4	3/4 x 1/4	3/4"	0.30"	1"	0.49"	1/4"	1-1/16"
232212X6	3/4 x 3/8	3/4"	0.30"	1"	0.51"	3/8"	1-1/16"
232212X8	3/4 x 1/2	3/4"	0.30"	1"	0.51"	1/2"	1-1/16"



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov