


Brass Pipe Fittings Hex Nipple (MPT)

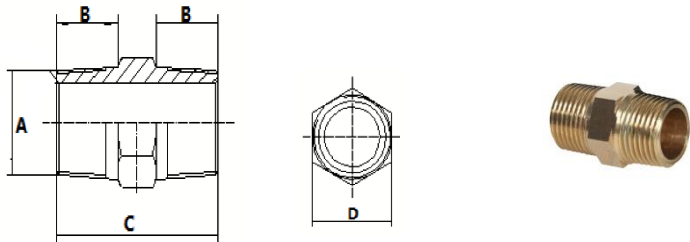

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: MPT

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
23325X2	1/8 x .97L	1/8"	0.37"	0.97"	7/16"
23325X4	1/4 x 1.38L	1/4"	0.55"	1.38"	9/16"
23325X6	3/8 x 1.41L	3/8"	0.59"	1.41"	3/4"
23325X8	1/2 x 1.81L	1/2"	0.65"	1.81"	7/8"
23325X12	3/4 x 1.96	3/4"	0.75"	1.96"	1-1/16"
23325X16	1 x 2.30L	1"	0.83"	2.30"	1-3/8"

Drawing Date: 8/2019

Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov