


Brass Pipe Fittings
45° Street Elbow (FPT x MPT)

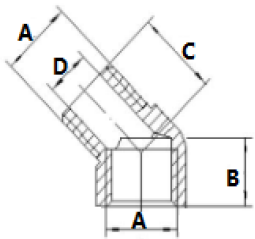

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: FPT x MPT

Part No.	Size (In)	A (In)	B (In)	C (In)	D (In)
23350X2	1/8	1/8"	0.37"	0.50"	0.22"
23350X4	1/4	1/4"	0.43"	0.60"	0.32"
23350X6	3/8	3/8"	0.57"	0.65"	0.45"
23350X8	1/2	1/2"	0.63"	0.83"	0.61"
23350X12	3/4	3/4"	0.75"	1.06"	0.75"

Drawing Date: 8/2019

Rev. Level-Date: R1 8/2021



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov