


Brass Pipe Fittings
Brass 90° Street Elbow (MPT x FPT)

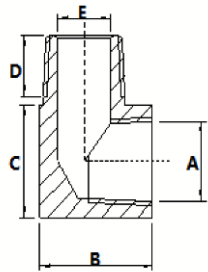

Used with Brass, Copper, Steel, Aluminum and Iron Pipe
Meets SAE, ASA and ASME Specifications and Standards
Pressure Rating: 1200 PSI
Temperature Rating: -65°F to 250°F
One Piece Construction
Teflon Tape or Pipe Sealant is Recommended
Pipe Threads Should be Tightened 2-1/2" Turns Past Finger Tight
Connection: MPT x FPT

Part No.	Size (In) MPT	A (In) FPT	B (In)	C (In)	D (In)	E (In)
23400X2	1/8	1/8"	0.55"	0.51"	0.28"	0.26"
23400X4	1/4	1/4"	0.74	0.68"	0.43"	0.35"
23400X6X4*	1/4	3/8"	0.96"	0.79"	0.43"	0.35"
23400X6	3/8	3/8"	0.98"	0.79"	0.43"	0.47"
23400X8	1/2	1/2"	1.14"	0.94"	0.59"	0.59"
23400X12	3/4	3/4"	1.69"	1.22"	0.75"	0.75"

Drawing Date: 8/2019
Rev. Level-Date: R2 6/2024



WARNING: This product can expose you to chemicals, including lead, which is known to the State of California to cause cancer and reproductive harm. For more information go to www.P65Warnings.CA.gov